




DATASHEET

230 V/AC Axial Fan


Item no 3594044

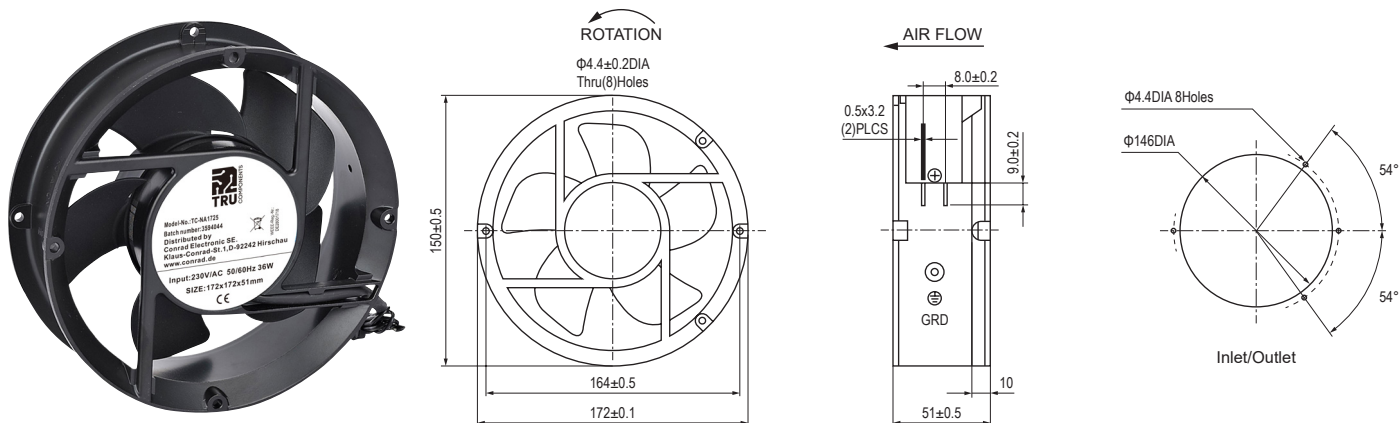


Dimensions in mm

Voltage	230 V/AC
Frequency	50/60 Hz
Power	35.8/33.8 W
Current	0.24/0.23 A
Phase	1
Protection class	I
Insulation class	F
Speed	2650 rpm
Air flow	336 m³/hr
Air flow	198 CFM
Noise	59 dBA
Impeller material	PBT Black
Frame material	Aluminum Alloy
Motor type	Shaded Pole Induction Motor
Bearing	Ball
Lead wire	AWG #22 (approx. 0.34 mm²)
Terminals size	0.5 mm
Operating temperature	-10 to +65 °C
Operating humidity	30 - 95 % RH
Storage temperature	-40 to +70 °C
Storage humidity	30 - 95 % RH
Dimensions (Ø x W)	172 x 172 x 51 mm
Weight	820 g


Static Pressure (mmH₂O)

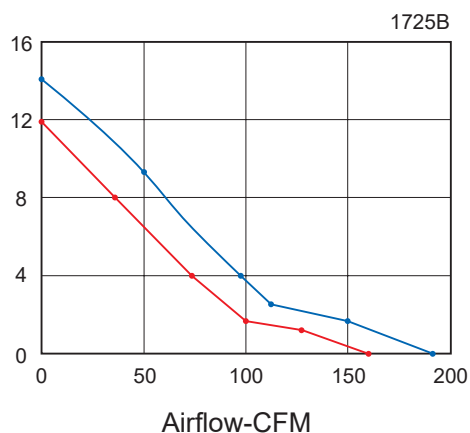


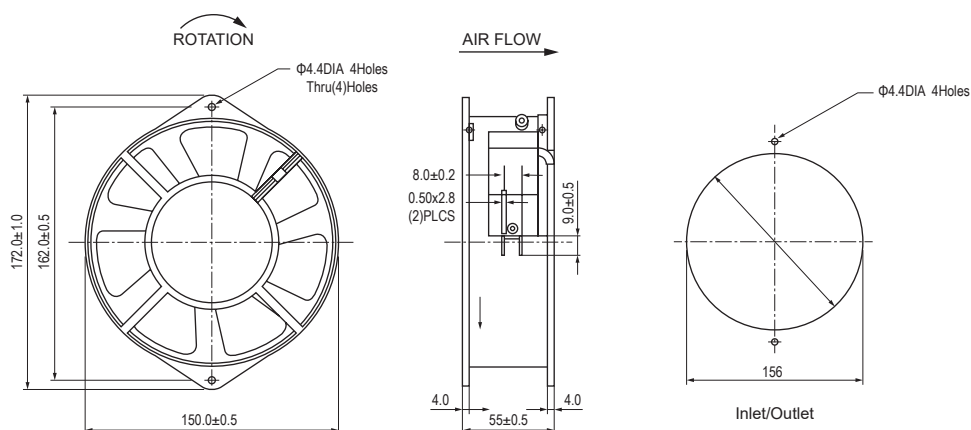

Dimensions in mm


Voltage	230 V/AC
Frequency	50/60 Hz
Power	38.2/33.5 W
Current	0.253/0.217 A
Phase	1
Protection class	I
Insulation class	F
Speed	2650 rpm
Air flow	400 m³/hr
Air flow	263 CFM
Noise	55 dBA
Impeller material	Iron Leaf
Frame material	Aluminum Alloy
Motor type	Capacitor-Run External Motor
Bearing	Ball
Lead wire	AWG #22 (approx. 0.34 mm²)
Terminals size	0.5 mm
Operating temperature	-10 to +105 °C
Operating humidity	30 - 95 % RH
Storage temperature	-40 to +70 °C
Storage humidity	30 - 95 % RH
Dimensions (Ø x W)	172 x 150 x 55 mm
Weight	1.03 kg

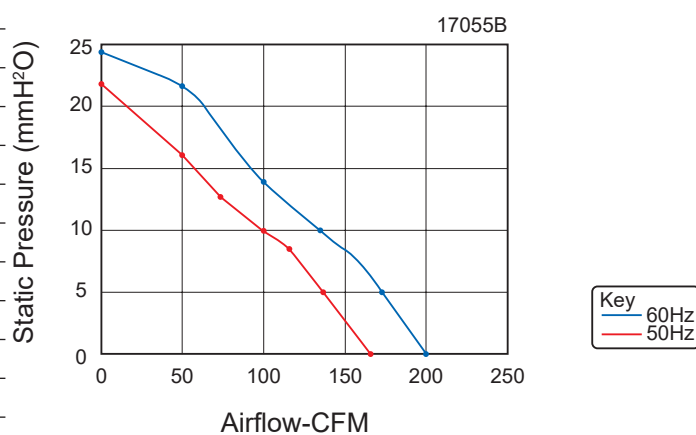


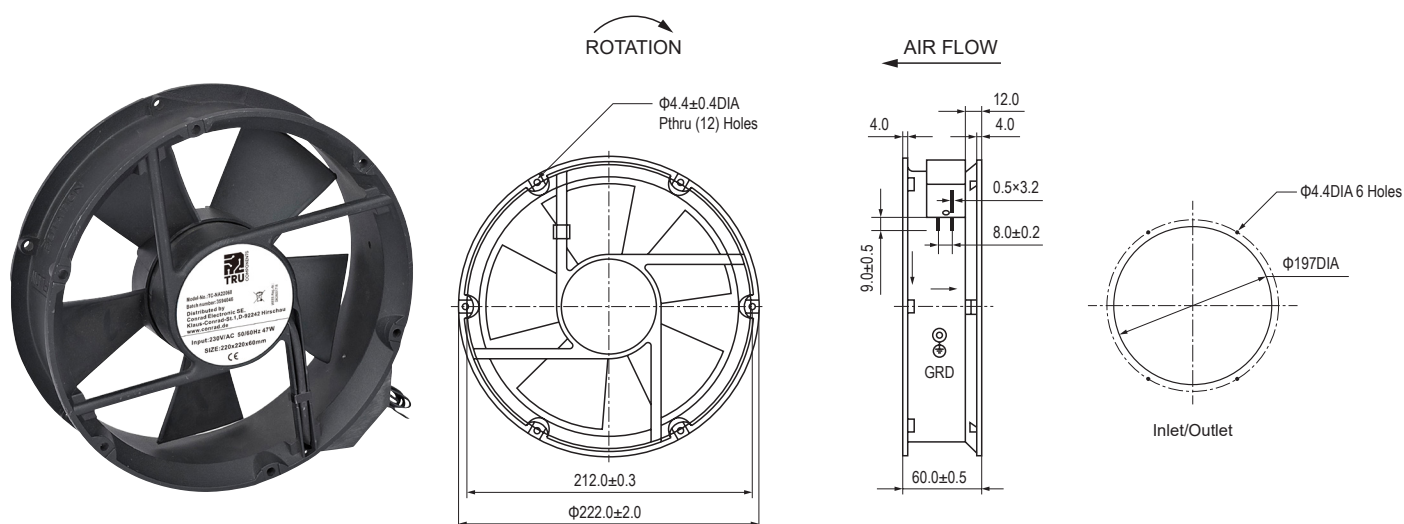

Dimensions in mm

Voltage	230 V/AC
Frequency	50/60 Hz
Power	47.2/60.3 W
Current	0.213/0.262 A
Phase	1
Protection class	I
Insulation class	F
Speed	2500 rpm
Air flow	890 m³/hr
Air flow	530 CFM
Noise	65 dBA
Impeller material	PBT Black
Frame material	Aluminum Alloy
Motor type	Capacitor-Run External Motor
Bearing	Ball
Capacitor	1 x 1.0 uf/500 V
Lead wire	AWG #22 (approx. 0.34 mm²)
Terminals size	0.5 mm
Operating temperature	-10 to +70 °C
Operating humidity	30 - 95 % RH
Storage temperature	-40 to +70 °C
Storage humidity	30 - 95 % RH
Dimensions (Ø x W)	220 x 220 x 60 mm
Weight	1.25 kg

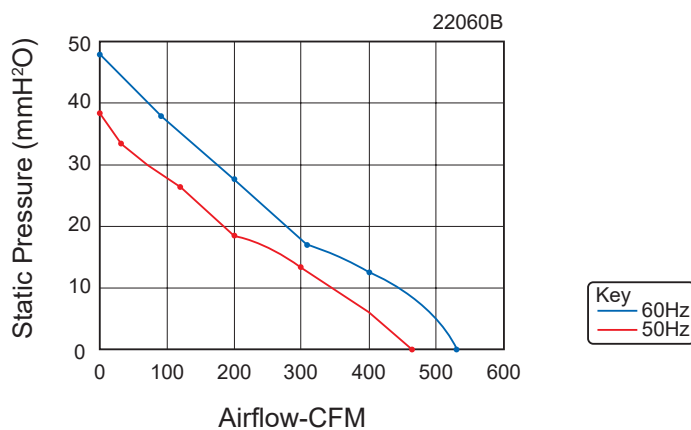

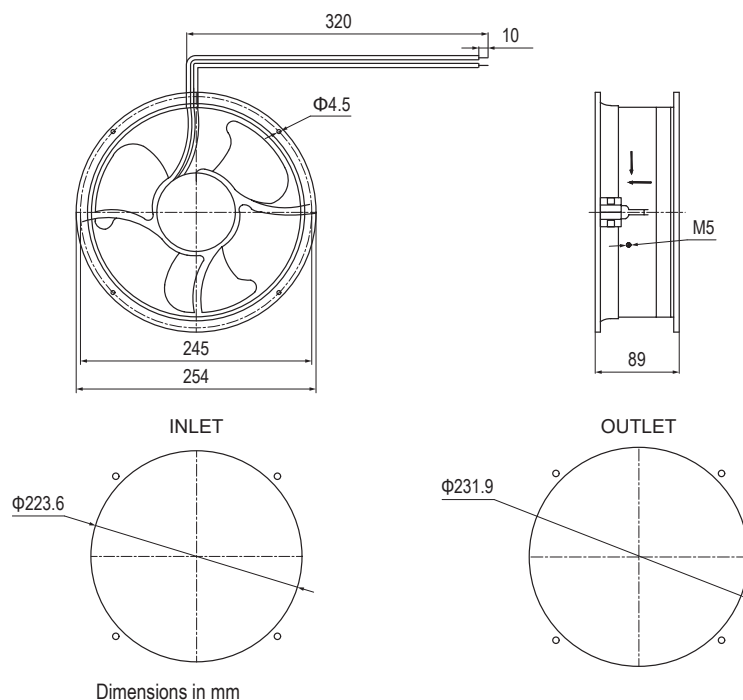

Voltage	230 V/AC
Frequency	50/60 Hz
Power	110/123.6 W
Current	0.52/0.534 A
Phase	1
Protection class	I
Insulation class	F
Speed	2800 rpm
Air flow	1528 m ³ /hr
Air flow	910 CFM
Noise	78 dBA
Impeller material	PBT Black
Frame material	Aluminum Alloy
Motor type	Capacitor-Run External Motor
Bearing	Ball
Lead wire	AWG #22 (approx. 0.34 mm ²)
Terminals size	0.5 mm
Operating temperature	-10 to +70 °C
Operating humidity	30 - 95 % RH
Storage temperature	-40 to +70 °C
Storage humidity	30 - 95 % RH
Dimensions (Ø x W)	254 x 254 x 89 mm
Weight	2.29 kg

