


Data Sheet

Toggle switch

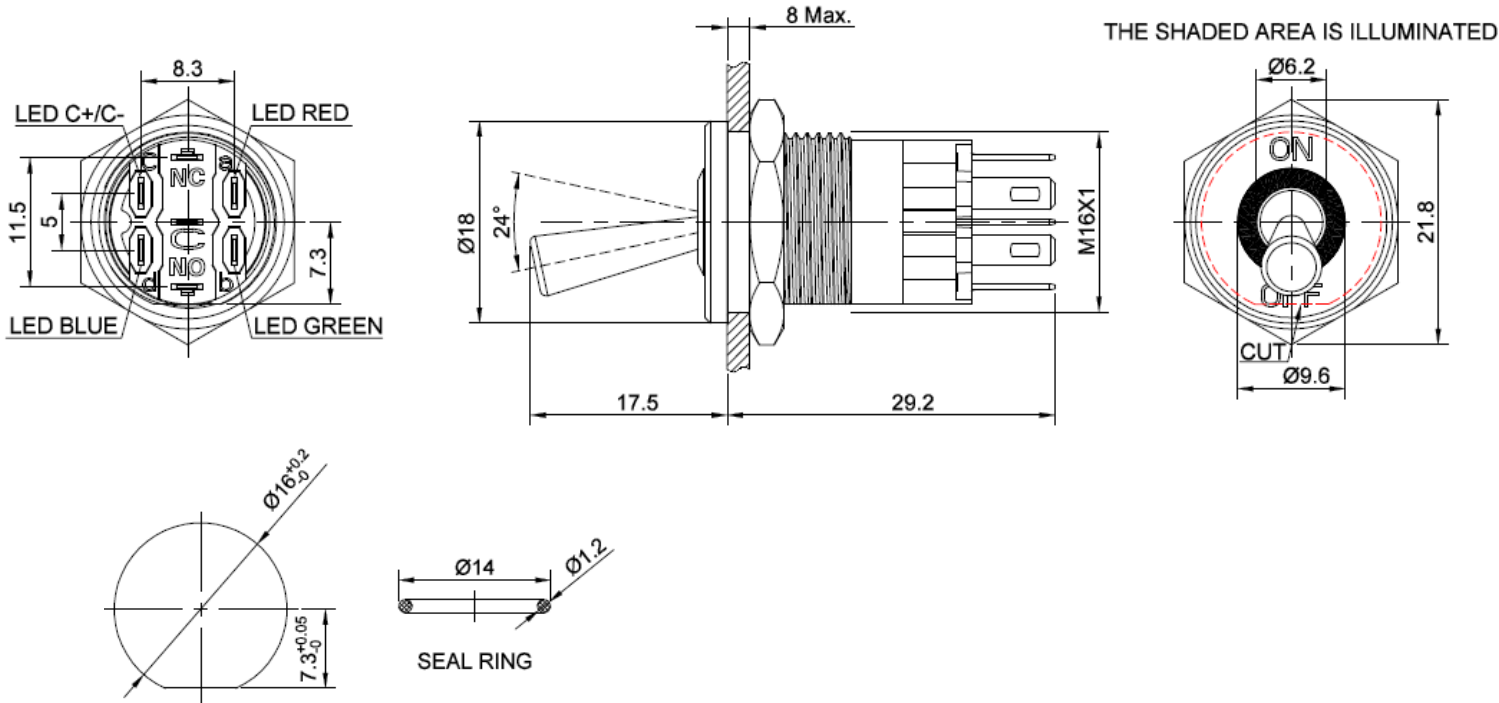

PANEL CUTOUT

8MAX: means the panel thickness, the max thickness for the panel no more than 8mm.

Specification

Switch rating.....	15 A / 250 VAC
Mounting diameter.....	16 mm
Operation type.....	1NO1NC
Operation angle.....	24°
Illumination type	Ring (common cathode RGB 12 V/DC)
Terminal	Pin terminal (2.8 X 0.5 mm)
Operating and storage temperature	-40 to +85 °C (No freezing)
Mechanical life.....	500,000 cycles
Electrical life	50,000 cycles
IP Degree	IP 67
Insulation resistance.....	≥ 100 MΩ (500 V DC)
Transition resistance	≤ 50 mΩ

	Housing Material	Rocker Material
3594604	Stainless steel	Nickel plated brass
3594605	Black plated brass	Black plated brass