


Data Sheet

Panel Jack

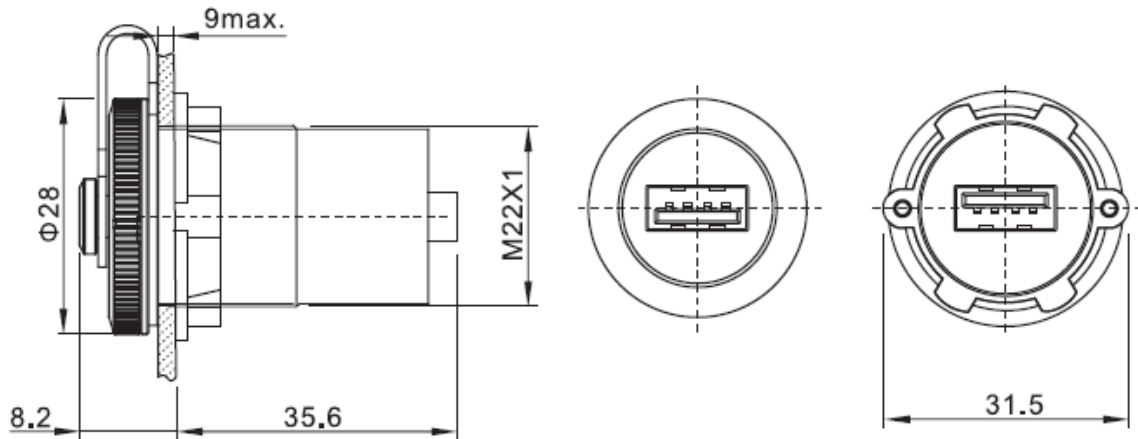

Specification

Type	USB 3.0 female A - female A
Rating	900 mA/5 VDC
Mounting diameter	22 mm
Body material	Aluminium alloy (Natural / Black)
Operating and storage temperature	-20 to +55 °C
Panel thickness	1 ~ 9 mm
IP Degree	IP 67

	Housing color
3594606	Silver
3594607	Black