


Data Sheet

Panel Jack

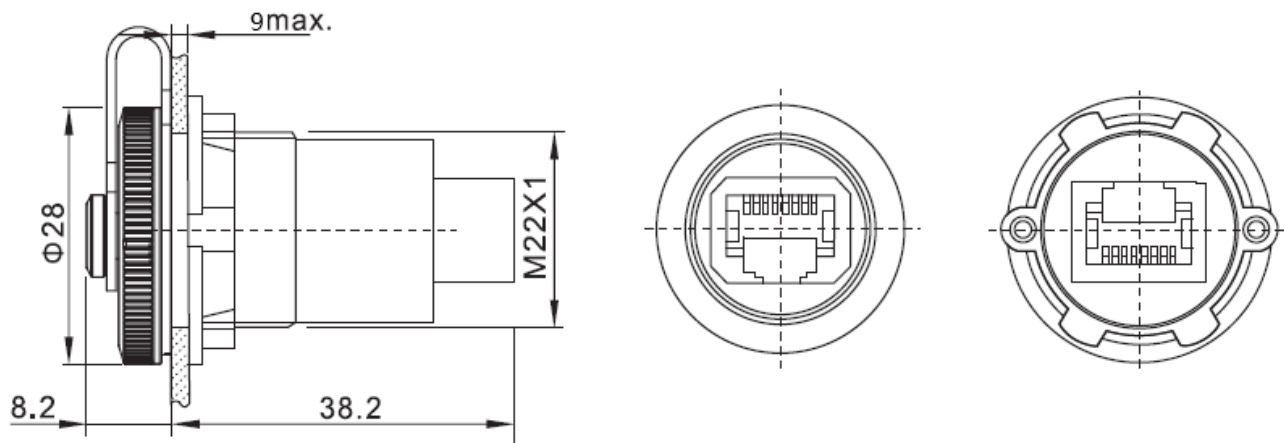

Specification

Type	Front: RJ45 Female - Back: RJ45 Female
Rating	1.5 A/150 VAC
Mounting diameter	22 mm
Body material	Aluminium alloy (Silver / Black)
Operating and storage temperature	-20 to +55 °C
Panel thickness	1 ~ 9 mm
IP degree	IP 67

	Housing color
3594608	Silver
3594610	Black