


Data Sheet

Panel Jack

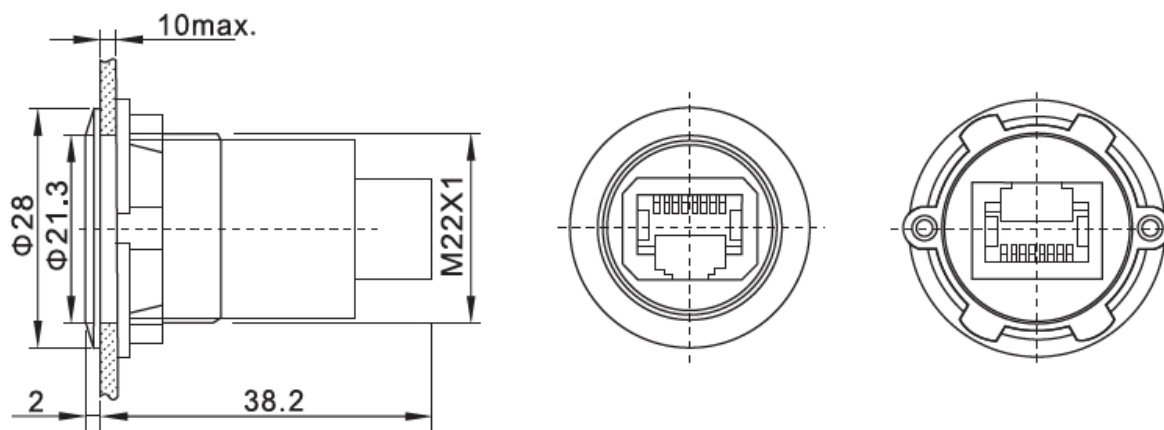

Specification

Type	Front: RJ45 Female - Back: RJ45 Female
Rating	1.5 A/150 VAC
Mounting diameter	22 mm
Body material	Plastic (White / Black)
Operating and storage temperature	-20 to +55 °C
Panel thickness	1 ~ 10 mm

	Housing color
3594611	White
3594609	Black