


Data Sheet

Panel Jack

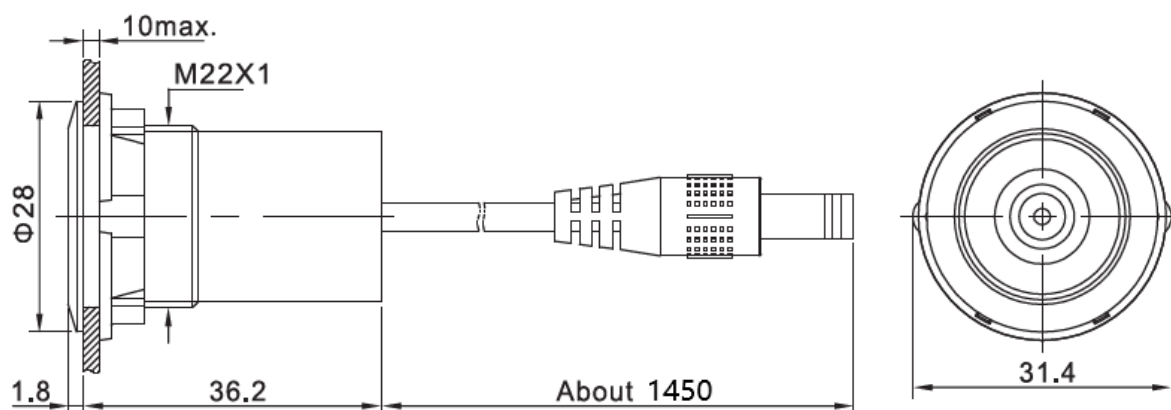

Specification

Type	Power jack Female –Male with 1450 mm wire
Rating	2 A/12 VDC
Mounting diameter	22 mm
Body material	Aluminium alloy (White / Black)
Operating and storage temperature	-20 to +55 °C
Panel thickness	1 ~ 10 mm

	Housing color
3594612	White
3594613	Black