


Item no.: 3594615
 Item no.: 3594617
 Item no.: 3594618
 Item no.: 3594619
 Item no.: 3594620

Data Sheet

Push Button Switch

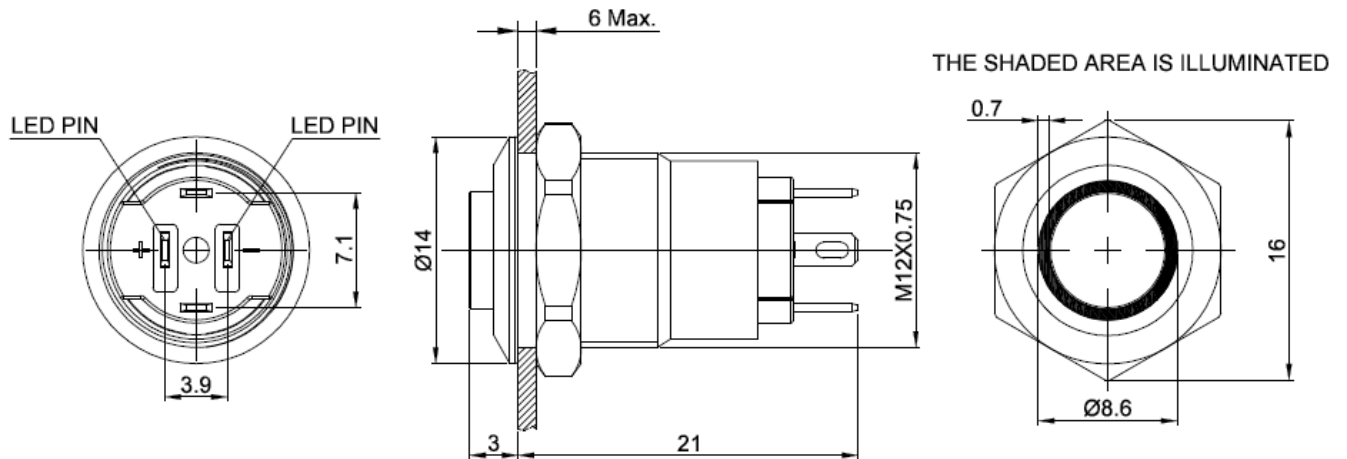

Specification

Switch rating.....	2 A/36 VAC/DC
Mounting diameter.....	12 mm
Head shape	Round raised head
Operation type.....	1NO latching
Illumination type	Ring illumination
LED voltage.....	12 V
Terminal	Pin terminal (2X0.5 mm)
Operating and storage temperature	-25 to +55 °C
Operating and storage humidity	45 - 85 % RH
Material.....	Stainless steel
Mechanical life.....	500,000 cycles
Electrical life	50,000 cycles
Dielectric strength.....	1,500 V, RMS 50 Hz, 1 min.

	LED Color
3594615	Red
3594617	Green
3594618	Blue
3594619	Yellow
3594620	White