

Avide LED Flood Light Slim SMD 2x20W NW 4000K 2 head with Tripod Opt. PIR

Issuer Name:
Issuer Address:

Bramcke Hungary Kft.
4031 Debrecen, Kishatár utca 17.

Date of Issue:
Documentum version:

2026.01.08.
DS2601

BOX PICTURE



BASIC INFORMATION

EAN	5999143209003
Product code	ABLRFLNW-20W-TRIPOD-D-OPIR
Brand link	-
Packaging	1
Warranty	3year(s)
Certifications	-

DIMENSION INFORMATION

Height	610mm
Width	130mm
Depth	110mm

TECHNICAL DETAILS

Wattage	40W
Technology	LED
energy class	F
Lumen	4,000lm
Lumen/Watt	100
type of chip	SMD2835
Voltage range	AC220-240V
Beam angle	110°
CRI	80
Colour temperature	4,000K
adjustable colour temperature	N
Dimmable	N
Built-in battery	-
Battery type	-
Charging time	-
IP class	IP65
Material	Aluminum + frosted glass
Color	Black
Life span (hours)	25,000h

PRODUCT PICTURE



Avide LED Flood Light Slim SMD 2x20W NW 4000K 2 head with Tripod Opt. PIR

Issuer Name:

Bramcke Hungary Kft.

Date of Issue:

2026.01.08.

Issuer Address:

4031 Debrecen, Kishatár utca 17.


Documentum version:

DS2601

PACKAGING INFORMATION

	Box	Carton
EAN	5999143209003	5999143209010
Size	-	-
Net weight	2750gram	11kg
Gross weight	3050gram	11.6kg
Packaging	1	4

OUTLINE

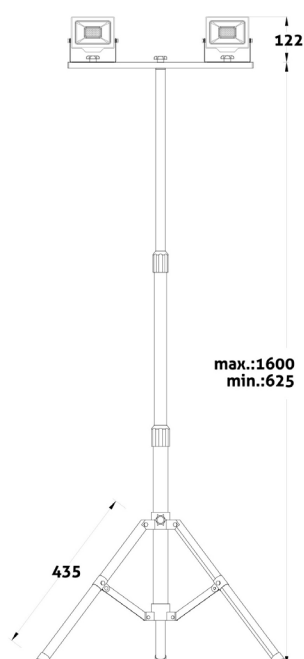

PHOTOMETRY INFORMATION