

DATASHEET


Adapter

Technical data

Material Insulation	PVC
Contact	Copper
Voltage Rating	250 V/AC
Current Rating	10 A
Contact Resistance	<20 mΩ
Insulating Resistance	>50 MΩ
Operating Temperature.....	-5 to +55 °C
Storage Temperature.....	-20 to +60 °C


Item no.	Type	Dimensions (W x H x D) (approx.) (mm)
3638578	IEC C14 to IEC C13, 90° right angle	46 x 55 x 29
3638579	CEE 7/7 Male plug to IEC C13, 90° angled	59 x 64 x 36
3638580	IEC C14 to IEC C13, 90° upward right angle	40 x 44 x 29
3638581	IEC C13 to IEC C14, 90° right angle	46 x 55 x 21
3638582	CEE 7/7 male plug to IEC C13, straight	36 x 74 x 36

Item no.: 3638578

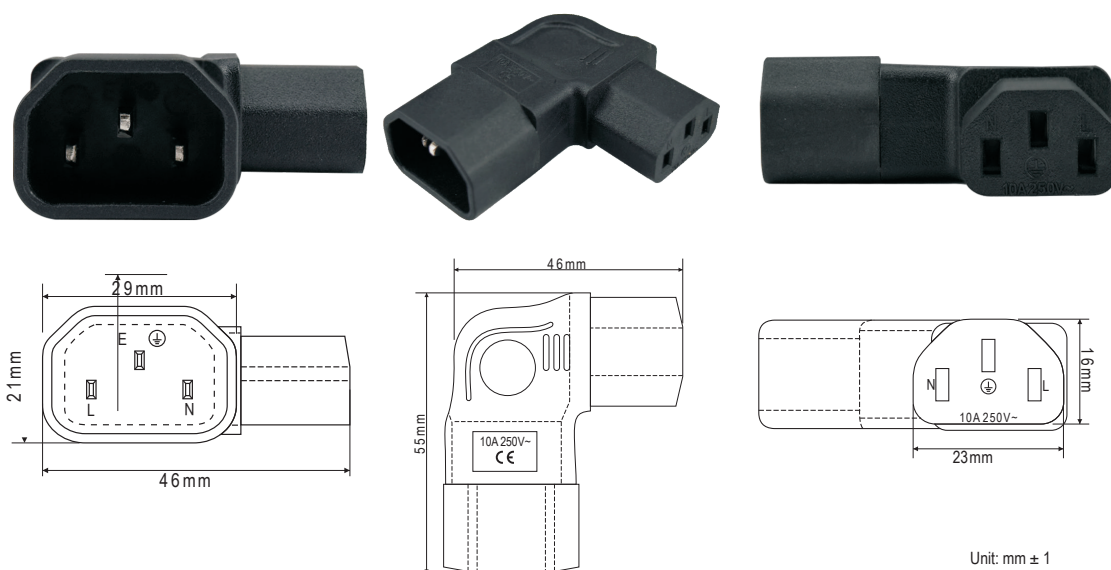





Item no.: 3638579

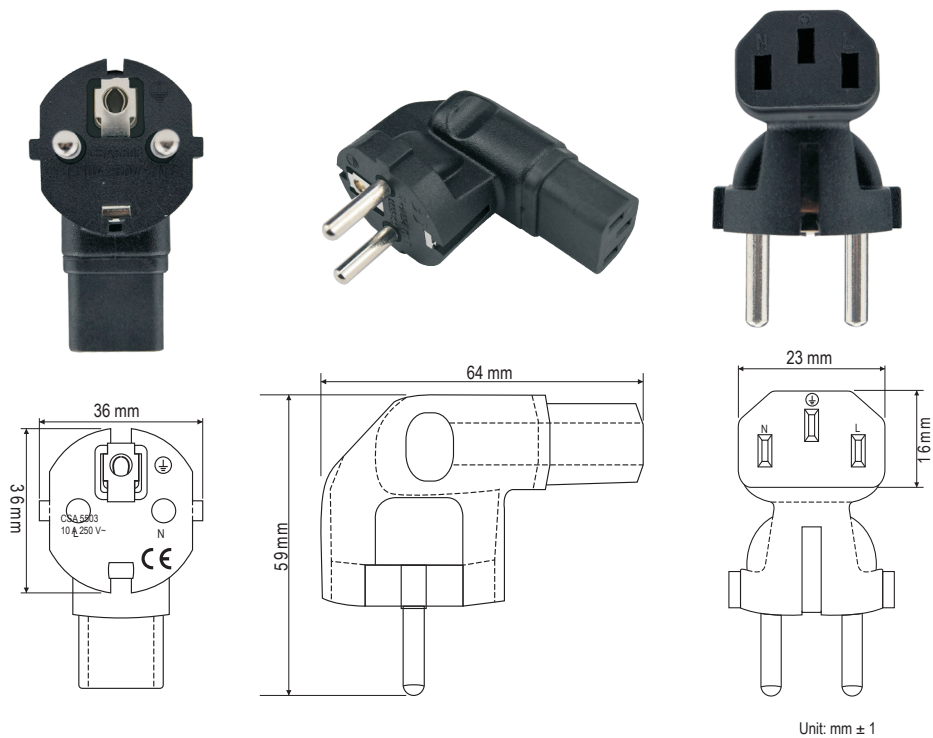

Item no.: 3638580

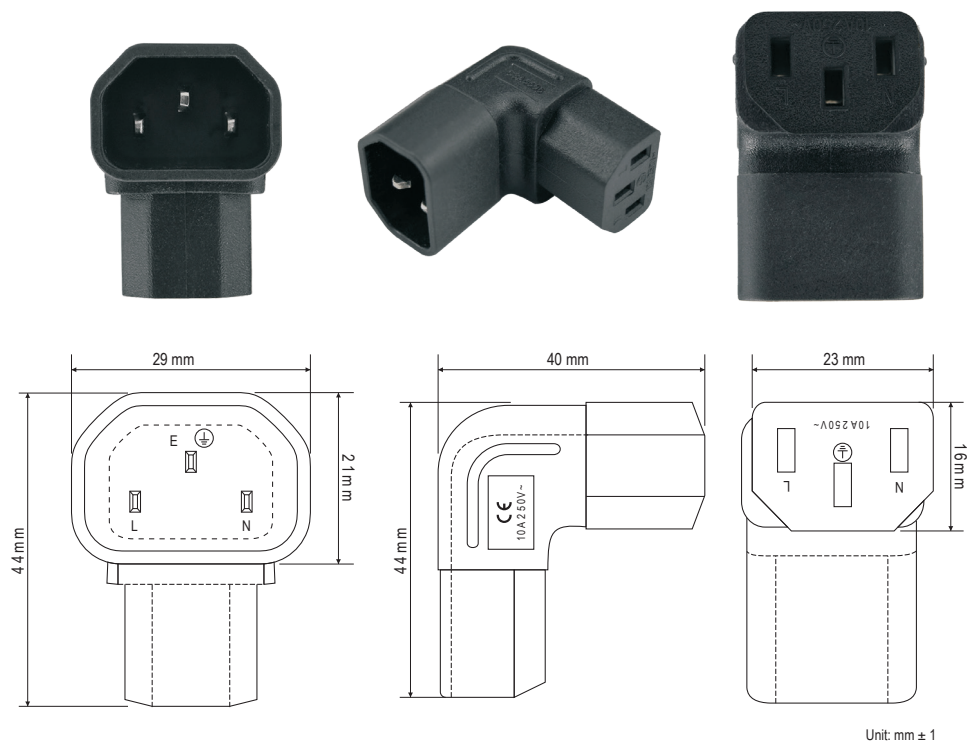

Item no.: 3638581

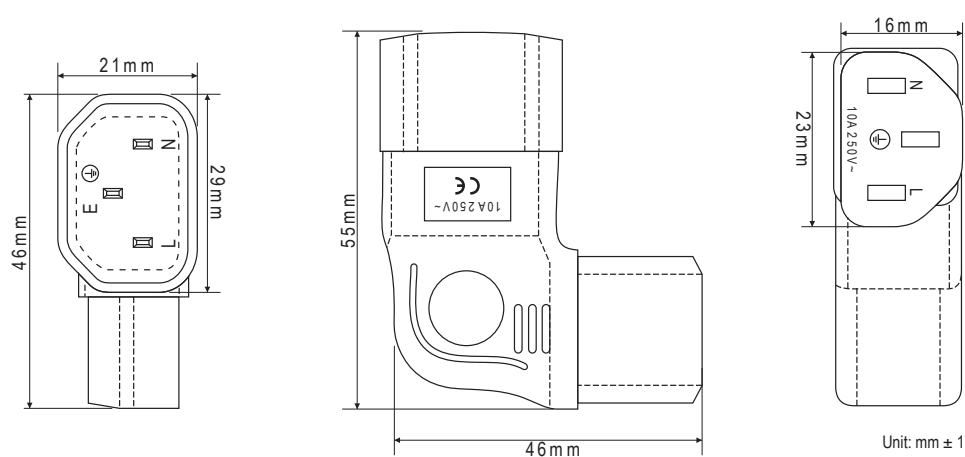

Item no.: 3638582

