


- **Style:** Simple
- **Size:** Mid Tower case supports up to ATX MB
- **Material:** Steel & Tempered Glass

Main Features

- **Connection :** Front I/O ports with 2 x USB 3.0 & 1 x USB 3.2 (Gen 2) Type C
- **Cooling Solution :** Pre-installed
 - 1 x SF360 ARGB PWM Reverse Fan
 - 1 x SF120 ARGB PWM Fan
- **Support:** 360mm AIO cooling solutions

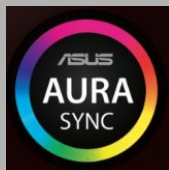

Specification

Model	S380 TG ARGB	S380 TG ARGB Snow
P/N	CA-11K-00M1WN-00	CA-11K-00M6WN-00
Color	Black	White
Case Type	Mid Tower	
Chassis Dimension (H*W*D)	536 x 238 x 485mm (21.1x 9.37 x 19.1inch)	
Side Panel Material	4mm Tempered Glass x 1	
Cooling System	Power Cover (intake): 360 x 120 x 25 mm SF360 ARGB PWM Reverse Fan (500~1800rpm, 36.7 dBA) x 1 Rear(exhaust): 120 x 120 x 25 mm SF120 ARGB PWM Fan (500~1800rpm, 31.2 dBA) x 1	Power Cover (intake): 360 x 120 x 25 mm SF360 ARGB PWM Reverse white Fan (500~1800rpm, 36.7 dBA) x 1 Rear(exhaust): 120 x 120 x 25 mm SF120 ARGB PWM white Fan (500~1800rpm, 31.2 dBA) x 1
Drive Bays	2 x 3.5"+2 x 2.5" or 1 x 3.5" + 3 x 2.5"	
Expansion Slots	7	
Motherboards	6.7" x 6.7" (Mini ITX), 9.6" x 9.6" (Micro ATX), 12" x 9.6" (ATX)	
Hidden-Connector Motherboard	9.6" x 9.6" (Micro ATX), 12" x 9.6" (ATX)	
I/O Port	USB 3.2 (Gen 2) Type-C x 1, USB 3.0 x 2, HD Audio x 1	
PSU	Standard PS2 PSU (optional)	
Fan Support	Top: 3 x 120mm, 2 x 120mm, 1 x 120mm 2 x 140mm, 1 x 140mm Front: 3 x 120mm, 2 x 120mm, 1 x 120mm 3 x 140 mm, 2 x 140mm, 1 x 140mm Rear: 1 x 120mm 1 x 140mm Power Cover: 3 x 120mm, 2 x 120mm, 1 x 120mm	
Radiator Support	Top Side(AIO) : 1 x 360mm, 1 x 240mm, 1 x 120mm 1 x 280mm, 1 x 140mm Front Side(AIO) : 1 x 360mm, 1 x 240mm, 1 x 120mm 1 x 280mm, 1 x 140mm Rear Side(AIO): 1 x 120mm	
Clearance	CPU cooler height limitation: 180mm VGA length limitation: 400mm PSU length limitation: 200mm	


Packaging

Package Information	S380 TG ARGB	S380 TG ARGB Snow
P/N	CA-11K-00M1WN-00	CA-11K-00M6WN-00
EAN Code	4711658544568	4711658544575
UPC Code	840480304560	840480304577
N.W	9.76kg/21.52 lbs	
G.W	11.67kg/25.73 lbs	
Carton Size (L x W x H)	594 x 308 x 543 mm / 23.39 x 12.13 x 21.38 inch	
Cuft	3.5	
Container	w/o pallet	
20'	240 pcs	
40'	533 pcs	
40' HQ	653 pcs	


Appearance - Black version




Angle view

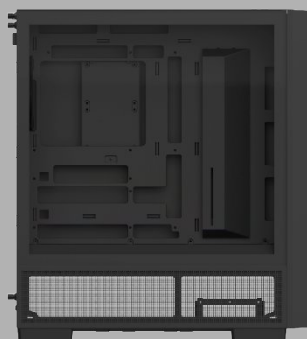


Left Side view

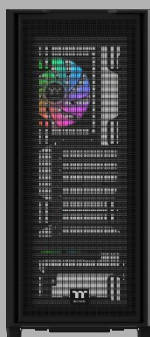

Front view

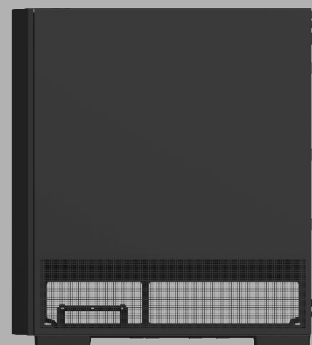


Right Side view

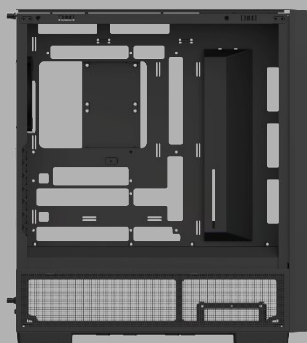

Internal Structure




Rear view

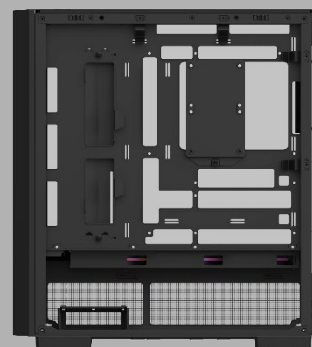

Internal Structure



Top view

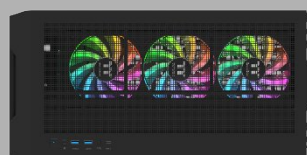


Bottom view


Appearance - Snow version




Angle view

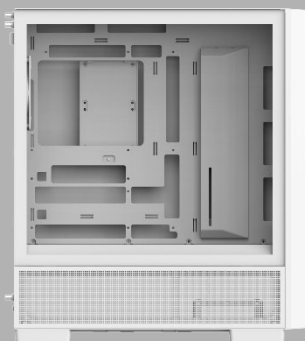


Left Side view

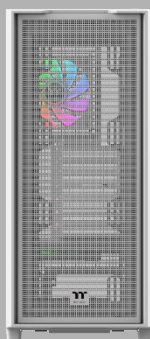

Front view

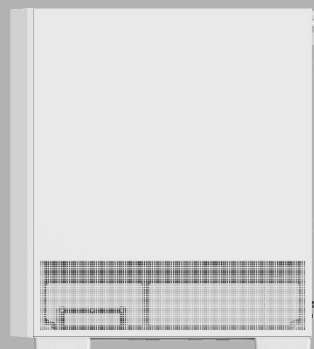


Right Side view

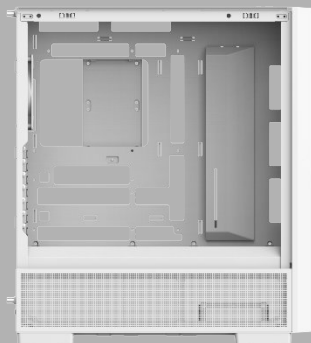

Internal Structure




Rear view

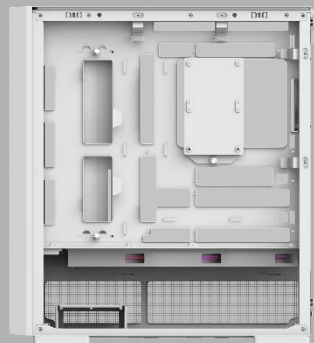


Internal Structure



Top view

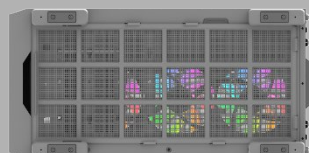

Bottom view

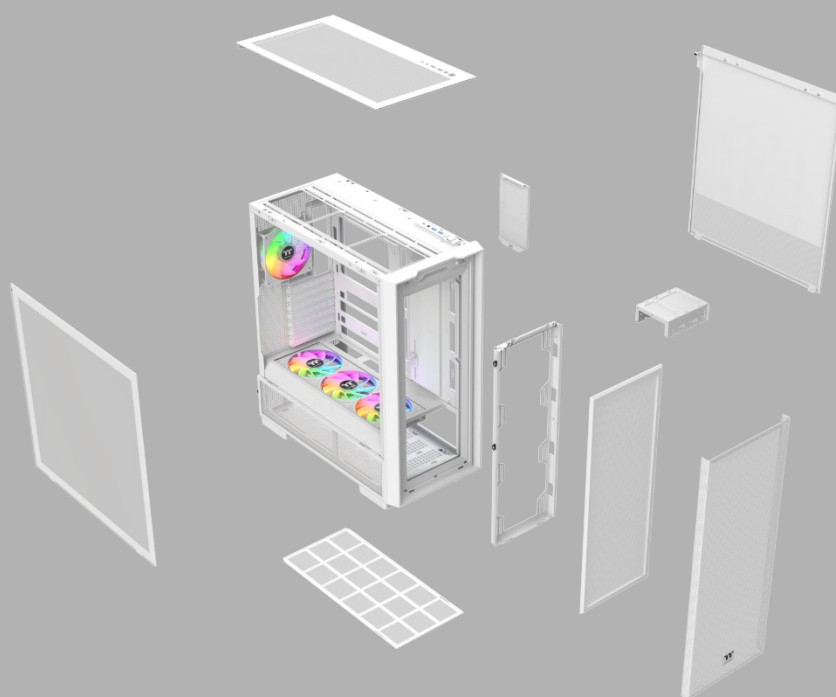

Pre-installed Fan



Black Version



Snow Version

Pre-installed hydraulic bearing **SF360 ARGB PWM Reverse Fan** & **SF120 ARGB PWM Fan** which can effectively lower the operation noise and enhance the thermal efficiency.

SPEC for Case **SF360 ARGB PWM Reverse Fan**


- Fan Speed: 500-1800±10%RPM
- Max. Fan Airflow: 173.96 CFM
- Max. Fan Air Pressure: 1.8 MM-H2O
 - Fan Noise Level: 36.4 dB-A
 - Fan Bearing: Hydraulic bearing

SPEC for Case **SF120 ARGB PWM Fan**

- Fan Speed: 500-1800±10%RPM
- Max. Fan Airflow: 58.7 CFM
- Max. Fan Air Pressure: 2.02 MM-H2O
 - Fan Noise Level: 29.3 dB-A
 - Fan Bearing: Hydraulic bearing

Fan Compatibility

Fan Compatibility List			
	120mm	140mm	200mm
Top	3	2	-
Front	3	3	-
Rear	1	1	-
Power Cover	3	-	-

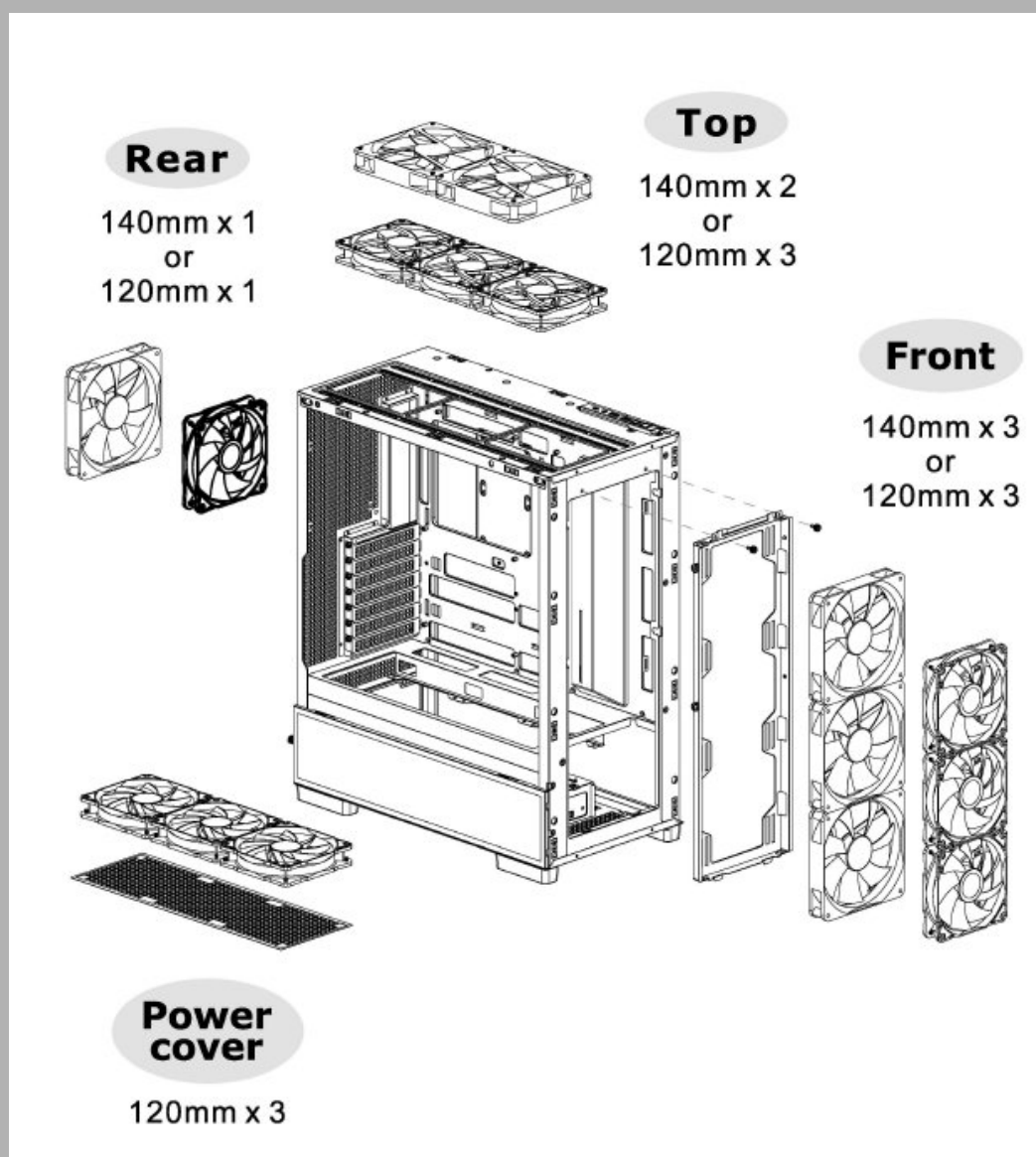

All-in-One Compatibility

All-in-One Compatibility List						
	120mm	240mm	360mm	140mm	280mm	420mm
Top	●	●	●	●	●	-
Front	●	●	●	●	●	-
Rear	●	-	-	-	-	-

