

DATASHEET

Waterproof Junction box, IP68

Technical data

Item no.	Inlets	Nut Size	Rated Output	Wire Range (Cross-Sectional)	Outer cable diameter	Dimensions (W x H x D)
3686318	3	M20	450VAC 24A	0.5 - 2.5 mm ²	4 - 8 / 6 - 11 mm	161.74 x 37.98 x 80.07 mm
3686319	2	M20	450VAC 24A	0.5 - 2.5 mm ²	4 - 8 / 6 - 11 mm	161.74 x 37.98 x 80.07 mm
3686320	4	M20	450VAC 24A	0.5 - 2.5 mm ²	4 - 8 / 6 - 11 mm	161.74 x 37.98 x 80.07 mm
3686321	5	M20	450VAC 24A	0.5 - 2.5 mm ²	4 - 8 / 6 - 11 mm	161.74 x 37.98 x 80.07 mm
3686322	3	M25	450VAC 24A	0.5 - 4.0 mm ²	4-8 / 8-12 / 10-14 mm	130.14 x 35.3 x 80.5 mm
3686323	4	M25	450VAC 24A	0.5 - 4.0 mm ²	4-8 / 8-12 / 10-14 mm	163.13 x 59.39 x 151.6 mm

Protection classIP68

Material.....Fire and flame retardant UL94V-2

Terminal block.....PA10


ColorBlack

Operating temperature-40 to +105 °C

Features


- Built-in rubber ring and clamping nut
- IP68
- UL94V-2

Item no.: 3686318

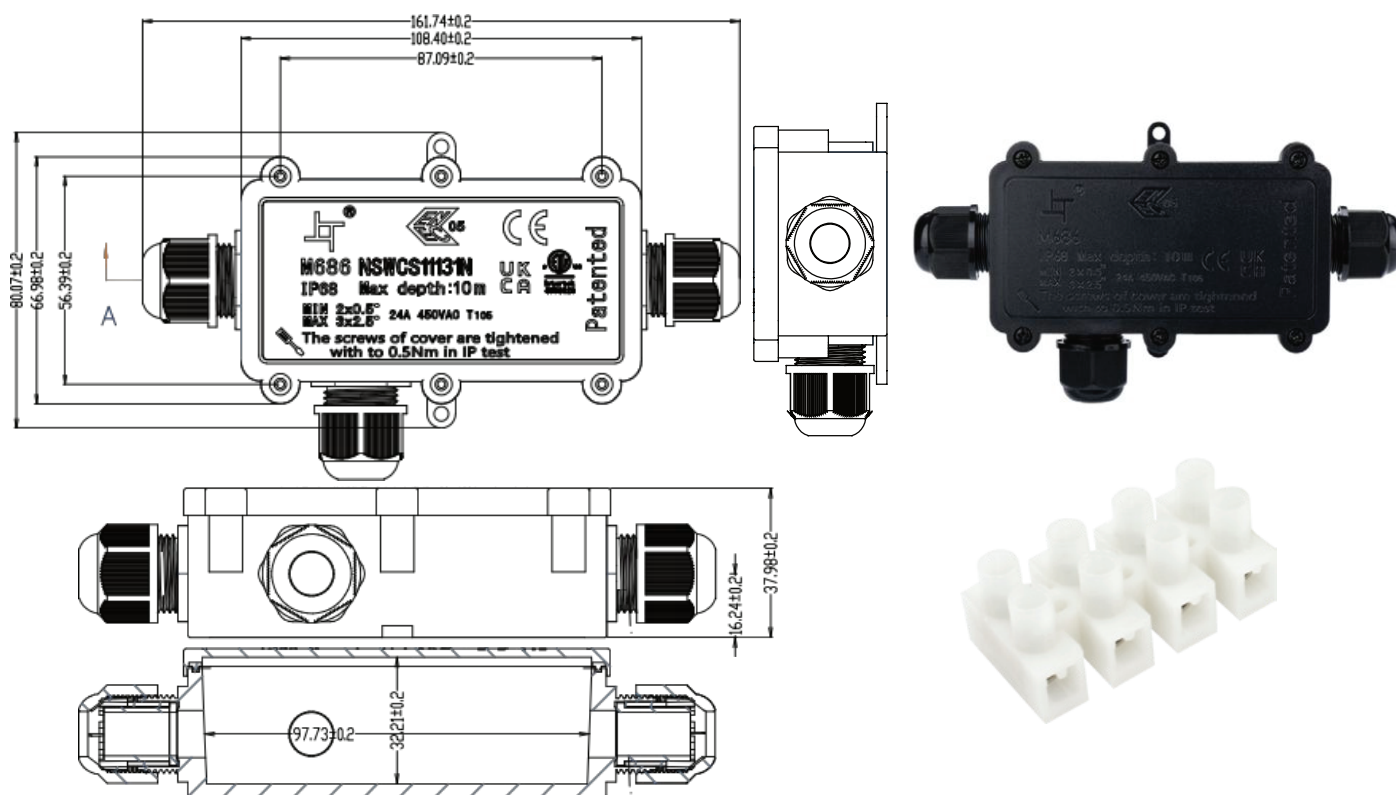


All measurements in mm

Item no.: 3686319

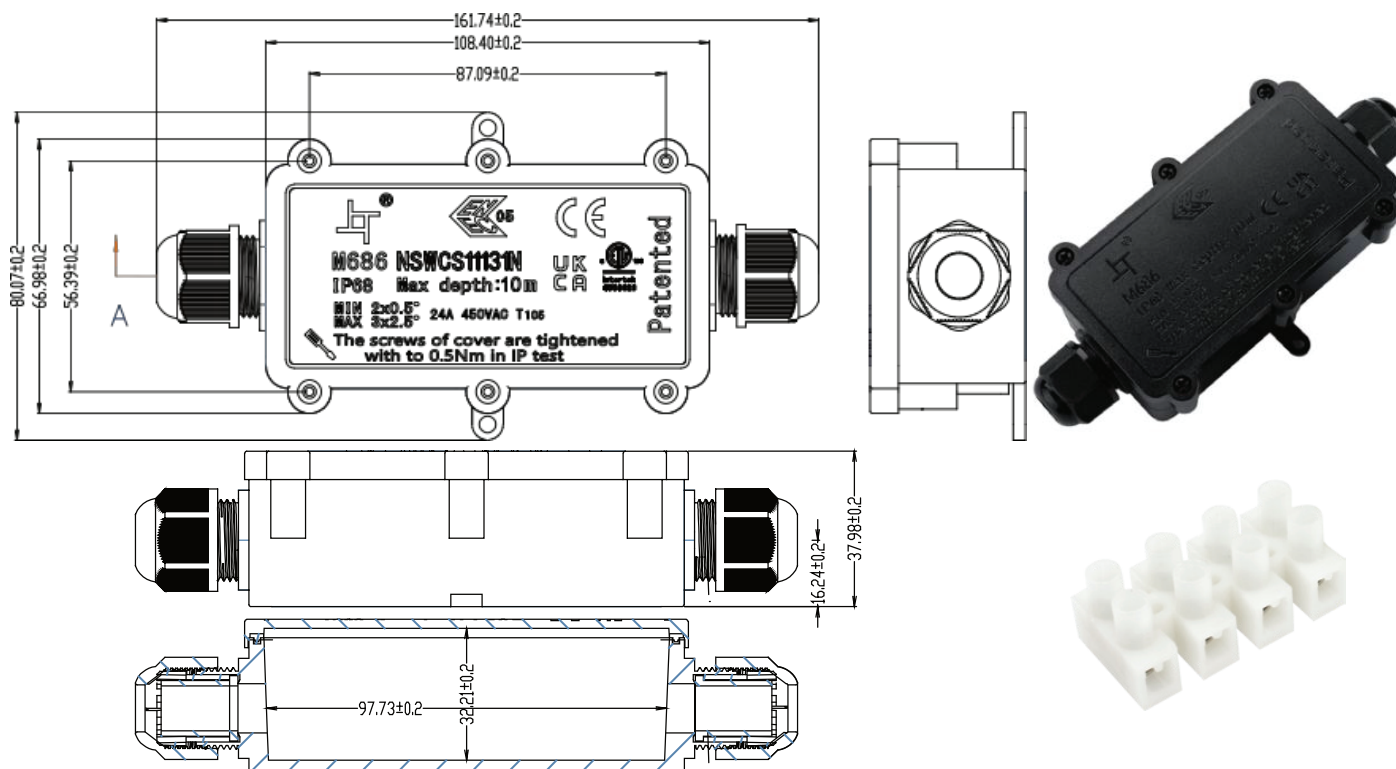


All measurements in mm

Item no.: 3686320

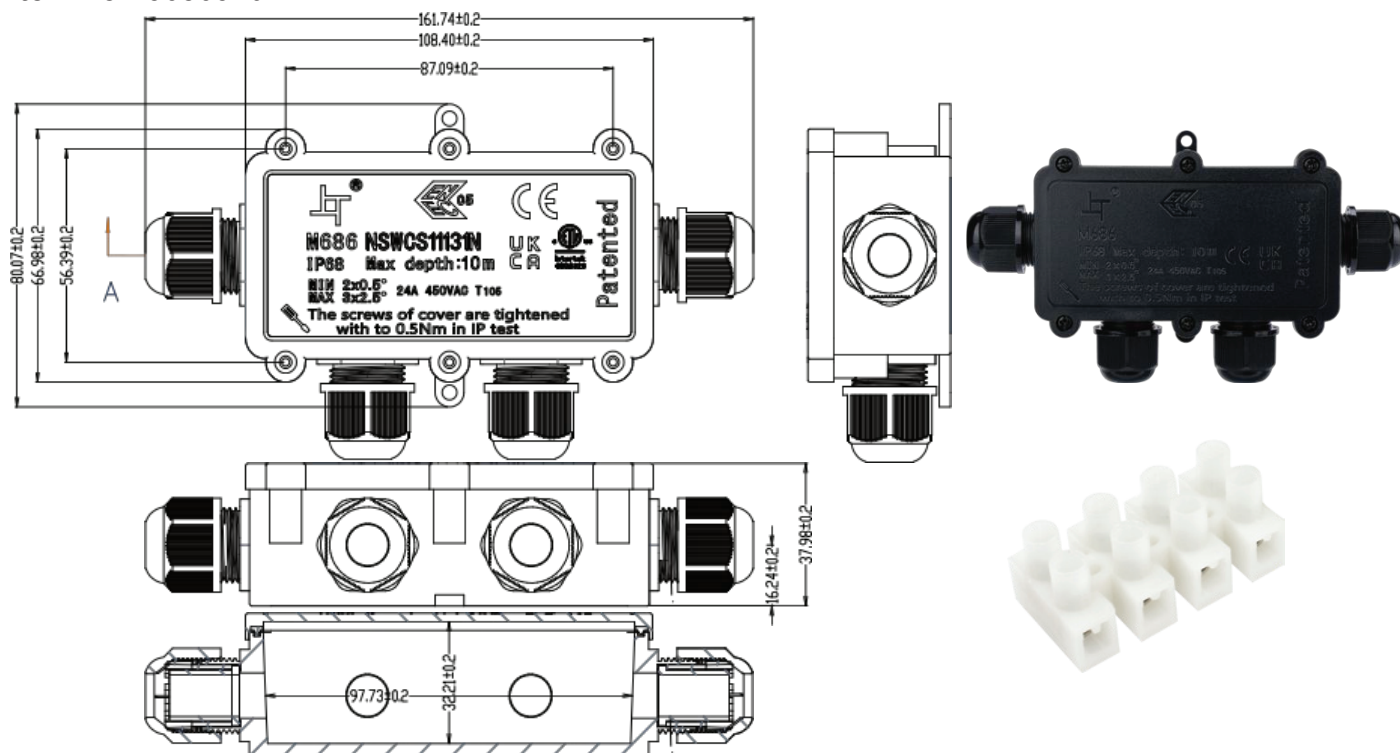


All measurements in mm

Item no.: 3686321

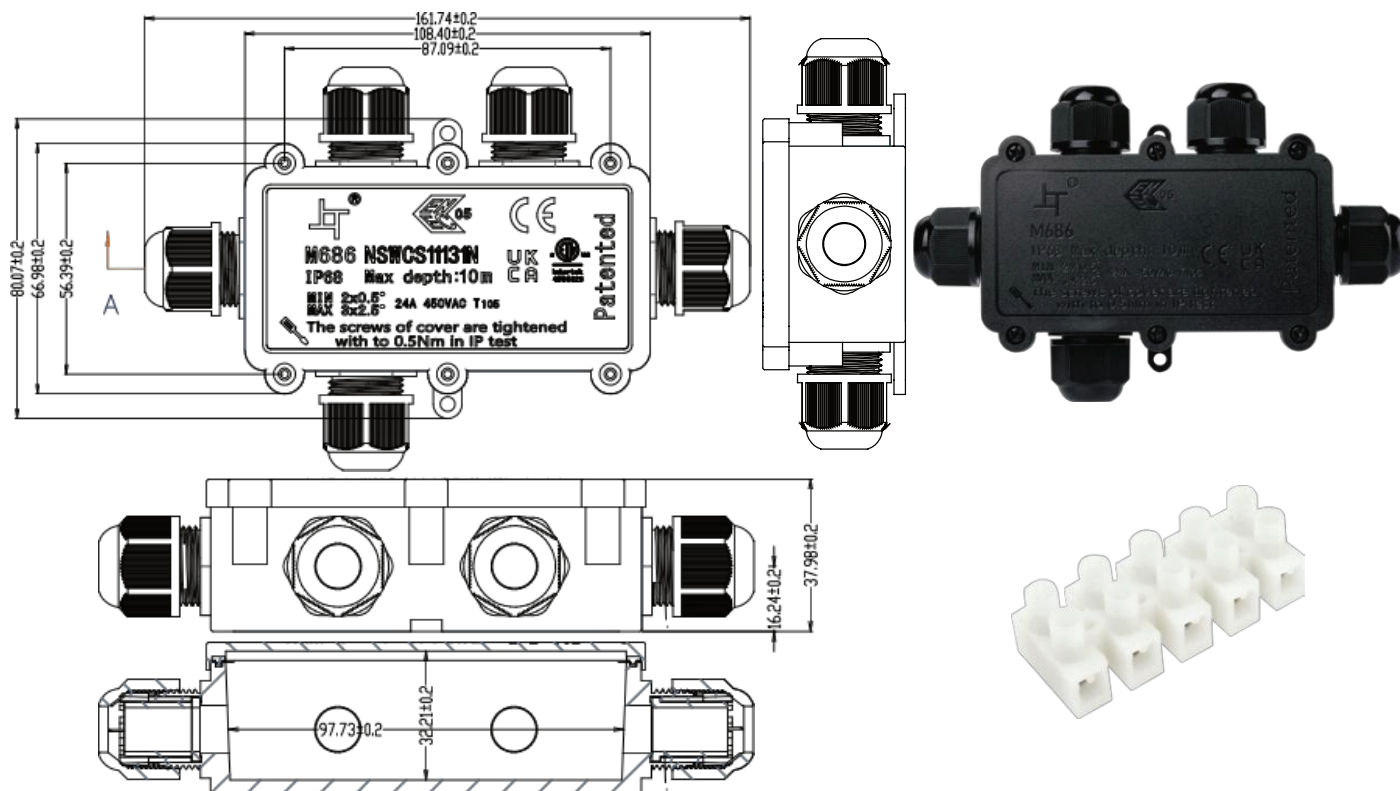

All measurements in mm

Item no.: 3686322

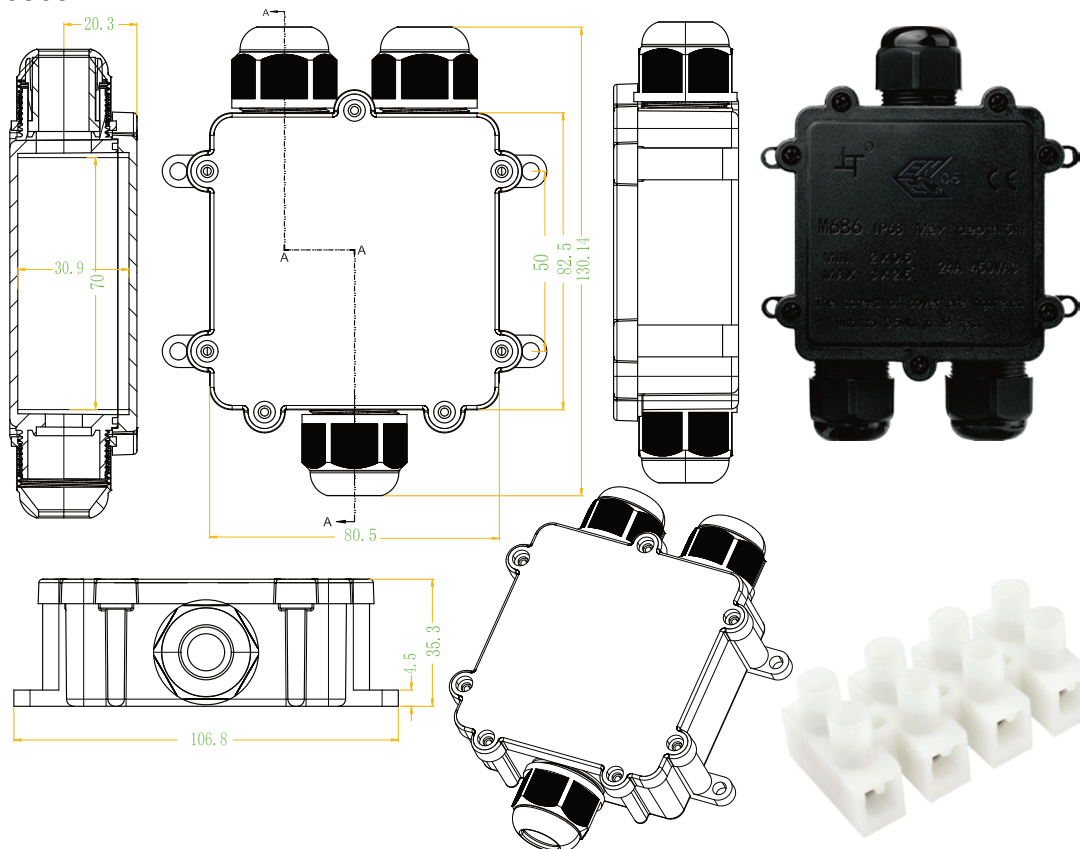

All measurements in mm

Item no.: 3686323

