

DATASHEET

Rubber Seal Plug

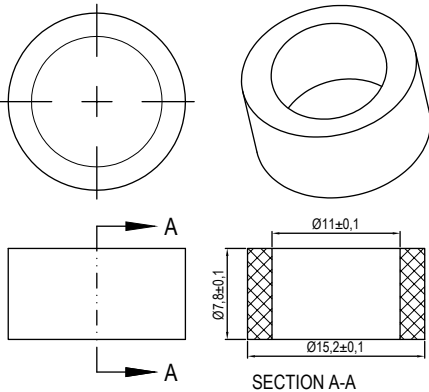
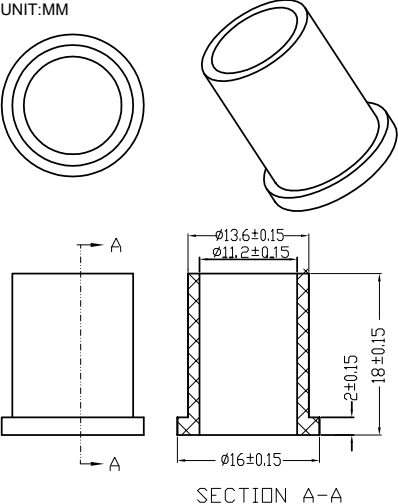
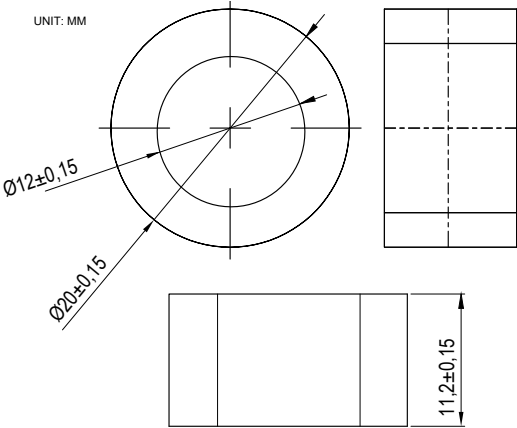
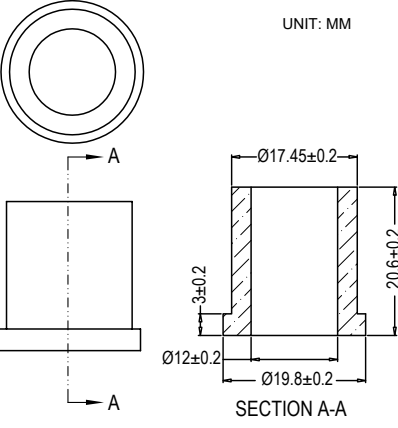
Technical data

Item no.	Type	Nut Size	Cable diameter (mm)	Inner Ø (mm)	Outer Ø (mm)	H (mm)
3686324	Flat	M20	6 - 11	11	15.2	7.8
3686325	Step	M20	6 - 11	11.2	13.6	18
3686326	Flat	M25	8 - 12	12	20	11.2
3686327	Step	M25	8 - 12	17.45	19.8	20.6
3686328	Flat	M25	10 - 14	14	20	11.2
3686329	Step	M25	10 - 14	14	17.45	20.6

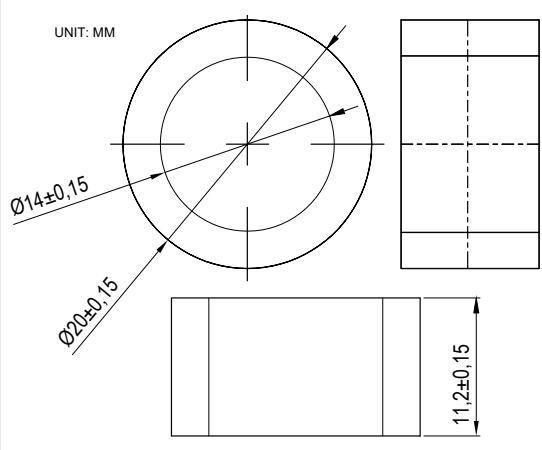
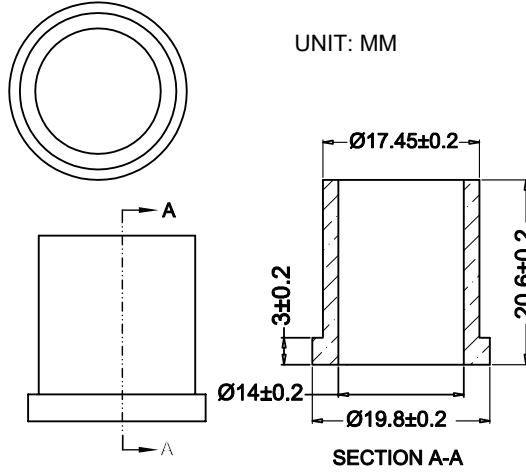
Material.....Silicone

Color.....Yellow

Hardness.....55 - 60

Item no.: 3686324 UNIT: MM  SECTION A-A	Item no.: 3686325 UNIT:MM  SECTION A-A
Item no.: 3686326 UNIT: MM  SECTION A-A	Item no.: 3686327 UNIT: MM  SECTION A-A



Item no.: 3686328	Item no.: 3686329
UNIT: MM 	UNIT: MM  SECTION A-A