


Hook & Loop Tape with Triangle-Buckle/Eyelet Item-No.: 26CA799 ... 26CA806

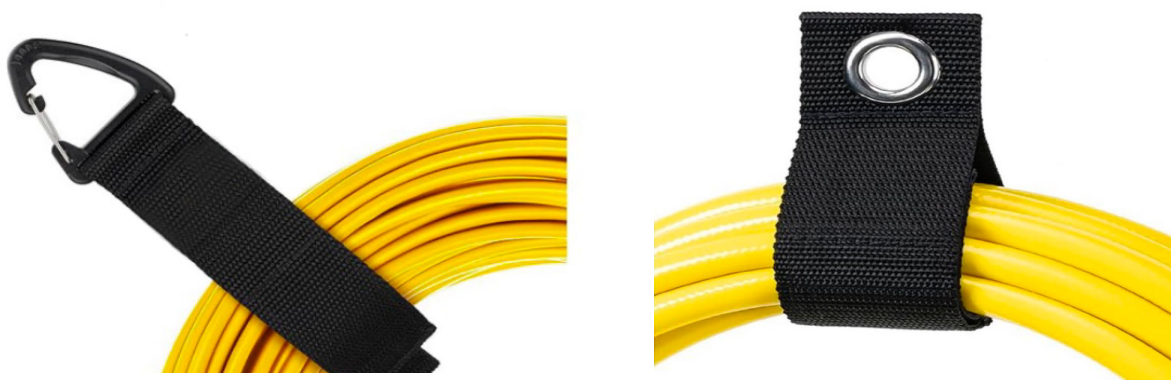

The cable tie, available in two different versions, is an innovative way to flexibly guide and fasten cables, wires, and hoses - or to hang objects in general. Thanks to its sturdy construction and reliable hook-and-loop fastener, even heavier objects can be carried, depending on the overlap of the hook-and-loop surface, even up to 20 kg without any problems!

Polyamide as the strap material ensures mechanical and climatic stability and is very easy to care for. Other areas of application include securing objects, tools, sports equipment, water hoses, drinking bottles, bags, and much more.

Technical Specifications

Material: Polyamide • Color: Black • Fastening type: Carabiner clasp or eyelet • Maximum bundle diameter: 100 - 150 mm • Length: 320 - 480 mm • Width (strap): 38 mm, 50 mm • Color: Black • RoHS & REACH compliant • Set of 6 pcs.

Item-No.	Description	Fastening type	Bundle-Ø	Length	Width	Content	EAN / GTIN
26CA799	H&L cable ties with carabiner fastener Ø 100 mm Set	Carabiner clasp	100 mm	330 mm	38 mm	6 pcs.	4262511626094
26CA800	H&L cable ties with carabiner fastener Ø 125 mm Set	Carabiner clasp	125 mm	390 mm	38 mm	6 pcs.	4262511626100
26CA801	H&L cable ties with carabiner fastener Ø 150 mm Set	Carabiner clasp	150 mm	480 mm	38 mm	6 pcs.	4262511626117
26CA802	H&L cable ties with carabiner fastener Ø 100 / 125 / 150 mm Set	Carabiner clasp	100 mm 125 mm 150 mm	330 mm (2x) 390 mm (2x) 480 mm (2x)	38 mm	6 pcs. (2/Ø)	4262511626124
26CA803	H&L cable ties with eyelet Ø 100 mm Set	Eyelet	100 mm	320 mm	50 mm	6 pcs.	4262511626131
26CA804	H&L cable ties with eyelet Ø 125 mm Set	Eyelet	125 mm	420 mm	50 mm	6 pcs.	4262511626148
26CA805	H&L cable ties with eyelet Ø 150 mm Set	Eyelet	150 mm	470 mm	50 mm	6 pcs.	4262511626155
26CA806	H&L cable ties with eyelet Ø 100 / 125 / 150 mm Set	Eyelet	100 mm 125 mm 150 mm	320 mm (2x) 420 mm (2x) 470 mm (2x)	50 mm	6 pcs. (2/Ø)	4262511626162