

VOLTCRAFT - RELIABLE AND PRECISE. SINCE 1982.

For decades, our product range has been dynamically adapting to the constant changes in the industry.

We commit to offering first-class quality to our customers while delivering an excellent cost-performance ratio. This philosophy remains the cornerstone of Voltcraft's success.

LiMnO₂ Rechargeable Button Cell




Item No.:	Pack
3737822	100 pcs
2542815	1 pc

TECHNICAL DATA

Type:	ML2032
Classification:	Rechargeable
Charging cycles	≤400
Chemical system:	Lithium/Manganese Dioxide (Li/MnO ₂)
Nominal voltage:	3.0 V
Weight (approx.)	3.2 g
Capacity:	65 mAh
Cut-off voltage:	2.0 V
Discharge current:	200 µA
Operating conditions:	-20 to +70 °C
Storage conditions:	0 to +30 °C, 35 ± 75 % RH

For performance and safety, observe the operating / storage conditions. Capacity varies depending on the applied load, temperature, and cut-off voltage.

DIMENSIONS

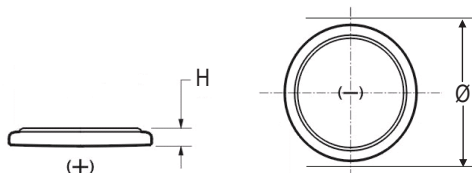

Dimension	mm.
Ø	20 (±0.2)
H	3.2 (±0.3)

