

VOLTCRAFT

VOLTCRAFT - RELIABLE AND PRECISE. SINCE 1982.

For decades, our product range has been dynamically adapting to the constant changes in the industry.

We commit to offering first-class quality to our customers while delivering an excellent cost-performance ratio. This philosophy remains the cornerstone of Voltcraft's success.

Lithium Rechargeable Button Cell



Item No.:	Pack
3737823	100 pcs
2542816	1 pc




TECHNICAL DATA


Type:	LIR2032
Classification:	Rechargeable
Charging cycles	≤400
Chemical system:	Lithium
Nominal voltage:	3.6 V
Weight (approx.)	2.6 g
Capacity:	45 mAh
Cut-off voltage:	3.0 V
Operating conditions:	-20 to +60 °C, 35 to 75 % RH
Storage conditions:	0 to +30 °C, 35 to 75 % RH

For performance and safety, observe the operating / storage conditions. Capacity varies depending on the applied load, temperature, and cut-off voltage.


TEMPERATURE CHARACTERISTICS

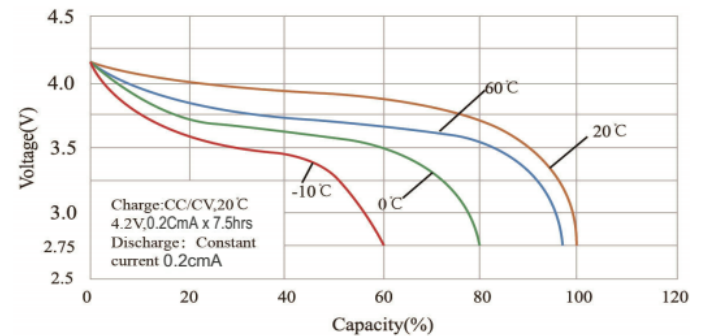


STORAGE CHARACTERISTICS

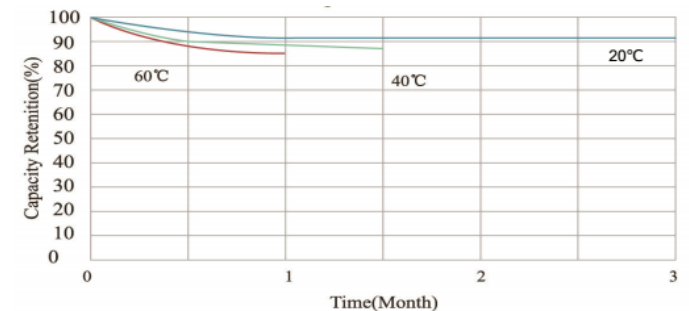


CHARGING CHARACTERISTICS

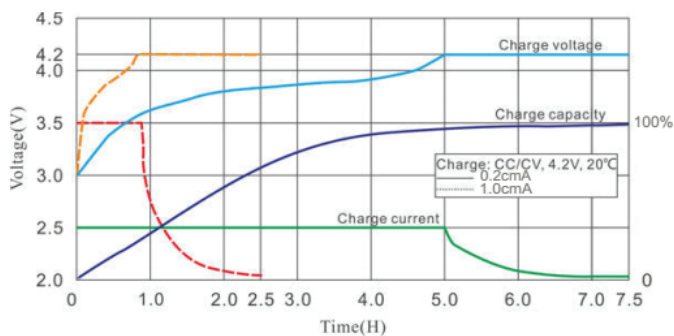


CYCLE LIFE CHARACTERISTICS

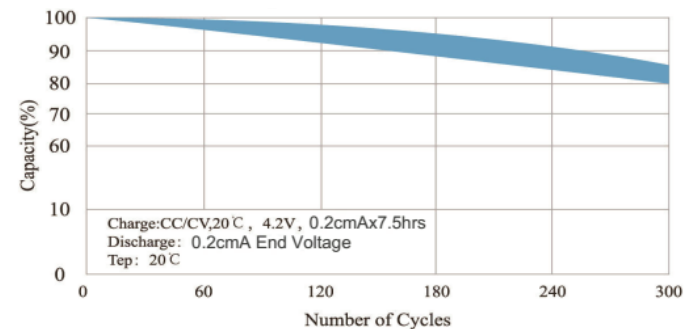

DISCHARGE CHARACTERISTICS

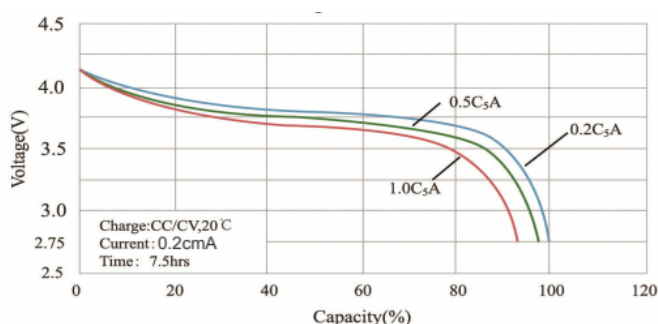

DIMENSIONS

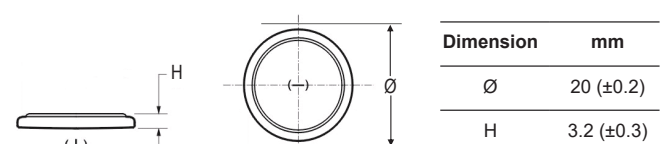

Dimension	mm
Ø	20 (±0.2)
H	3.2 (±0.3)