

66.6mm

94.5mm



HJB-172
denver.eu

01/2026



FR
Cet appareil et ses accessoires sont recyclables



À DÉPOSER EN MAGASIN



OU



À DÉPOSER EN DÉCHÈTERIE

Points de collecte sur www.quefaire-demandedechets.fr
Privilégiez la réparation ou le don de votre appareil !

SAFETY INSTRUCTIONS

Please read the safety instructions carefully before using the product for the first time and keep the instructions for future reference.

- Warning: This product has a built-in lithium polymer battery.
- Do not expose this product to rain or damp conditions. Product is not waterproof.
- Never use dust blower on sharp elements such as broken glass.
- Keep the product out of reach of children and pets to avoid chewing and swallowing.
- Prevent this item from falling as it could cause serious damage.
- Product operating and storage temperature is from 0 degrees Celsius to 40 degrees Celsius. Under and over this temperature might affect the function.
- Never open the product battery compartment. Touching the inside electronics can cause electric shock. Repairs or service should only be performed by qualified personnel.
- Do not place this item near sources of water or expose to direct sunlight.
- Do not use non-original accessories together with the product as this can make the product functionality abnormal.

ENG 1

PRODUCT DESCRIPTION



- On/off button
- USB-C Charging port
- Digital display screen
- Air outlet
- Short air blowing Nozzle head
- Flashlight
- Flashlight Switch button
- Long air blowing Nozzle head

CONTROL KEY FUNCTIONS

ON/OFF Button

Press & Hold: Power on
Press Once: From L1 to L5 Wind Speed Level
Press twice in a row: Max. Wind Speed Mode
Press & Hold Again: Power OFF

Flashlight Switch Button

Press Once: Flashlight ON
Press Once again: Flashlight OFF

ENG 2

Charging:

Use the provided USB-C charging cable to charge the product. Connect one end of the cable to a suitable power supply and the other end to the product's USB-C charging port. During charging, the display will sequentially show numbers from 0 to 100, indicating a full charge when it reaches 100.


Important note: The product must be fully charged to function properly. If the product's power is very low, the blowing effect won't be as effective.

Installation and Operation:
Attach the blowing head to the jet blower by turning it to the left on a specific place on the head until you feel it go into place.
Press and hold the On/Off button to turn it on.

Press the On/Off button briefly to cycle through the five different wind speeds (L1-L5).

Press twice in a row to get the maximum wind speed.

When you are finished, press and hold the button again to turn it off.

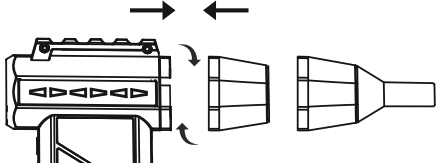

ENG 3

Note:

- You will already have the short air blowing head attached to the jet blower. To use a different air blowing head, please detach the short blowing head by turning it to the right.
- The blowing speed depends on the battery charge. Therefore, it is recommended that you fully charge the battery each time before use.

Precision tool for diverse scenarios for reference:



ENG 4

Please notice - All products are subject to change without any notice. We take reservations for errors and omissions in the manual.

ALL RIGHTS RESERVED, COPYRIGHT DENVER A/S



Electric and electronic equipment and included batteries contains materials, components and substances that can be hazardous to your health and the environment. If the waste material (discarded electric and electronic equipment and batteries) is not handled correctly.

Electric and electronic equipment and batteries is marked with the crossed out trash can symbol, seen above. This symbol signifies that electric and electronic equipment and batteries should not be disposed of with other household waste, but should be disposed of separately.

As the end user it is important that you submit your used batteries to the appropriate and designated facility. In this manner you make sure that the batteries are recycled in accordance with legislature and will not harm the environment.

ENG 5

All cities have established collection points, where electric and electronic equipment and batteries can either be submitted free of charge at recycling stations and other collection sites, or be collected from the households. Additional information is available at the technical department of your city.

Information on standby/off mode power consumption and power management for products compliant with Commission Regulation (EU) 2023/826 can be found at the following internet address: denver.eu and then click the search ICON on topline of website. Write model number: HJB-172 and enter the page.

DENVER A/S
Omega 5A, Soeften
DK-8382 Hinnerup
Denmark
www.denver.eu
www.facebook.com/denver.eu

ENG 6

Contact

Main contact point: contact.hq@denver.eu

Nordics Headquarter Denver A/S Omega 5A, Soeften DK-8382 Hinnerup Denmark Phone: +45 96 22 61 00 (Push "1" for support) E-Mail: support.hq@denver.eu For technical questions, please write to: support.hq@denver.eu For all other questions please write to: contact.hq@denver.eu	Germany Denver Germany GmbH Service Service Center Max-Emanuel-Str. 4 94036 Passau Phone: +49 851 379369 40 E-Mail: support.de@denver.eu Monday - Thursday 09:00 - 16:30 Friday 09:00 - 14:00
Benelux DENVER BENELUX B.V. Bovenloosander 13C-C 3443 HE Woerden The Netherlands Phone: 0900-3437825 E-Mail: support.nl@denver.eu	Austria Leaf Premium Service GmbH Deutchothstrasse 1 1230 Wien Phone: +43 1 904 3085 E-Mail: denver@lurbservice.at
Spain/Portugal denver Spain S.A. Ronda Augustas y Louis Lumiere, nº 25 - nave 16 Paseo Tecnológico 46100 PATISSEÑA Valencia (Spain) Spain: Phone: +34 902 046 885 Mail: support.es@denver.eu Portugal: Phone: +35 1255240 294 E-Mail: denver.service@denver.com	Poland LectiaRepair Poland sp. z o.o. ul. Cieszkowska 140 62-800 Kalisz Phone: 62 79 38 002 E-Mail: denver-service@lectiarepair.pl Coddymy spacy 8 - 18@ponedziak - pluk4) If your country is not listed above, please write an email to: contact.hq@denver.eu



Denver A/S
Omega 5A, Soeften
DK-8382 Hinnerup
Denmark
denver.eu
facebook.com/denver.eu



ENG 7