


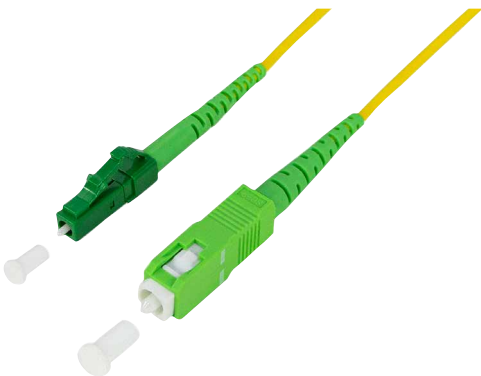


Fiber Simplex Patch Cable

SC/APC-LC/APC Polish

Technical Features

- SC/APC-LC/APC polish
- OS2 9/125 μm , compliant with G.657.A2
- Jacket: LSZH, yellow, $\varnothing 2\text{ mm}$
- Test report included

Technical Drawings

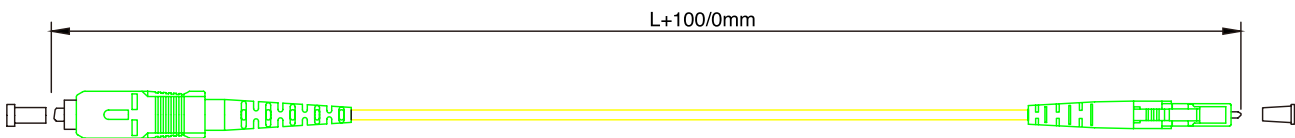

Test Grade Designation:Each to Reference		
Grade IL/RL	Standard	
Insertion Loss (IL)	$\leq 0,3\text{dB}$	IEC 61300-3-4
Return Loss(RL)	$\text{APC}\geq 60\text{dB}$	IEC 61300-3-6
Test Wavelength	1310nm	
End face inspection	$\times 400$	

Length	SC/APC-LC/APC	EAN Code	Length	SC/APC-LC/APC	EAN Code
0.50 m	FPSLS00	4052792066142	25.00 m	FPSLS25	4052792081367
1.00 m	FPSLS01	4052792066159	30.00 m	FPSLS30	4052792081374
2.00 m	FPSLS02	4052792066166	40.00 m	FPSLS40	4052792081381
3.00 m	FPSLS03	4052792066173	50.00 m	FPSLS50	4052792081398
5.00 m	FPSLS05	4052792066180	100.00 m	FPSLS11	4052792081404
10.00 m	FPSLS10	4052792066197			
15.00 m	FPSLS15	4052792066203			
20.00 m	FPSLS20	4052792066210			

Package Contents

1 x Fiber Simplex Patch Cable

Packaging Information

Art-No.	Packing Dimension	Packing Weight	Carton Dimension	Carton Q'ty	Carton Weight
FPSLS00	180 x 180 x 20 mm	0.011 kg	450 x 250 x 235 mm	300 pcs	4.04 kg
FPSLS01	180 x 180 x 20 mm	0.013 kg	450 x 250 x 235 mm	250 pcs	3.92 kg
FPSLS02	180 x 180 x 40 mm	0.016 kg	450 x 250 x 235 mm	200 pcs	3.98 kg
FPSLS03	220 x 220 x 40 mm	0.02 kg	450 x 250 x 235 mm	160 pcs	3.89 kg
FPSLS05	220 x 220 x 60 mm	0.027 kg	450 x 250 x 235 mm	60 pcs	2.33 kg
FPSLS10	220 x 220 x 60 mm	0.044 kg	450 x 250 x 235 mm	60 pcs	3.38 kg
FPSLS15	220 x 220 x 80 mm	0.062 kg	450 x 250 x 235 mm	50 pcs	3.81 kg
FPSLS20	220 x 220 x 80 mm	0.079 kg	450 x 250 x 235 mm	40 pcs	3.89 kg
FPSLS25	250 x 250 x 100 mm	0.09 kg	450 x 250 x 250 mm	50 pcs	5.3 kg
FPSLS30	250 x 250 x 120 mm	0.11 kg	450 x 250 x 250 mm	40 pcs	5.2 kg
FPSLS40	250 x 250 x 140 mm	0.14 kg	450 x 250 x 250 mm	32 pcs	5.3 kg
FPSLS50	230 x 230 x 50 mm	0.18 kg	450 x 250 x 250 mm	25 pcs	5.3 kg
FPSLS11	230 x 230 x 50 mm	0.36 kg	480 x 265 x 260 mm	10 pcs	5.3 kg



Made in China

www.2direct.de

*The specifications and pictures are subject to change without prior notice.
*All trade names referenced are the registered trademarks of their respective owners.