



PRODUCT SPECIFICATION

PD 20W Charger (2-port)
Model: WM2B

Revision History

Revision	Date	Initiator	Reason for Change
0.0	23 Oct 2020	CC Li	First release

Prepared By	Approved By
Joyce Tse	Joyce Tse
Date: 23 Oct, 2024	Date: 23 Oct, 2024




Member
Gold Peak Group

Manufacturer reserves the right to alter or amend the design, model and specification without prior notice.

Product Specification

Model no.: WM2B

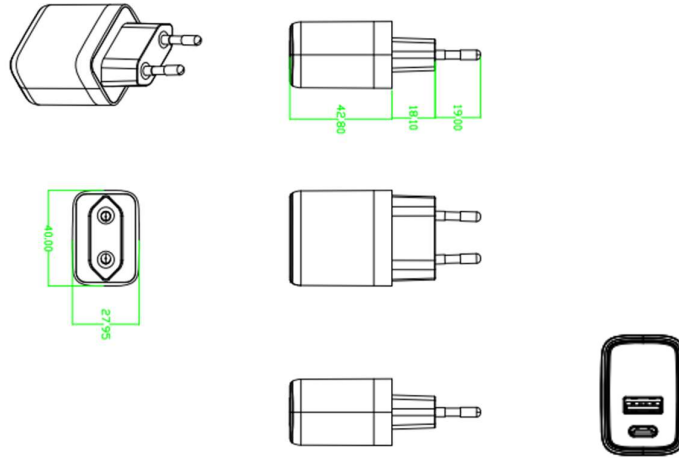

Product name	: PD 20W Charger, GS Plug (2-port)
Application	: Charge smartphones and other electronic products
Input	: AC 100-240V, 50/60Hz, 0.6A Max.
Output	: USB-C DC 5.0V/3.0A, 9.0V/2.22A, 12.0V/1.67A (20.0W Max.) USB-A DC 5.0V/3.0A, 9.0V/2.0A, 12.0V/1.5A (18.0W Max.) USB-C + USB-A DC 5.0V/3.0A (15.0W Max.)
Total output	: PD 20W
Number of ports	: USB-C x1, USB-A x1
Protection	: Over current protection (OCP) Short circuit protection (SCP)
Operation temperature	: 0°C to 25°C
Storage temperature	: -20°C to 80°C
Product dimension	: 80 (L) x 28 (W) x 40 (H) mm (Approx.)
Weight	: 50g (Approx.)
Compliance	: CE-LVD, CE-EMC, CE-ErP, ROHS, REACH
Warranty period	: 12 months from ex-factory date



Member
Gold Peak Group

Manufacturer reserves the right to alter or amend the design, model and specification without prior notice.