

15

1501 13






Jack connectors



Jack chassis socket acc. to JIS C 6560 JC25J3A, 2.5 mm, 3 poles/stereo, angular version, with metal collar, for printed circuit boards

15

1501 13

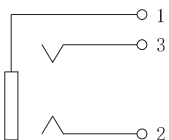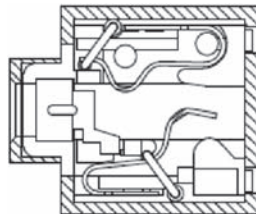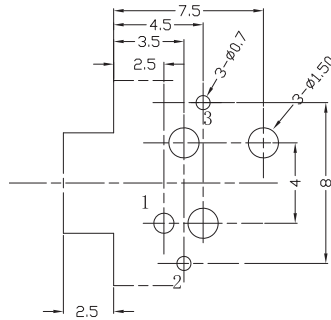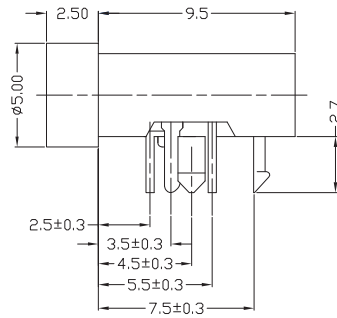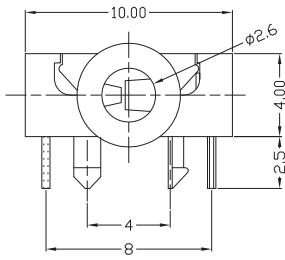

Environmental conditions

Temperature range -16 °C/+65 °C

Materials

Insulating body PBT, V-0 according to UL94
Contact spring CuSn, silver-plated
Cover PC

Mechanical data

Mating cycles 5000
Insertion force 2.9–29.4 N
Withdrawal force 2.9–29.4 N

Electrical data (at T_{amb} 20 °C)

Contact resistance ≤ 50 mΩ
Rated current 1 A
Rated voltage 12 V DC
Insulation resistance ≥ 100 MΩ

Associated products

Counterparts
☑ KLS 13

15

1501 13

Designation	Pole Number	PU (Pieces)	MDQ (Pieces)
1501 13	3	500	500

Packaging:

in bulk, in a cardboard box or a plastic bag