




IB-HUB1407


In-Desk USB Charger with Power Delivery & Quick Charge®

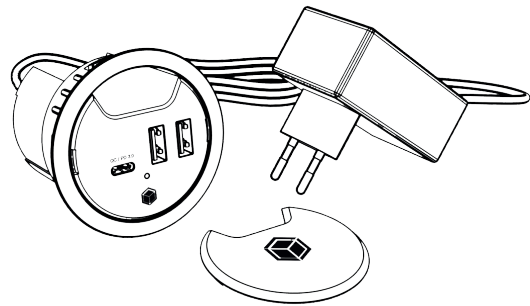

1x





1x

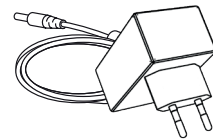


1x



1x

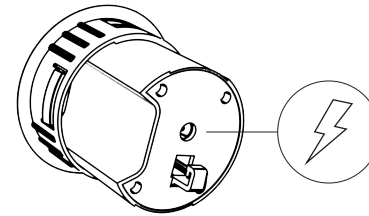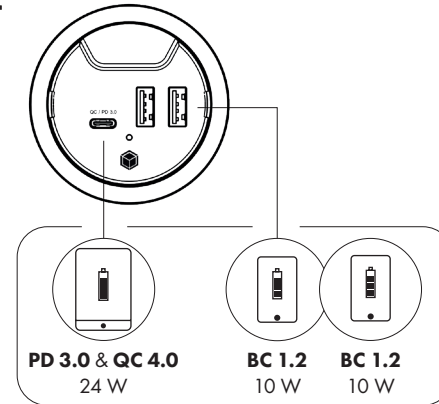

Connection	Max. input: AC 100-240 V ~50/60 Hz 1.5 A
USB Type-C®	5 V@3 A = 15 W; 9 V@3 A = 27 W; 12 V@2 A = 24 W
USB Type-A 1	5 V @ 2 A = 10 W
USB Type-A 2	5 V @ 2 A = 10 W
USB Type-C® + Type-A	24 W + 7.5 W (Max. 31.5 W)
USB Type-A 1 + Type-A 2	7.5 W + 7.5 W (Max. 15 W)
USB Type-C® + Type-A 1 + Type-A 2	15 W + 7.5 W + 7.5 W (Max. 30 W)

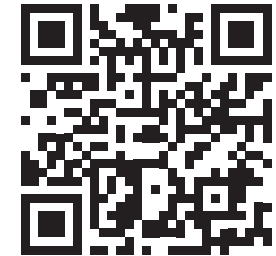


www.icybox.de




Nos produits et emballages se recyclent, ne les jetez pas! Trouvez où les déposer sur le site www.quefairedemesdechets.fr

© Copyright 2023 by RaidSonic Technology GmbH. All Rights Reserved.
The information contained in this manual is believed to be accurate and reliable. RaidSonic Technology GmbH assumes no responsibility for any errors contained in this manual. RaidSonic Technology GmbH reserves the right to make changes in the specifications and/or design of the above-mentioned product without prior notice. The diagrams contained in this manual may also not fully represent the product that you are using and are there for illustration purposes only. RaidSonic Technology GmbH assumes no responsibility for any differences between the product mentioned in this manual and the product you may have. Apple and macOS are registered trademarks of Apple Computer Inc. Microsoft, Windows and the Windows logo are registered trademarks of Microsoft Corporation.


1

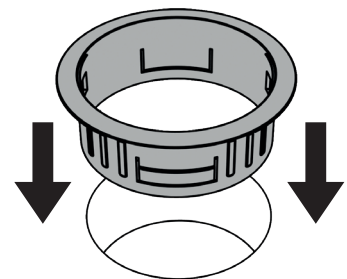


2

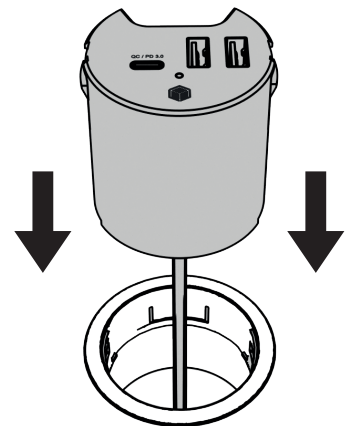

3

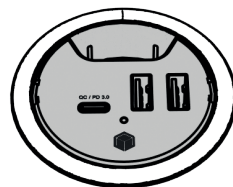

4

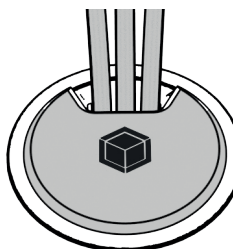

5

