

KERN CPB 30K0.5N

Professional model with counting resolution 60.000 points

KERN



Category	
Brand	KERN
Product category	Industrial scale
Product group	Counting scale
Product family	CPB

Measuring System	
Weighing system	Strain gauge
Weighing capacity [Max]	30 kg
Readability [d]	0,0005 kg
Reproducibility	0,001 kg
Linearity	± 0,002 kg
Resolution	60.000
Tare range	30 kg
Adjustment options	Adjusting with external weight
Recommended adjusting weight	20 kg (F2); 10 kg (F2)
Possible calibration points	30 kg
Stabilization time	2 s
Warm-up time	120 min
Eccentric loading at 1/3 [Max]	0,005 kg
Construction type of the scale	Single-range balance
Units	kg
Maximum creep (15 minutes)	5 g
Maximum creep (30 minutes)	10 g
Default unit	kg

Display	
Display type	LCD
Display backlight	✓
Display digit height - smallest digit	4 mm
Display digit height	20 mm

Construction	
Dimension housing (W×D×H)	315×350×100 mm
Dimensions device (W×D×H)	315×350×125 mm
Dimensions completely mounted (W×D×H)	315×350×125 mm
Dimensions weighing surface (W×D)	295×225 mm
Dimensions weighing surface	295×225 mm
Material housing	plastic
Material weighing plate	stainless steel
Level indicator	✓
Levelling feet adjustable	✓

Functions	
PreTare function	✓
Sum memory function	✓
Recipe/summing level	Sum A
Tolerance weighing	✓
Tolerance weighing - type of signal	acoustically visual
Underfloor weighing	None
Counting function	✓
Counting resolution (laboratory conditions)	60.000
Counting reference weight can be entered	✓
Smallest piece weight when piece counting - laboratory conditions	500 mg
Smallest piece weight when piece counting - normal conditions	5 g
Reference quantity	n (any number of pieces)
Auto-off interval(s) in battery mode/rechargeable battery mode	3 min 5 min 30 min 15 min
Tare function	manual (multi)
Number of keys for operation	20

Interface	
Interfaces	RS-232 standard

Power Supply	
Supplied power supply	Power supply unit
Power supply type	Power adapter
Plug-in power supply / adapter for countries - included with the delivery	EURO UK US CH

KERN CPB 30K0.5N

KERN

Professional model with counting resolution 60.000 points

Plug-in power supply / adapter for countries - optional	EURO AUS UK US CH
Power supply – Cable length	180 cm
Input voltage power supply / power [Max]	100 V - 240 V, 50 / 60 Hz
Input voltage device / power [Max]	12 V, 500 mA
Power socket for mains adapter	Hollow plug, inside plus, Ø outside 5,5 mm, Ø inside 2,1 mm, long 9,5 mm
Rechargeable battery	GAB-A04
Rechargeable battery operating time - backlight on	50 h
Rechargeable battery operating time - backlight off	90 h
Rechargeable battery charging time	12 h
Rechargeable battery optional	Rchrg. battery optional - intern

Environmental conditions

Ambient temperature [Min]	0 °C
Ambient temperature [Max]	40 °C
Humidity of environment [Min]	0 %
Humidity of environment [Max]	80 %
Storage temperature [Min]	-20 °C
Storage temperature [Max]	60 °C

Approval

CE mark	✓
---------	---

Services (optional)

Article number for DAkkS calibration	963-128
Article number for certificate of conformity	969-517

Packing & Shipping


Delivery time	1 d
Dimensions packaging (W×D×H)	370×450×220 mm
Shipping method	Parcel service
Net weight approx.	3,4 kg
Gross weight approx.	4,4 kg
Shipping weight	7,3 kg

Product information

GTIN/EAN number	4045761124394
REACH classification	no prohibited substances

Pictograms

STANDARD

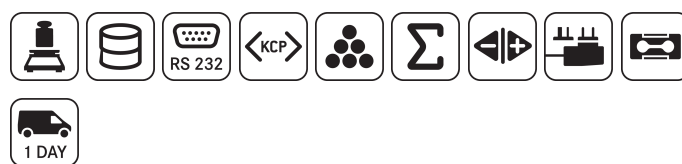

OPTION

