


|                  |                 |                            |
|------------------|-----------------|----------------------------|
| <b>5 x 20 mm</b> | F = No. 120.900 | (DIN 41661 / EN 60127-2-2) |
|                  | M = No. 121.800 | (DIN 41571/2)              |
|                  | T = No. 122.800 | (DIN 41662 / EN 60127-2-3) |

|           |               |             |          |   |
|-----------|---------------|-------------|----------|---|
| Inhalt:   | 100 St./pcs.: | 10 x 160 mA | 10 x 1   | A |
| contents: |               | 10 x 250 mA | 10 x 1,6 | A |
| contenu:  |               | 10 x 500 mA | 10 x 2,5 | A |
|           |               | 10 x 630 mA | 10 x 4   | A |
|           |               | 10 x 800 mA | 10 x 6,3 | A |

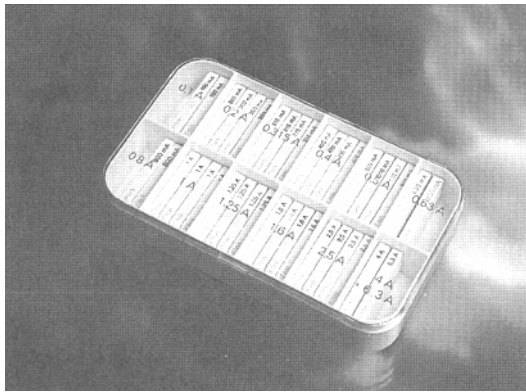


|                  |                 |                            |
|------------------|-----------------|----------------------------|
| <b>5 x 20 mm</b> | F = No. 520.800 | (DIN 41661 / EN 60127-2-2) |
|                  | M = No. 521.800 | (DIN 41571/2)              |
|                  | T = No. 522.800 | (DIN 41662 / EN 60127-2-3) |

|           |               |             |           |    |
|-----------|---------------|-------------|-----------|----|
| Inhalt:   | 200 St./pcs.: | 10 x 100 mA | 20 x 800  | mA |
| contents: |               | 10 x 200 mA | 30 x 1    | A  |
| contenu:  |               | 10 x 315 mA | 10 x 1,25 | A  |
|           |               | 10 x 400 mA | 20 x 1,6  | A  |
|           |               | 30 x 500 mA | 10 x 2,5  | A  |
|           |               | 20 x 630 mA | 10 x 4    | A  |
|           |               |             | 10 x 6,3  | A  |



|                  |                   |                            |
|------------------|-------------------|----------------------------|
| <b>5 x 20 mm</b> | F = No. E3520.800 | (DIN 41661 / EN 60127-2-2) |
|                  | M = No. E3521.800 | (DIN 41571/2)              |
|                  | T = No. E3522.800 | (DIN 41662 / EN 60127-2-3) |

|           |               |             |           |    |
|-----------|---------------|-------------|-----------|----|
| Inhalt:   | 360 St./pcs.: | 20 x 100 mA | 20 x 800  | mA |
| contents: |               | 20 x 125 mA | 20 x 1    | A  |
| contenu:  |               | 20 x 160 mA | 20 x 1,25 | A  |
|           |               | 20 x 200 mA | 20 x 1,6  | A  |
|           |               | 20 x 250 mA | 20 x 2    | A  |
|           |               | 20 x 315 mA | 20 x 2,5  | A  |
|           |               | 20 x 400 mA | 20 x 3,15 | A  |
|           |               | 20 x 500 mA | 20 x 4    | A  |
|           |               | 20 x 630 mA | 20 x 6,3  | A  |

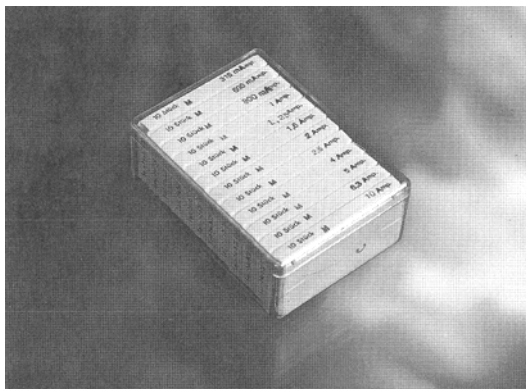

|                    |                 |
|--------------------|-----------------|
| <b>6,3 x 32 mm</b> | F = No. 632.800 |
|                    | M = No. 632.820 |
|                    | T = No. 632.830 |

|           |               |             |          |   |
|-----------|---------------|-------------|----------|---|
| Inhalt:   | 120 St./pcs.: | 10 x 315 mA | 10 x 2   | A |
| contents: |               | 10 x 500 mA | 10 x 2,5 | A |
| contenu:  |               | 10 x 800 mA | 10 x 4   | A |
|           |               | 10 x 1      | 10 x 5   | A |
|           |               | 10 x 1,25 A | 10 x 6,3 | A |
|           |               | 10 x 1,6 A  | 10 x 10  | A |