



Ø 2 mm-Einbaubuchsen

Ø 2 mm Panel-mount Sockets

Douilles Ø 2 mm à visser

LB2-IF

 1:1

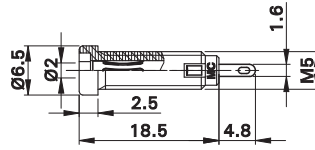

MU/M5



Montagebohrung
Panel drilling
Perçage de panneau



Isolierte Ø 2 mm-Buchse mit federnder Kontaktlamelle. Montage durch Festschrauben in Bohrungen von Platten oder Gehäusen.

Lötanschluss.

Insulated Ø 2 mm socket with spring-loaded Multilam. The socket can be screw-mounted in predrilled panels. **Solder connection.**

Douille à lamelles Ø 2 mm, isolée. A visser dans des perçages de panneaux ou de boîtiers. **Raccord à souder.**

Typ Type Type	Best.-Nr. Order No. N° de Cde	Bemessungsspannung / -strom Rated voltage / current Tension / intensité assignée	Einzelteile: Buchse / Montagmaterial Component parts: Socket / Assembly material Pièces détachées : Douille / Matériel de fixation	*Farben *Colours *Couleurs
---------------------	-------------------------------------	--	--	----------------------------------

LB2-IF	23.0050*	30 V _{AC} ~ 60 V _{DC} / 10 A	BI-LB2-IF, 23.5062* MU/M5	Au	21 22 23 24 25
---------------	-----------------	--	------------------------------	-----------	---