



Ø 2 mm-Einbaubuchsen

Ø 2 mm Panel-mount Sockets

Douilles Ø 2 mm à visser

LB2-IF

 1:1

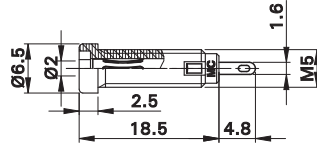

MU/M5



Montagebohrung  
Panel drilling  
Perçage de panneau



Isolierte Ø 2 mm-Buchse mit federnder Kontaktlamelle. Montage durch Festschrauben in Bohrungen von Platten oder Gehäusen.

**Lötanschluss.**

Insulated Ø 2 mm socket with spring-loaded Multilam. The socket can be screw-mounted in predrilled panels. **Solder connection.**

Douille à lamelles Ø 2 mm, isolée. A visser dans des perçages de panneaux ou de boîtiers. **Raccord à souder.**

Typ Type Type	Best.-Nr. Order No. N° de Cde	Bemessungsspannung / -strom Rated voltage / current Tension / intensité assignée	Einzelteile: Buchse / Montagematerial Component parts: Socket / Assembly material Pièces détachées : Douille / Matériel de fixation	*Farben *Colours *Couleurs
---------------------	-------------------------------------	--	---	----------------------------------

<b>LB2-IF</b>	<b>23.0050*</b>	30 V <sub>AC</sub> ~ 60 V <sub>DC</sub> / 10 A	BI-LB2-IF, 23.5062* MU/M5	<b>Au</b>	<b>21</b> <b>22</b> <b>23</b> <b>24</b> <b>25</b>
---------------	-----------------	--	------------------------------	-----------	---