

KERN FCB 12K1

KERN

Checkweighing and portioning scale with up to three interfaces



Category

Brand	KERN
Product category	Industrial scale
Product group	Bench scale
Product family	FCB

Measuring System

Weighing system	Strain gauge
Weighing capacity [Max]	12 kg
Readability [d]	0,001 kg
Reproducibility	0,001 kg
Linearity	± 0,003 kg
Resolution	12.000

Adjustment options	Adjusting with external weight
--------------------	--------------------------------

Recommended adjusting weight	12 kg (M1)
Possible calibration points	4 kg; 8 kg; 12 kg
Stabilization time	2 s
Warm-up time	30 min
Eccentric loading at 1/3 [Max]	0,005 kg

Construction type of the scale	Single-range balance
--------------------------------	----------------------

Units	kg
	g
	gn
	dwt
	ct
	lb
	oz
	ffa
	PCS
	%

Maximum creep (15 minutes)	4 g
----------------------------	-----

Maximum creep (30 minutes)	8 g
----------------------------	-----

Default unit	kg
Loadcell type	aluminium IP65 silicone-coated

Display

Display type	LCD
Display backlight	✓
Display screen size	120×38 mm
Display digit height	25 mm
Languages of the user interface	English Symbol language

Construction

Dimension housing (W×D×H)	322×267×91 mm
Dimensions completely mounted (W×D×H)	325×270×105 mm
Dimensions weighing surface (W×D)	252×225 mm
Dimensions weighing surface	252×225 mm
Material housing	plastic
Material weighing plate	stainless steel
Material display housing	plastic
Material load cell(s)	aluminium
Level indicator	✓
Levelling feet adjustable	✓
Transport safety lock - bolt torque	0,4 Nm

Functions

Recipe/summing level	Sum A
Percentage determination	✓
Tolerance weighing	✓
Tolerance weighing - type of signal	acoustically visual
Underfloor weighing	None
Function for averaging under unstable weighing conditions	✓
Counting function	✓
Counting resolution (laboratory conditions)	12.000
Counting reference weight can be entered	✓
Smallest piece weight when piece counting - laboratory conditions	1 g
Smallest piece weight when piece counting - normal conditions	10 g
Reference quantity	5, 10, 20, 50, free, Input
IP protection - complete device	-
IP protection - display	no IP protection
IP protection - load cell	IP65

KERN FCB 12K1



Checkweighing and portioning scale with up to three interfaces

Auto-off interval(s) in battery mode/rechargeable battery mode	2 min
	1 min
	30 min
	60 min
	30 sec
Tare function	manual (multi)
Number of keys for operation	6

Interface

Interfaces	RS-232 (optional)
	Ethernet (optional)
	Bluetooth BLE (v4.0) (optional)
	USB-Device (optional)
	KUP
	WiFi (optional)

compatible with EasyTouch ✓

Power Supply

Supplied power supply	Power supply unit
Power supply type	Power adapter
Plug-in power supply / adapter for countries - included with the delivery	EURO
	UK
	US
	CH

Plug-in power supply / adapter for countries - optional	EURO
	UK
	US
	CH

Input voltage power supply / power [Max]	100 V - 240 V AC, 50 / 60 Hz
--	------------------------------

Power supply cable removable	removable
------------------------------	-----------

Input voltage device / power [Max]	5,9V, 1A
------------------------------------	----------

Power socket for mains adapter	Hollow plug, inside plus, Ø outside 5,5 mm, Ø inside 2,1 mm, long 13 mm

Battery / accumulator type	Li-Ion
----------------------------	--------

Battery operating time	20 h
------------------------	------

Rechargeable battery operating time - backlight on	24 h
--	------

Rechargeable battery operating time - backlight off	48 h
---	------

Rechargeable battery charging time	8 h
------------------------------------	-----

Rechargeable battery optional	Rchrg. battery optional
-------------------------------	-------------------------

Environmental conditions

Ambient temperature [Min]	0 °C
---------------------------	------

Ambient temperature [Max]	40 °C
---------------------------	-------

Humidity of environment [Min]	0 %
-------------------------------	-----

Humidity of environment [Max]	80 %
-------------------------------	------

Storage temperature [Min]	-20 °C
---------------------------	--------

Storage temperature [Max]	60 °C
---------------------------	-------

Approval

CE mark	✓
---------	---

Services (optional)

Article number for adjustment at the location of installation	961-248
---	---------

Article number for DAkkS calibration	963-128
--------------------------------------	---------

Article number for certificate of conformity	969-517
--	---------

Packing & Shipping

Delivery time	1 d
---------------	-----

Dimensions packaging (W×D×H)	395×335×200 mm
------------------------------	----------------

Shipping method	Parcel service
-----------------	----------------

Net weight approx.	3,0 kg
--------------------	--------

Gross weight approx.	3,4 kg
----------------------	--------

Shipping weight	5,3 kg
-----------------	--------


Product information

GTIN/EAN number	4045761475496
-----------------	---------------

REACH classification	no prohibited substances
----------------------	--------------------------

Pictograms

STANDARD

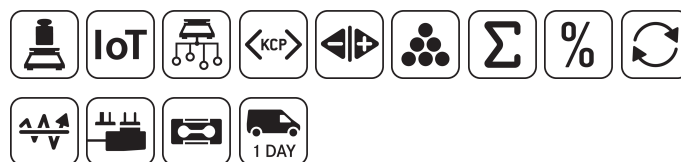

OPTION

