

Isoliertüllen für Steckhülsen 2,8 mm / 4,8 mm / 6,3 mm

Douilles pour languettes

Housings for taps

2,8 mm

Werkstoff:
 PA = Polyamid
 PE = Polyethylen
 PV = PVC (Polyvinylchlorid)




Temperaturbeständigkeit:
 PA -55°C bis +105°C
 PE -60°C bis +80°C
 PVC -10°C bis +75°C

Matière:
 PA = polyamide
 PE = polyéthylène
 PV = PVC (chlorure polyvinyle)

Résistant à une température de:
 PA -55°C à +105°C
 PE -60°C à +80°C
 PVC -10°C à +75°C

Material:
 PA = polyamid
 PE = polyethylen
 PV = PVC (polyvinylchlorid)

Temperature range:
 PA -55°C up to +105°C
 PE -60°C up to +80°C
 PVC -10°C up to +75°C

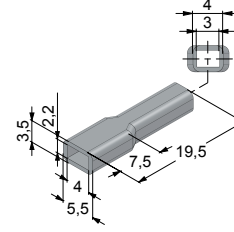
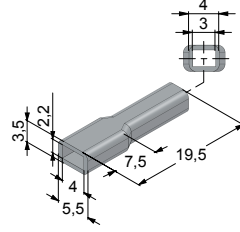
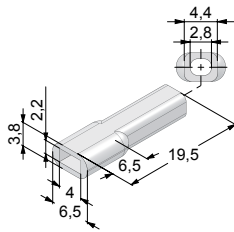


Artikelnummer
 Numéro d'article
 Part-No.

3930pv
 mm² 0.14-0.5 mm²
 AWG 26-22

3930pe
 mm² 0.5-1 mm²
 AWG 22-18

3930pa
 mm² 0.5-1 mm²
 AWG 22-18

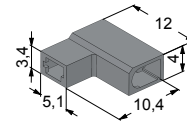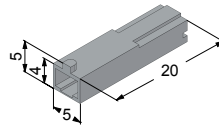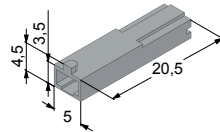





Artikelnummer
 Numéro d'article
 Part-No.

3931pa
 mm² 0.14-1 mm²
 AWG 26-18

39314pa
 mm² 0.14-1 mm²
 AWG 26-18

39311pa
 mm² 0.5-1 mm²
 AWG 22-18

4,8 mm

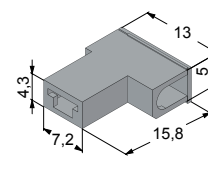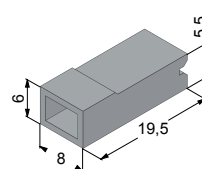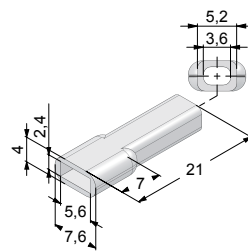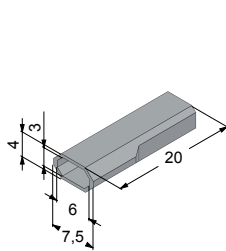

Artikelnummer
 Numéro d'article
 Part-No.

3935pe
 mm² 0.5-2.5 mm²
 AWG 22-14

3935wpv
 mm² 0.5-2.5 mm²
 AWG 22-14

3936pa
 mm² 0.5-2.5 mm²
 AWG 22-14

39361pa
 mm² 0.5-2.5 mm²
 AWG 22-14

