

Contact à sertir - RC-22S2000 - 1603327

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://download.phoenixcontact.com>)



Contact à sertir, roulés, Contact unique, Diamètre de contact: 1 mm, Zone de sertissage: 0,22 mm²...0,56 mm²

Key commercial data

package_quantity	100
GTIN	4046356244947

Technical data

Généralités

Type de contact	roulés
Diamètre de contact	1 mm
Type de contact	Connecteur femelle
Mode de raccordement	raccordement serti
De cycles d'enchâssage mécaniques	50
Section de cordon min.	0,22 mm²
Section de cordon max.	0,56 mm²

classifications

eCl@ss

eCl@ss 4.0	272607xx
eCl@ss 4.1	27260701
eCl@ss 5.0	27260701
eCl@ss 5.1	27260701
eCl@ss 6.0	27261204
eCl@ss 7.0	27440205
eCl@ss 8.0	27440204

ETIM

ETIM 3.0	EC001121
ETIM 4.0	EC000796
ETIM 5.0	EC000796

UNSPSC

UNSPSC 6.01	43172015
-------------	----------

Contact à sertir - RC-22S2000 - 1603327

classifications

UNSPSC

UNSPSC 7.0901	43201404
UNSPSC 11	43172015
UNSPSC 12.01	43201404
UNSPSC 13.2	43201404

accessories


Outil à sertir

RC-Z2130 - 1604267



Drawings

Dessin coté

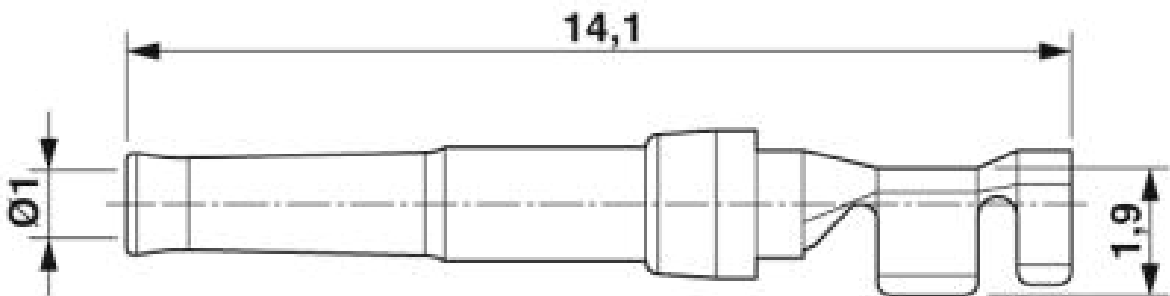

Dessin coté

© Phoenix Contact 2014 - all rights reserved
<http://www.phoenixcontact.com>