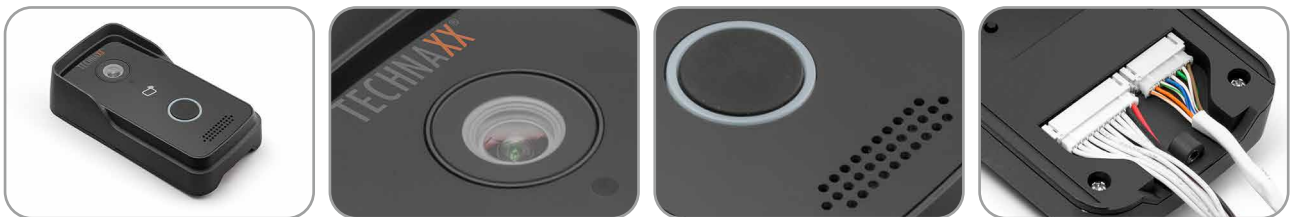


Smart WiFi Video Door Phone TX-82

Video Door Phone with WiFi outdoor camera & door opener function

 HD Camera 720P with CMOS Sensor / HD Kamera 720P mit CMOS Sensor	 Monitoring Entrance Areas / Überwachung von Eingangsbereichen	 Real Time Video Recording / Echtzeit-Videoaufnahme	 Picture Snapshot Function / Foto-Schnappschussaufnahme
 Live preview via mobile phone / Live-Bild via Mobiltelefon	 Unlock door by RFID/NFC Chip or APP / Türöffnung via RFID/NFC Chip oder APP	 Viewing Angle 120° horizontal & 105° vertical / Sichtwinkel 120° horizontal & 105° vertikal	 Night Vision Function / Nachtsichtfunktion
 Push Notice via APP by door ring & tamper alarm signal / Push-Nachricht via APP bei Türklingel & Sabotage-Alarmsignal	 Supports 2-Way Communication / Gegensprechanlage	 Storage on MicroSD Card / Speicherung auf MicroSD Karte	 IP65 Waterjet & Dust Protection / IP65 Strahlwasser- & Staubschutz

- 1/4" CMOS image sensor HD with 1 megapixel
- Real Time Video HD 720P via APP
- Video resolution 1280x720
- Viewing angle 125° horizontal & 105° vertical
- Night Vision Function ~1-2m with IR-Cut
- Push Notice via APP by door ring & tamper alarm signal
- 2-way communication via free iOS & Android APP
- Built-in microphone & speaker
- Supports chip card (RFID/NFC) to open the entrance door
- Connection via WiFi or network cable
- List of visitors with date & time
- Supports MicroSD cards up to 32GB
- IP65 camera protection class (against waterjet & dust)

Technical Specifications:

- Supports IEEE802.11b/g/n wireless protocol
- Lens: 2.2mm; viewing angle 125° horizontal & 105° vertical
- H.264 video compression standard
- Audio compression G.711 (input, output, talk)
- Communication interface: 1x RS485 10M/100Mbps self-adaptive Ethernet, supports WiFi, Protocol: TCP/IP
- Alarm Input/Output: 1-ch unlock button, 1-ch door sensor feedback / 1-ch relay output
- Outdoor control by 1 relay for main lock & 1 extended by access control module
- Current consumption standby 1W maximum
- Current consumption work 7W maximum
- External power supply DC 12V or standard PoE (802.3af)
- Recommended mounting height 1.4-1.6m / Surface mounting
- Operating conditions: -30°C~+60°C, humidity 90% or less
- Weight / Dimensions: 400g / (L) 13.5 x (W) 7.0 x (H) 3.5cm

Package Contents:

- Smart WiFi Video Door Phone TX-82
- 3x RFID Transponder Chip Key
- Ethernet adapter cable
- Cable with different power connectors
- Mounting bracket
- Screws for installation
- Waterproof rubber cap
- CD
- User Manual



Article-No. 4649