




Bedienungsanleitung

Mantelthermoelement
120757
(0625 1189-41)

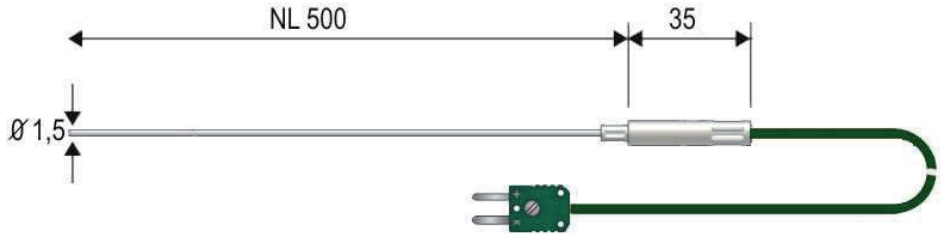


1. Mantelthermoelement NiCr-Ni, Typ K, mit Miniaturstecker (gelb oder grün) am Messgerät in die dafür vorgesehene Buchse einstecken.
2. Messwert am eingeschalteten Messgerät ablesen.
3. Messbereich des Mantelthermoelements -100°C bis $+1000^{\circ}\text{C}$

B+B Thermo-Technik GmbH | Heinrich-Hertz-Straße 4 | D-78166 Donaueschingen
Fon +49 771 83160 | Fax +49 771 831650 | info@bb-sensors.com | bb-sensors.com



Operating Instruction

Mineral Insulated Thermocouple
120757
(0625 1189-41)

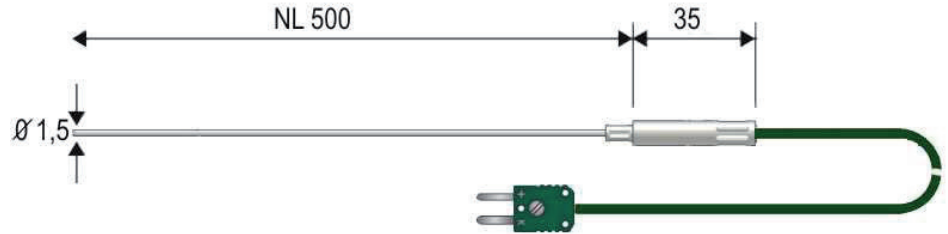

1. Plug in the Mineral Insulated Thermocouple NiCr-Ni, Type K with Miniature Plug (yellow or green) into the destined socket at the measurement device.
2. Read out the measured value of the measurement device.
3. Measuring range of Mineral Insulated Thermocouple $-100^{\circ}\text{C}\dots+1000^{\circ}\text{C}$
($-148^{\circ}\text{F}\dots+1832^{\circ}\text{F}$)

B+B Thermo-Technik GmbH | Heinrich-Hertz-Straße 4 | D-78166 Donaueschingen
Fon +49 771 83160 | Fax +49 771 831650 | info@bb-sensors.com | bb-sensors.com