


**Ø 4 mm-Messleitungen
mit stapelbaren Steckern**

**Ø 4 mm Test Leads
with Stackable Plugs**

**Cordons de mesure Ø 4 mm
à reprise arrière**

SLK425-E

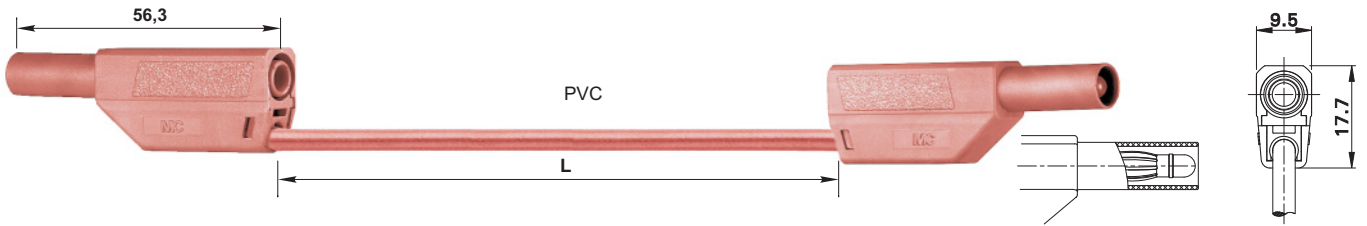

Hoch flexible Messleitungen mit PVC-Isolierung, beidseitig mit vergoldetem, stapelbarem Ø 4 mm-Lamellenstecker mit starrer Isolierhülse.

Highly flexible test leads with insulation in PVC with gold-plated stackable Ø 4 mm Multilam plugs with rigid insulating sleeve on both ends.

Cordons de mesure extra-souples à isolation en PVC, équipés des deux côtés d'une fiche à lamelles Ø 4 mm à reprise arrière, dorée, protégée par un fourreau isolant rigide.

Typ Type Type	Best.-Nr. Order No. N° de Cde	Bemessungsspannung / -strom Rated voltage / current Tension / intensité assignée	Leitungsquerschnitt Lead cross section Section du câble	Längen [cm] Lead lengths [cm] Longueurs [cm]	*Farben *Colours *Couleurs
---------------------	-------------------------------------	----------------------------------------------------------------------------------------	---------------------------------------------------------------	----------------------------------------------------	----------------------------------

SLK425-E **28.0124-*** 600 V, CAT III ~ 1000 V, CAT II / 32 A 2,5 mm²

