
 
 
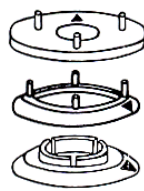
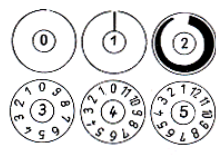
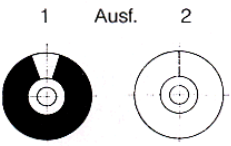



 

 
 



 
 
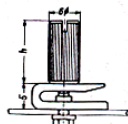
 



Knöpfe / Knobs			Zubehör / Accessories		
1	2	3	4	5	6
Farbenschlüssel / Colour Key 1 - r = rot red 0 - sch = schwarz black 2 - ga = grau grey 3 - br = braun brown 4 - be = beige beige 5 - c = chrom chromium 6 - b = blau blue 7 - ge = gelb yellow 8 - gü = grün green			ohne Markierung without Mark	mit Markierung with Mark	Kappe Cap
		d ∅			
		3 4 4 4	sch 330.3 sch 330.4 ga 330.404 br 4330.4191	sch 330.31 sch 330.41	r 499.642 sch 499.643 ga 499.644 c 499.645 b 499.646 ge 499.647 gü 499.648 be 499.649
		4 6 6 6	sch 331.4 sch 331.6 ga 331.604 br 4331.6191	sch 331.41 sch 331.61 ga 331.614 -	r 499.642 sch 499.643 ga 499.644 c 499.645 b 499.646 ge 499.647 gü 499.648 be 499.649
		4 4 6 6 6	sch 332.4 ga 332.404 sch 332.6 ga 332.604 br 4332.6191	sch 332.41 ga 332.414 sch 332.61 ga 332.614	r 332.662 sch 332.663 ga 332.664 c 332.665 b 332.666 ge 332.667 gü 332.668 be 332.669
		6 6 6	sch 333.6 ga 333.604 br 4333.6191	sch 333.61 ga 333.614 -	r 333.662 sch 333.663 ga 333.664 b 333.666 ge 333.667 gü 333.668 be 333.669
		6 6 6 8	sch 334.6 ga 334.604 br 4334.6191 sch 334.8	sch 334.61 - - sch 334.81	r 334.662 sch 334.663 ga 334.664 be 334.669
		6 6 6 8 10	sch 335.6 ga 335.604 br 4335.6191 sch 335.8 sch 335.9	sch 335.61 - - sch 335.81 sch 335.91	r 335.662 sch 335.663 ga 335.664 be 335.669

Zubehör / Accessories					
7	8	9	10	11	12
Mutterabdeckung Nut Cover	Dio. mit Zeiger Same, with Pointer	Zeiger Pointer	Zeigerscheibe Pointer dial	Glasklare Scheibe Transparent dial	Grundplatte Base plate
					
330.120	330.130	330.100 1 2	sch 330.250	Ausf. Type 0 330.200 1 330.201 2 330.202 3 330.203 4 330.204 5 330.205	1 330.300 sch
				0 331.200 1 331.201 2 331.202 3 331.203 4 331.204 5 331.205	1 331.300 sch
331.120	331.130 2	331.100 1 2	sch 331.250		
				0 332.200 1 332.201 2 332.202 3 332.203 4 332.204 5 332.205	1 332.300 sch
332.120	332.100 1 2	4332.100	sch 332.250		
-	-			0 333.200 1 333.201 2 333.202 3 333.203 4 333.204 5 333.205	1 333.300 sch
-	-			0 334.200 1 334.201	Feststeller Arrestor 
-	-			0 335.200 1 335.201	h = 7,5 329.15 h = 12 329.14 ohne Anzeige without indication h = 7,5 329.05 h = 12 329.04
-	-	335.100			