
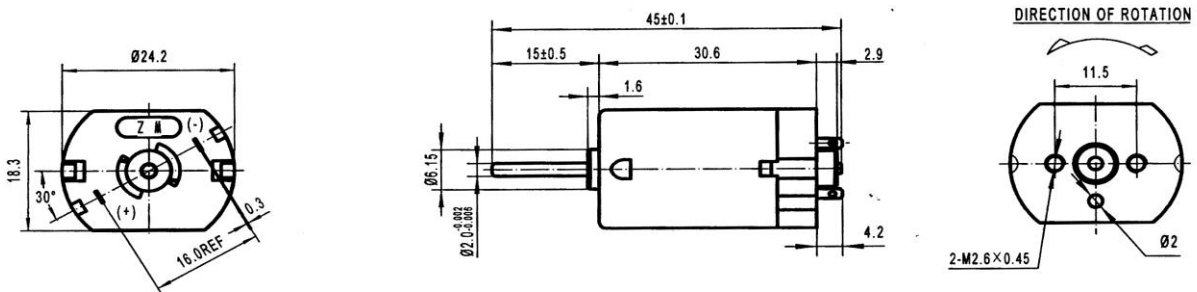


MODEL	VOLTAGE		NO LOAD		AT MAXIMUM EFFICIENCY				STARTING		max. OUTPUT POWER W	POLES	CAPACITOR	BRUSHES
	Operating Range	Nominal	Speed	Current	Speed	Current	Torque	Output Power	Current	Torque				
	VDC	VDC	rpm	A	rpm	A	mNm	W	A	mNm				
FK-280SAV-19170	1,0-16,0	12,0	11.581	0,07	10.029	0,47	3,81	4,18	3,04	28,46	9,00	3	none	carbon

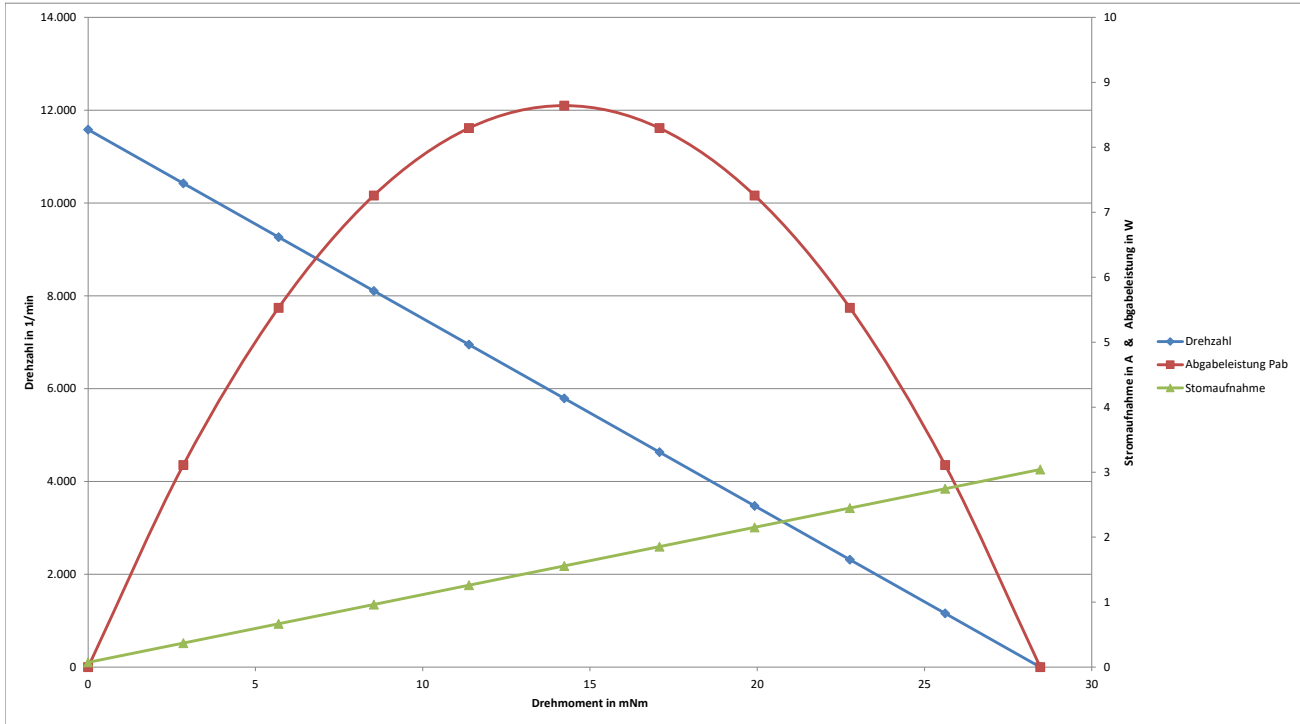

Irrtum und Druckfehler vorbehalten / Errors and Omissions excepted