
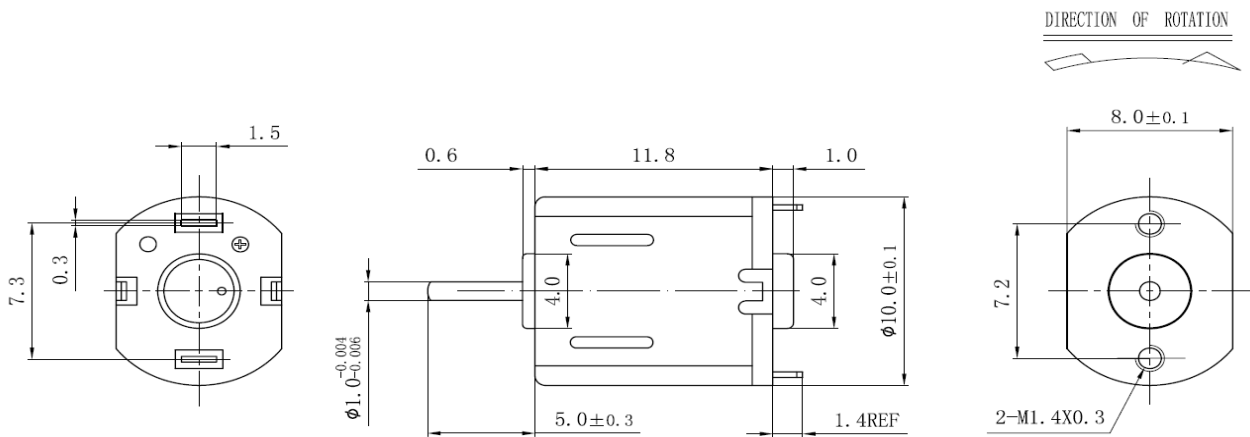


MODEL	VOLTAGE		NO LOAD		AT MAXIMUM EFFICIENCY				STARTING		max. OUTPUT POWER W	POLES	CAPACITOR	BRUSHES
	Operating Range	Nominal	Speed	Current	Speed	Current	Torque	Output Power	Current	Torque				
	VDC	VDC	rpm	A	rpm	A	mNm	W	A	mNm				
FF-M10VA-06230	1,5-6,0	4,5	23.200	0,05	17.485	0,14	0,15	0,28	0,42	0,62	0,37	3	none	metal

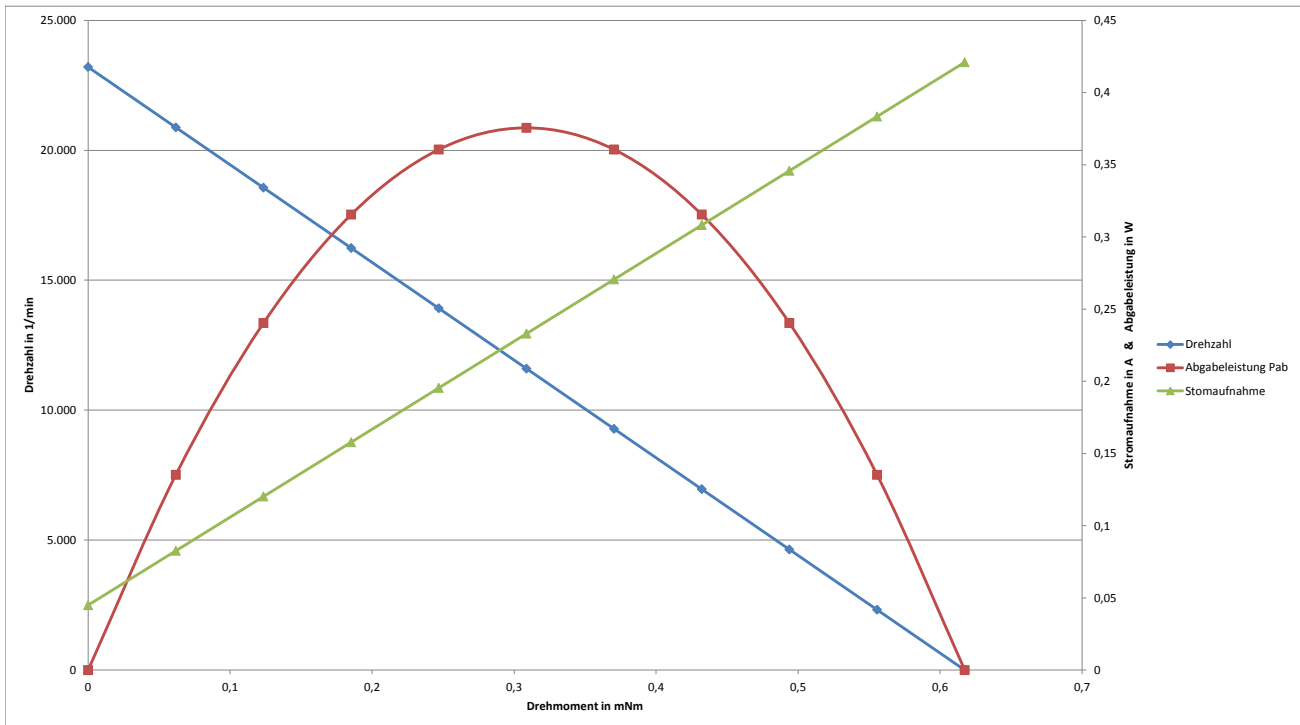

Irrtum und Druckfehler vorbehalten / Errors and Omissions excepted