


## SPRINT cable glands with mounting reduction sealing insert, metric

## SPRINT Kabelverschraubungen mit Reduzierdichteinsatz, metrisch

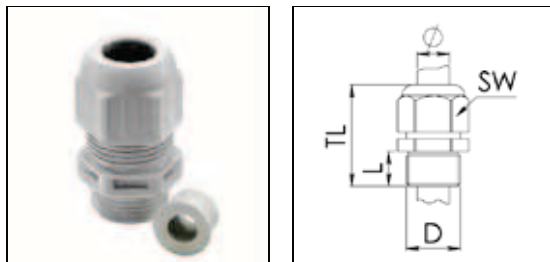

**Protection class to EN 60 529:** IP 68 to 5 bar (30 min) / M 40 up to M 63 with connection thread gasket

**Protection class to DIN 40 050-T9:** IP 69K

**Flame protection:** Glow wire test 750° C acc. to EN 60695-2-11

**Temperature range:** -40°C to 100°C, interm. up to approx. 120°C

**Material:** - Cable gland: polyamide

- Sealing insert: EPDM

**Equipment:** - Greater clamping range

- M 40 · M 63 incl. connection thread gasket

- Maximum traction relief through WISKA patent lamella

- Seal tight of enclosure through moulded sealing ring

- Profil thread with high torque guarantees tight and permanent fit of the cap nut (vibration-safe)

**Schutzart gemäß EN 60 529:** IP 68 bis 5 bar (30 min) / M 40 bis M 63 mit Anschlussgewindedichtring

**Schutzart gemäß DIN 40 050-T9:** IP 69K

**Flammwidrigkeit:** Glühdrahtprüfung 750° C gemäß EN 60695-2-11

**Einsatztemperatur:** -40°C bis 100°C, kurzzeitig bis ca. 120°C

**Material:** - Verschraubung: Polyamid

- Dichteinsatz: EPDM

**Ausstattung:** - Erweiterter Klemmbereich

- M 40 · M 63 inkl. Anschlussgewindedichtring

- Optimale Abdichtung und Zugentlastung durch patentiertes WISKA-Lamellensystem

- Abdichtung am Gehäuse durch angespritzte Dichtlippe

- Durch Profilgewinde vibrationsfest und Schutz vor Überdrehen der Hutmutter

Type	WISKA-No. RAL 7035	WISKA-No. RAL 9005	WISKA-No. RAL 7001						TL
					mm	mm	mm	mm	mm
ESKV-RDE 12	10064976	10064992	10064984	50/500	M 12x1,5	9	1 · 7	16	29 · 34
ESKV-RDE 16	10064977	10064993	10064985	50/500	M 16x1,5	9	2 · 10	20	31 · 37
ESKV-RDE 20	10064978	10064994	10064986	50/500	M 20x1,5	10	4 · 13	24	36 · 45
ESKV-RDE 25	10064979	10064995	10064987	50/450	M 25x1,5	10	7 · 17	29	38 · 47
ESKV-RDE 32	10064980	10064996	10064988	25/250	M 32x1,5	12	9 · 21	36	42 · 51
ESKV-RDE 40	10064981	10064997	10064989	10/100	M 40x1,5	12	12 · 28	46	52 · 65
ESKV-RDE 50	10064982	10064998	10064990	4/40	M 50x1,5	14	16 · 35	55	59 · 72
ESKV-RDE 63	10064983	10064999	10064991	3/30	M 63x1,5	15	28 · 48	68	64 · 78

**Recommended accessories:**

Empfohlenes Zubehör:



EMUG  
Page / Seite 26



EADR  
Page / Seite 208



BS  
Page / Seite 204

KUNSTSTOFF PLASTIC  
MEMBRAN MEMBRANE  
MESSING BRASS  
DIN 89280  
EDELSTAHL STAINL. STEEL  
EMV EMC  
ATEX  
VentGLAND  
BS 6121  
DICHTUNGEN SEALINGS  
WERKZEUGE TOOLS  
TECHNIK TECHNICS  
INDEX INDEX