

LOGLIFE



wolfcraft®




**60
68
74
80
95
mm**





2155⁰⁰⁰

140002155 X31 - 2155⁰⁰⁰

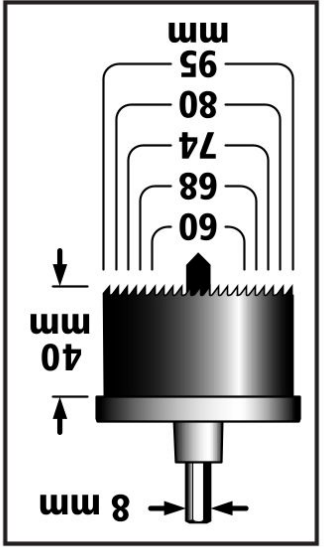

Ø	max. RPM
60	1.000
68	800
74	800
80	600
80	400
95	400

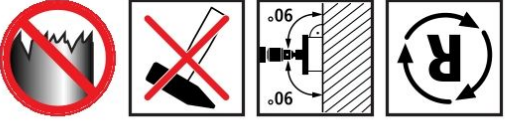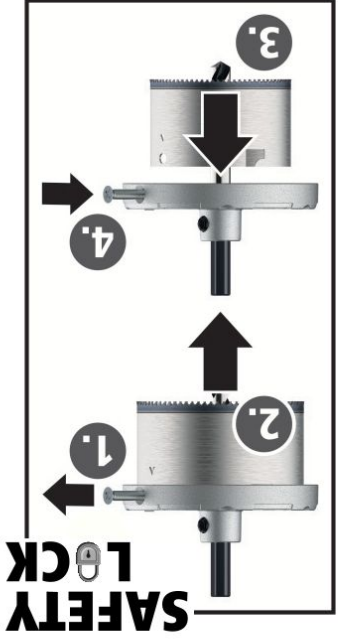

wolfcraft GmbH
Wolffstraße 1
56746 Kempenich
Germany
www.wolfcraft.com