

LONGLIFE




wolfcraft®

- Ø**
- 25
 - 32
 - 38
 - 45
 - 50
 - 56
 - 62
 - mm




0000912

140002160 Y43 - 2160000

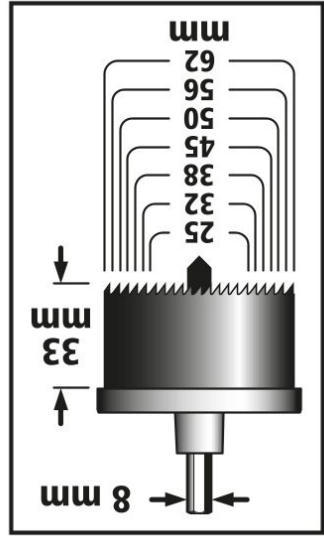

Ø	mm	RPM
max.	1.200	1.200
25	1.200	1.200
32	1.200	1.200
38	1.200	1.200
45	1.000	1.000
50	1.000	1.000
56	1.000	1.000
62	800	800

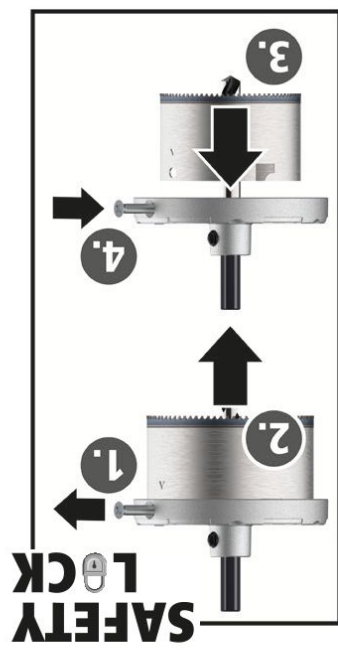

wolfcraft GmbH
Wolffstraße 1
56746 Kempenich
Germany
info@wolfcraft.com
www.wolfcraft.com