

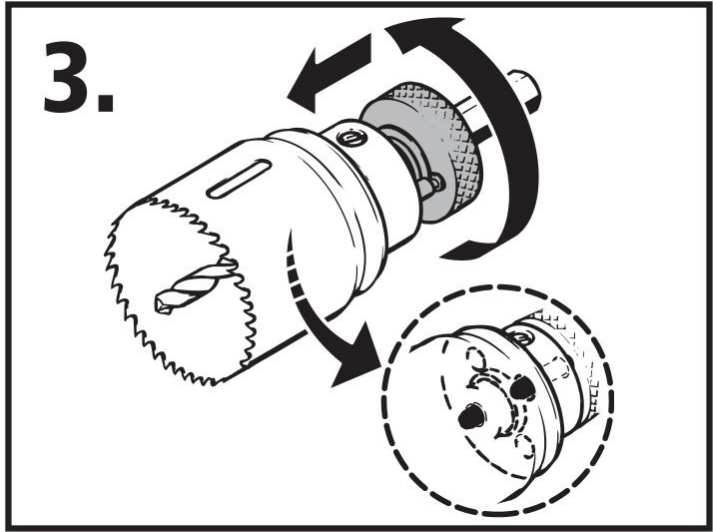


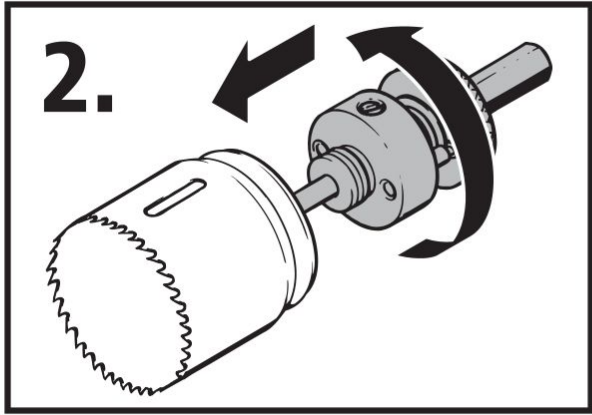







INFO +

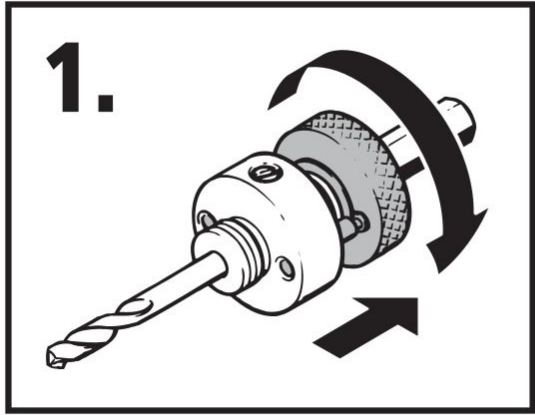


Type Approved
Safety
Regular Production
Surveillance

www.tuv.com
ID 0000039234

014325423 X24 - **5423000**

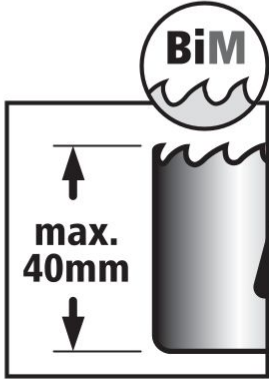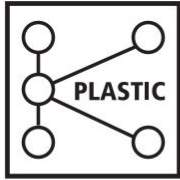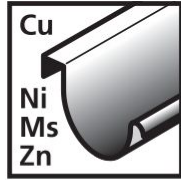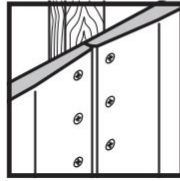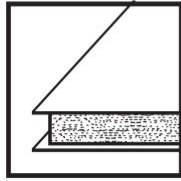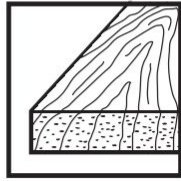

max. RPM Ø			
40 mm	2.100	2.100	220
54 mm	2.000	2.000	160
65 mm	1.850	1.850	130
68 mm	1.800	1.800	130
74 mm	1.800	1.800	120
86 mm	1.500	1.500	100

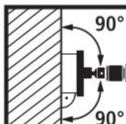

①
Raccolta differenziata.
Verifica le disposizioni
del tuo Comune



wolfcraft GmbH
Wolffstraße 1
56746 Kempenich
Germany
www.wolfcraft.com