

6372 000



mm
20/16
Ø

mm
180
Ø

14



142106372 U31 - 6372 000

HM/HW

TCT





DIN
847-1

HRC
40-44

n max.

6.600
min⁻¹

22 x

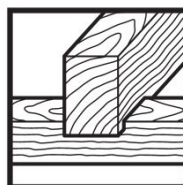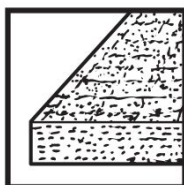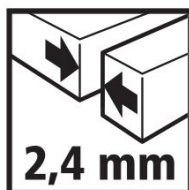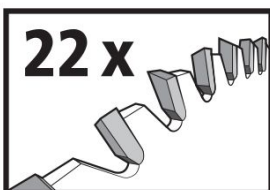

Ø16 mm



Ø20 mm

