

6373 000



mm
20/16
Ø

mm
184
Ø

15

142106373 U31 - 6373 000

HM/HW

TCT



DIN
847-1

HRC
40-44



n max.

6.600
min⁻¹

22 x

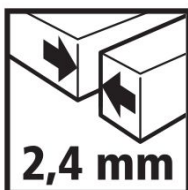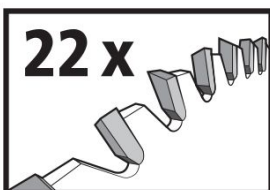

2,4 mm

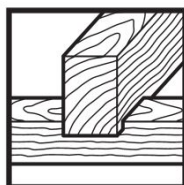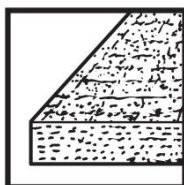

Ø16 mm



Ø20 mm

