



6731 000 1379



mm

20/12,75

Ø

mm Ø 140

4/4a

142106731 U31 - 6731 000

HM/HW

TCT

DIN

847-1

HRC


40-44

n max.

6.800

min⁻¹

18 x

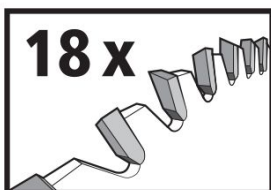

2,4 mm



Ø12,75 mm Ø20 mm

