


8918⁰⁰⁰

wolfcraft®




Ø 68
74
80
90
100
mm



140008918 V09 - 8918⁰⁰⁰

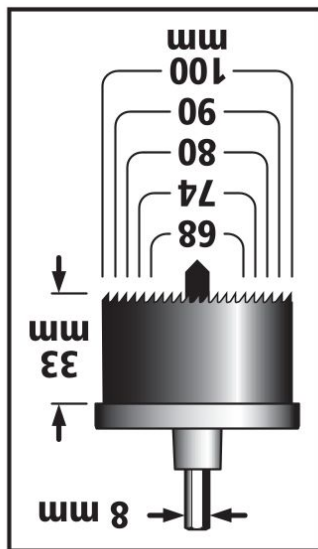

Ø	max. RPM
100	400
90	500
80	600
74	800
68	800

 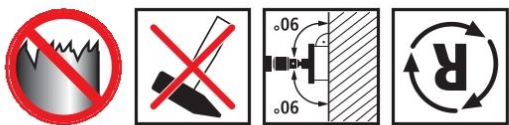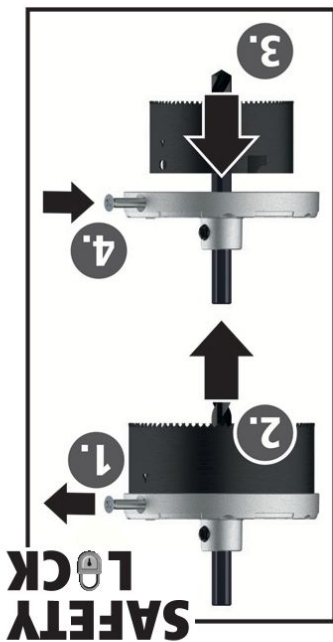

wolfcraft GmbH
Wolffstraße 1
56746 Kempenich
Germany
info@wolfcraft.com
www.wolfcraft.com