
 
 
 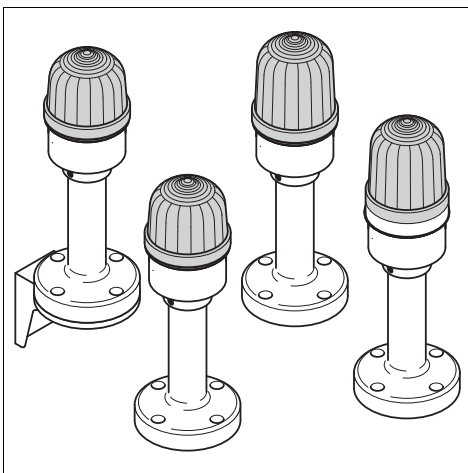
 




- Ⓓ Anschluss **ausschließlich** durch ausgebildete Elektro-Fachkräfte.
- Ⓔ Electrical connection is to be made by trained electrical specialists **only**.
- Ⓕ Le branchement doit **uniquement** être effectué par des professionnels.
- Ⓖ Il collegamento deve essere eseguito **solo** da elettricisti specializzati.
- Ⓔ La conexión **sólo** debe ser realizada por electricistas debidamente formados.
- Ⓕ A ligação deve ser feita **exclusivamente** por profissional elétrico especializado.
- Ⓖ De aansluiting mag **enkel** gebeuren door erkende vakmensen.
- ⒸZ Připojení smí **provádět** pouze kvalifikovaný personál.
- Ⓖ Podłączenie **wyłącznie** przez specjalistów-elektryków.
- Ⓕ Liittäminen kuuluu **ainoastaan** koulutettujen sähköalan ammattilaisten tehtäviin.
- Ⓖ Подключение проводится только специа-листом-электриком.
- Ⓕ Bağlantı **sadece** eğitimli elektrik teknisyenleri tarafından yapılmalıdır.
- ⒸN 布线需由专业电工执行




209 x00 00	12 – 240 V~, ≤ 7 W
209 x10 67	115 V~, 25 mA, I ₀ < 500 mA
209 x10 68	230 V~, 25 mA, I ₀ < 500 mA
209 x10 75	24 V~, 45 mA, I ₀ < 500 mA
209 x20 55	24 V~, 100 mA, ~ 0.75 Hz
209 x20 67	115 V~, 20 mA, ~ 0.75 Hz
209 x20 68	230 V~, 30 mA, ~ 0.75 Hz
219 x00 00	12 – 240 V~, ≤ 10 W
219 x10 67	115 V~, 25 mA, I ₀ < 500 mA
219 x10 68	230 V~, 25 mA, I ₀ < 500 mA
219 x10 75	24 V~, 45 mA, I ₀ < 500 mA
219 x20 55	24 V~, 100 mA, ~ 0.75 Hz
219 x20 67	115 V~, 20 mA, ~ 0.75 Hz
219 x20 68	230 V~, 30 mA, ~ 0.75 Hz




BA 15 d
(209 x10 xx, 219 x10 xx)

956 x00 75	24 V~, 45 mA
956 x00 67	115 V~, 15 mA
956 x00 68	230 V~, 15 mA

 

BA 15 d, ≤ 42 mm (1.65"),
(209 x00 00 ≤ 7 W)

955 840 34	12 V
955 840 35	24 V
955 840 32	30 V
955 840 57	115 V
955 840 38	230 V

 

BA 15 d, ≤ 52 mm (2.05"),
(219 x00 00 ≤ 10 W)

955 015 34	12 V
955 015 35	24 V
955 015 57	115 V
955 015 38	230 V

