
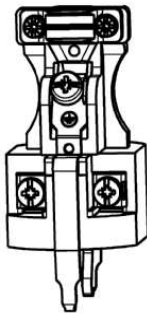
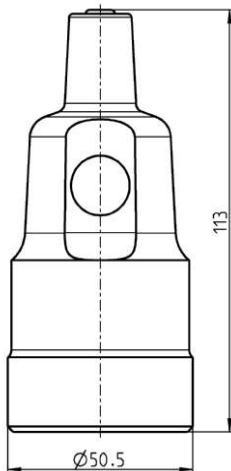


Datenblatt / Datasheet

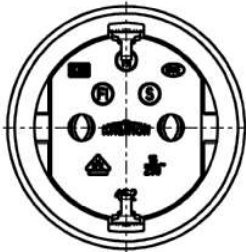

Schutzkontaktkupplung deutsche Ausführung.

Vollgummi Ausführung, Schutzart IP 20.

Solid rubber socket outlet with protective contact system, IP 20 protection.

Typ: 452G Art. Nr.: 452001
Type:

Nennspannung: AC 250 V
Rated voltage:

Nennstrom: 16A
Rated current:

Bauart: DIN 49 440
According to:

Schutzart: IP 20
IP-Code

Anschlüsse: Schraubklemmen
Type of Terminals: Screw terminals

Kontakte: CuZn 37
Material of Terminals:

Kontaktträger: SBR
Carrying parts: Styrol-butadien-rubber

Gehäuse: SBR
Cover: Styrol-butadien-rubber

Approbationen: VDE
Certified by:

Anmerkung: -
Annotation:

RoHs Konformität: Ja
RoHs Compliance: yes

Ce Kennzeichnung: Keine
Ce Marking: None

Altgeräterichtlinie: Nicht zutreffend
WEEE: Not applicable