


**RoHS & REACH Compliant**

Signature	Revision History	Date	Rev.
LIBRA	For Bulk Production	Dec.14.2016	01




PIN Assignment			
P1	input	output	P2
1	WHITE	1	WHITE
2	RED	2	RED
3	GROUND	3	GROUND
4	WHITE	4	WHITE
5	BROWN	5	BROWN
6	GROUND	6	GROUND
7	WHITE	7	WHITE
8	BLUE	8	BLUE
9	GROUND	9	GROUND
10	WHITE	10	WHITE
11	GREEN	11	GREEN
12	GROUND	12	GROUND
13	BLACK	13	BLACK
14	WHITE	14	WHITE
15	RED	15	RED
16	GRAY	16	GRAY
17	YELLOW	17	YELLOW
18	ORANGE	18	ORANGE
19	PURPLE	19	PURPLE
SHELL	GROUND+JUMP WIRE	SHELL	

- NOTES:
- CABLE: UL20276 (28AWG\*1PR+EAM)\*4C+28AWG\*1PR+28AWG\*5C+AEB 50%Aluminum made up OD:7.3MM black printing:HIGH SPEED HDMITM CABLE .....
  - CONNECTOR:  
P1 ,P2 : HDMI M 19P Black rubber core The Pin needle gold-plated 15u Iron shell plating
  - HDMI TO HDMI adjustable Repeater (1.4V) +PCB
  - HOOD: MOLDED TYPE,PVC 45P,COLOR:BLACK.
  - ELECTRICLE TEST:  
(1)100% OPEN SHORT & MIS WIRE TEST.  
(2)CONTACT RESISTANCE 5 ohm Max .  
(3)INSULATION RESISTANCE 10M ohm Min .  
(4)HI-POT TEST:DC 300V/10ms

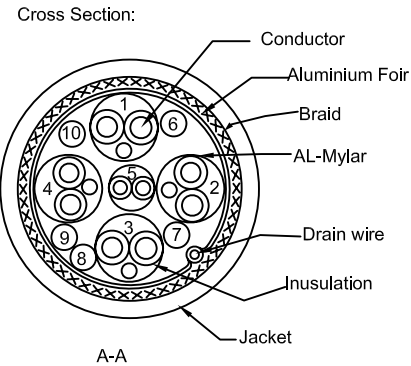

IC  
 东莞市南麟电子有限公司  
 LN6214P332P (3.3V SOT-89-3L)  
 DS16EV5110ASQE

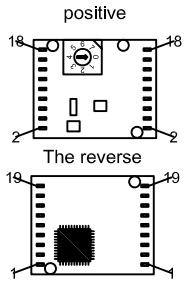

	Date	Name	Part No.
Drawn by	Dec.14,2016	Lyw	<b>AK-330105-150-S</b>
Checked by	Dec.14,2016	Saul	EAN:4016032346494
Approved by	16Dec, 2016,	Joe	Title
<b>ASSMANN</b> Electronic GmbH			HDMI M TO M 28Awg Cable 1.3 b Gold-plated
			Scale Unit

1

2

3

4

5

6

7

A

# Package Details

RoHS & REACH Compliant


Signature	Revision History	Date	Rev.
LIBRA	For Bulk Production	Dec.14,2016	01

## Single Cable

P/N	Cable Length	Rolling Size (Single Cable)	Polybag Type (Single Cable)	Bag Size (Single Cable)	Article Weight (Single Cable)
AK-330105-150-S	15m	mm max.	ednet Polybag (Stick type)	300*240*0.06mm	0.945 kg

## Inner Packing Unit

P/N	Cable Length	Quantity (Inner Packing Unit)	Type (Inner Packing Unit)	Size (Inner Packing Unit)	Weight (Inner Packing Unit)
xxx	Xm	pcs	Polybag (Heat Sealed)	mm	kg

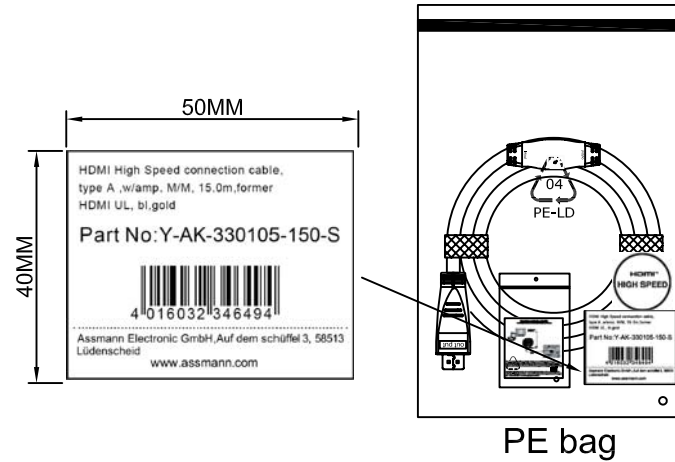

PE bag


D

## CARTON DETAILS

P/N	Cable Length	Quantity (Carton)	Measurement (Carton)	N.W. (Carton)	G.W. (Carton)
AK-330105-150-S	15m	11pcs	500*320*210MM	10.4 kg	11.2 kg

E


F

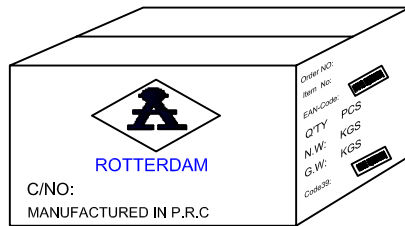

EAN-Code:



Code39:

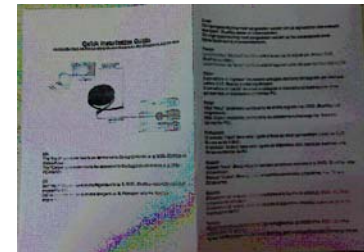

210\*297MM color specifications



The instructions

G

	Date	Name	Part No.
Drawn by	Dec.14,2016	Lyw	AK-330105-150-S
Checked by	Dec.14,2016	Saul	EAN:4016032346494
Approved by	16Dec, 2016,	Joe	

H

- \* "ROTTERDAM" is for Sea Freight shipment
- \* "COLOGNE" is for Air Freight shipment
- \* "LUDENSCHIED" is for Fedex or UPS shipment

**ASSMANN**  
Electronic GmbH

Title  
HDMI M TO M 28Awg Cable 1.3 b Gold-plated

Scale	N/A	Sheet
Unit	MM	2/2

1

2

3

4

5

6

7