


RoHS & REACH Compliant

Signature	Revision History	Date	Rev.
LIBRA	For Bulk Production	Dec.16,2016	01


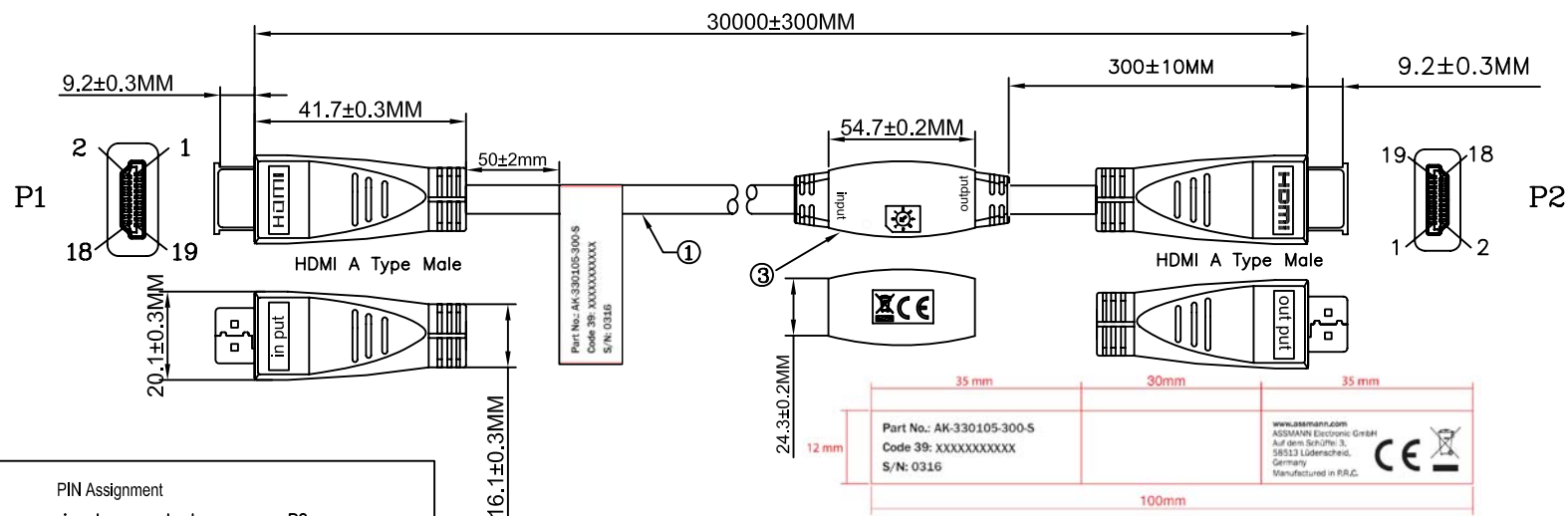


PIN Assignment			
P1	input	output	P2
1	WHITE	1	WHITE
2	RED	2	RED
3	GROUND	3	GROUND
4	WHITE	4	WHITE
5	BROWN	5	BROWN
6	GROUND	6	GROUND
7	WHITE	7	WHITE
8	BLUE	8	BLUE
9	GROUND	9	GROUND
10	WHITE	10	WHITE
11	GREEN	11	GREEN
12	GROUND	12	GROUND
13	BLACK	13	BLACK
14	WHITE	14	WHITE
15	RED	15	RED
16	GRAY	16	GRAY
17	YELLOW	17	YELLOW
18	ORANGE	18	ORANGE
19	PURPLE	19	PURPLE
SHELL	GROUND+JUMP WIRE	SHELL	

NOTES:

- CABLE: UL20276 (26AWG*1PR+EAM)*4C+26AWG*1PR+26AWG*5C+AEB 50%AL OD:8.0MM BLACK Print:HIGH SPEED HDMI M CABLE ...
- CONNECTOR:
P1 ,P2 : HDMI M 19P Black rubber core The Pin needle gold-plated 15u The gilded iron shell G/F
- HDMI TO HDMI adjustable Repeater (1.4V) +PCB
- HOOD: MOLDED TYPE,PVC 45P,COLOR:BLACK.
- ELECTRICLE TEST:
(1)100% OPEN SHORT & MIS WIRE TEST.
(2)CONTACT RESISTANCE 1 ohm Max .
(3)INSULATION RESISTANCE 10M ohm Min .
(4)HI-POT TEST:DC 300V/10ms

IC
东莞市南麟电子有限公司
LN6214P332P (3.3V SOT-89-3L)
DS16EV5110ASQE

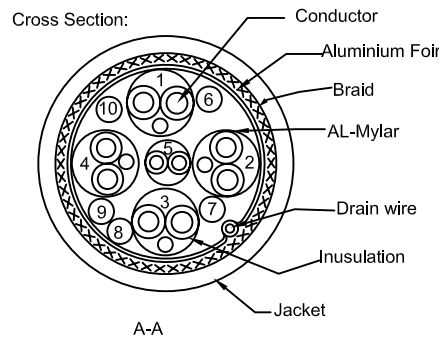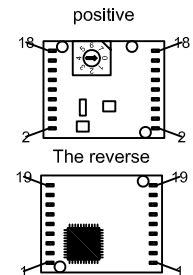

	Date	Name	Part No.
Drawn by	Dec.16,2016	Lyw	AK-330105-300-S
Checked by	Dec.16,2016	Saul	EAN:4016032295839
Approved by	19Dec, 2016	Joe	
ASSMANN Electronic GmbH			Title
			HDMI M TO M 28Awg Cable 1.3 b Gold-plated
			Scale Unit

	1	2	3	4	5	6	7																									
A	<h1>Package Details</h1>					RoHS & REACH Compliant		<table border="1"> <tr> <td>Signature</td> <td>Revision History</td> <td>Date</td> <td>Rev.</td> </tr> <tr> <td>LIBRA</td> <td>For Bulk Production</td> <td>Dec.16,2016</td> <td>01</td> </tr> </table>	Signature	Revision History	Date	Rev.	LIBRA	For Bulk Production	Dec.16,2016	01																
Signature	Revision History	Date	Rev.																													
LIBRA	For Bulk Production	Dec.16,2016	01																													
B	<p>Single Cable</p> <table border="1"> <thead> <tr> <th>P/N</th> <th>Cable Length</th> <th>Rolling Size (Single Cable)</th> <th>Polybag Type (Single Cable)</th> <th>Bag Size (Single Cable)</th> <th>Article Weight (Single Cable)</th> </tr> </thead> <tbody> <tr> <td>AK-330105-300-S</td> <td>30m</td> <td>mm max.</td> <td>ednet Polybag (Stick type)</td> <td>400*350*0.06mm</td> <td>2.1 kg</td> </tr> </tbody> </table>					P/N	Cable Length	Rolling Size (Single Cable)	Polybag Type (Single Cable)	Bag Size (Single Cable)	Article Weight (Single Cable)	AK-330105-300-S	30m	mm max.	ednet Polybag (Stick type)	400*350*0.06mm	2.1 kg	<p>50MM</p> <p>40MM</p> <p>Part No:AK-330105-300-S</p> <p>HDMI High Speed connection cable, type A, w/ amp. M/M, 30.0m, UL, bl, gold</p> <p>4 016032 295839</p> <p>Assmann Electronic GmbH, Auf dem schüttel 3, 58513 Lüdenscheid www.assmann.com</p> <p>PE bag</p>														
P/N	Cable Length	Rolling Size (Single Cable)	Polybag Type (Single Cable)	Bag Size (Single Cable)	Article Weight (Single Cable)																											
AK-330105-300-S	30m	mm max.	ednet Polybag (Stick type)	400*350*0.06mm	2.1 kg																											
C	<p>Inner Packing Unit</p> <table border="1"> <thead> <tr> <th>P/N</th> <th>Cable Length</th> <th>Quantity (Inner Packing Unit)</th> <th>Type (Inner Packing Unit)</th> <th>Size (Inner Packing Unit)</th> <th>Weight (Inner Packing Unit)</th> </tr> </thead> <tbody> <tr> <td>xxx</td> <td>Xm</td> <td>pcs</td> <td>Polybag (Heat Sealed)</td> <td>mm</td> <td>kg</td> </tr> </tbody> </table>					P/N	Cable Length	Quantity (Inner Packing Unit)	Type (Inner Packing Unit)	Size (Inner Packing Unit)	Weight (Inner Packing Unit)	xxx	Xm	pcs	Polybag (Heat Sealed)	mm	kg															
P/N	Cable Length	Quantity (Inner Packing Unit)	Type (Inner Packing Unit)	Size (Inner Packing Unit)	Weight (Inner Packing Unit)																											
xxx	Xm	pcs	Polybag (Heat Sealed)	mm	kg																											
D	<p>CARTON DETAILS</p> <table border="1"> <thead> <tr> <th>P/N</th> <th>Cable Length</th> <th>Quantity (Carton)</th> <th>Measurement (Carton)</th> <th>N.W. (Carton)</th> <th>G.W. (Carton)</th> </tr> </thead> <tbody> <tr> <td>AK-330105-300-S</td> <td>30m</td> <td>4pcs</td> <td>420*220*210MM</td> <td>8.4 kg</td> <td>9.0 kg</td> </tr> </tbody> </table>					P/N	Cable Length	Quantity (Carton)	Measurement (Carton)	N.W. (Carton)	G.W. (Carton)	AK-330105-300-S	30m	4pcs	420*220*210MM	8.4 kg	9.0 kg	<p>210*297MM color specifications</p>														
P/N	Cable Length	Quantity (Carton)	Measurement (Carton)	N.W. (Carton)	G.W. (Carton)																											
AK-330105-300-S	30m	4pcs	420*220*210MM	8.4 kg	9.0 kg																											
E						<p>The instructions</p>																										
F						<p>EAN-Code:</p>																										
G						<p>Code39:</p>																										
H	<p>* "ROTTERDAM" is for Sea Freight shipment * "COLOGNE" is for Air Freight shipment * "LUDENSCHIED" is for Fedex or UPS shipment</p>					<table border="1"> <tr> <td></td> <td>Date</td> <td>Name</td> <td rowspan="3">Part No. AK-330105-300-S EAN:4016032295839</td> </tr> <tr> <td>Drawn by</td> <td>Dec.16,2016</td> <td>Lyw</td> </tr> <tr> <td>Checked by</td> <td>Dec.16,2016</td> <td>Saul</td> </tr> <tr> <td>Approved by</td> <td>19Dec, 2016</td> <td>Joe</td> <td></td> </tr> <tr> <td colspan="3" style="text-align: center;">ASSMANN Electronic GmbH</td> <td>Title HDMI M TO M 28Awg Cable 1.3 b Gold-plated</td> </tr> <tr> <td colspan="2">Scale</td> <td>N/A</td> <td rowspan="2">Sheet 2/2</td> </tr> <tr> <td colspan="2">Unit</td> <td>MM</td> </tr> </table>			Date	Name	Part No. AK-330105-300-S EAN:4016032295839	Drawn by	Dec.16,2016	Lyw	Checked by	Dec.16,2016	Saul	Approved by	19Dec, 2016	Joe		ASSMANN Electronic GmbH			Title HDMI M TO M 28Awg Cable 1.3 b Gold-plated	Scale		N/A	Sheet 2/2	Unit		MM
	Date	Name	Part No. AK-330105-300-S EAN:4016032295839																													
Drawn by	Dec.16,2016	Lyw																														
Checked by	Dec.16,2016	Saul																														
Approved by	19Dec, 2016	Joe																														
ASSMANN Electronic GmbH			Title HDMI M TO M 28Awg Cable 1.3 b Gold-plated																													
Scale		N/A	Sheet 2/2																													
Unit		MM																														
	1	2	3	4	5	6	7																									