



RoHS & REACH Compliant

Signature	Revision History	Date	Rev.
LIBRA	For Bulk Production	Dec.16,2016	01

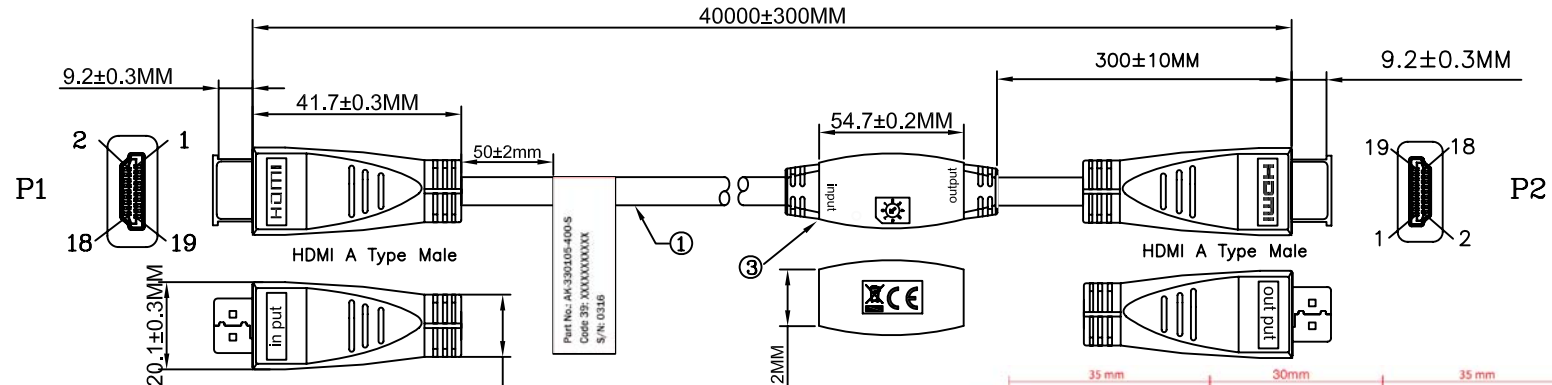


PIN Assignment			
P1	input	output	P2
1	WHITE	1	WHITE
2	RED	2	RED
3	GROUND	3	GROUND
4	WHITE	4	WHITE
5	BROWN	5	BROWN
6	GROUND	6	GROUND
7	WHITE	7	WHITE
8	BLUE	8	BLUE
9	GROUND	9	GROUND
10	WHITE	10	WHITE
11	GREEN	11	GREEN
12	GROUND	12	GROUND
13	BLACK	13	BLACK
14	WHITE	14	WHITE
15	RED	15	RED
16	GRAY	16	GRAY
17	YELLOW	17	YELLOW
18	ORANGE	18	ORANGE
19	PURPLE	19	PURPLE
SHELL	GROUND+JUMP WIRE	SHELL	

- NOTES:
- CABLE: UL20276 (24AWG*1PR+EAM)*4C+24AWG*1PR+28AWG*5C+AEB 50%AL OD:9.5MM
BLACK Print:HIGH SPEED HDMI TM CABLE ...
 - CONNECTOR:
P1 ,P2 : HDMI M 19P Black rubber core Pin Gold-plated needle15u Iron shell plating G/F
 - HDMI TO HDMI Adjustable Repeater (1.4V) +PCB
 - HOOD: MOLDED TYPE,PVC 45P,COLOR:BLACK.
 - ELECTRICLE TEST:
(1)100% OPEN SHORT & MIS WIRE TEST.
(2)CONTACT RESISTANCE 1 ohm Max .
(3)INSULATION RESISTANCE 10M ohm Min .
(4)HI-POT TEST:DC 300V/10ms

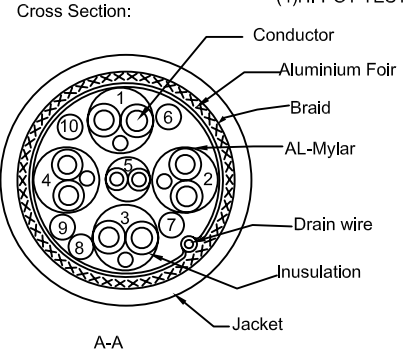

IC
 东莞市南麟电子有限公司
 LN6214P332P (3.3V SOT-89-3L)
 DS16EV5110ASQE

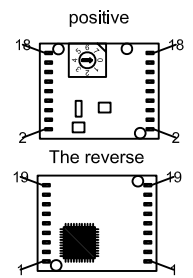

	Date	Name	Part No.
Drawn by	Dec.16,2016	Lyw	AK-330105-400-S
Checked by	Dec.16,2016	Saul	EAN:4016032295846
Approved by	19Dec, 2016	Joe	
ASSMANN Electronic GmbH			Title
			HDMI M TO M 24Awg Cable 1.3 b Gold-plated
Scale	N/A	Sheet	
Unit	MM		1/2

1

2

3

4

5

6

7

A

Package Details

RoHS & REACH Compliant



Signature	Revision History	Date	Rev.
LIBRA	For Bulk Production	Dec.16,2016	01

Single Cable

P/N	Cable Length	Rolling Size (Single Cable)	Polybag Type (Single Cable)	Bag Size (Single Cable)	Article Weight (Single Cable)
AK-330105-400-S	40m	mm max.	ednet Polybag (Stick type)	400*350*0.06mm	3.9 kg

Inner Packing Unit

P/N	Cable Length	Quantity (Inner Packing Unit)	Type (Inner Packing Unit)	Size (Inner Packing Unit)	Weight (Inner Packing Unit)
xxx	Xm	pcs	Polybag (Heat Sealed)	mm	kg

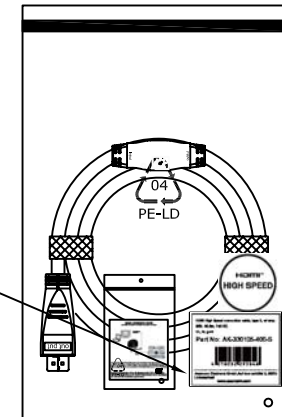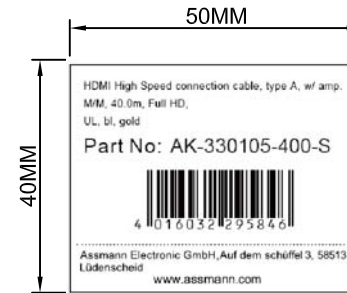

PE bag

B

B

C

C

D

D

CARTON DETAILS


P/N	Cable Length	Quantity (Carton)	Measurement (Carton)	N.W. (Carton)	G.W. (Carton)
AK-330105-400-S	40m	2pcs	420*220*210MM	7.8 kg	8.3 kg

E

E

F


F

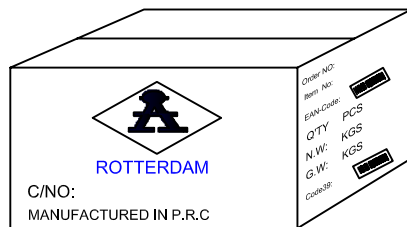

EAN-Code:



Code39:

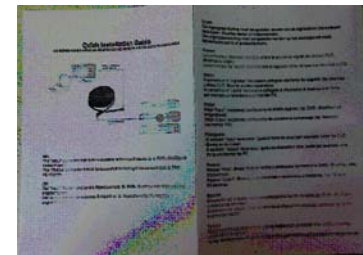

210*297MM color specifications



The instructions

G

G

H

H

- * "ROTTERDAM" is for Sea Freight shipment
- * "COLOGNE" is for Air Freight shipment
- * "LUDENSCHIED" is for Fedex or UPS shipment

	Date	Name	Part No.
Drawn by	Dec.16,2016	Lyw	AK-330105-400-S
Checked by	Dec.16,2016	Saul	EAN:4016032295846
Approved by	19Dec, 2016	Joe	
ASSMANN Electronic GmbH			Title
			HDMI M TO M 24Awg Cable 1.3 b Gold-plated
Scale	N/A	Sheet	2/2
Unit	MM		

1

2

3

4

5

6

7