



Anwendungshinweis

Pneumatik-Saug- und Blaspistole

HAZET®

9043-10





HAZET Pneumatik-Saug- und Blaspistole 9043-10 durch eine kompakte Bauweise ideal zum Aussaugen und Ausblasen verschmutzter schwer zugänglicher Bereiche.



 



Vor jeder Benutzung den Auffangbeutel entleeren und säubern.

 Die Saug- und Blaspistole 9043-10 darf während der Reinigung des Auffangbeutels nicht mit der Druckluft verbunden sein.



 Saugebetrieb nur mit montiertem Auffangbeutel, da angesaugte Partikel beschleunigt in Richtung Anwender geschleudert werden!

 **Achtung:** Das Gerät ist nicht elektrisch isoliert.

Technische Daten:

 HAZET No.		 kg	Schlauch- Ø mm	Luft- verbrauch l/min.	Betriebs- druck bar	 dB(A)	Schall- leistungspegel dB(A)	Vakuump- egel mmHg	Vibrations- beschleunigung m/s ²	 mm
9043-10	12.91(1/4) - 7.2	0,67	10	96	6,3	Lp A 92	Lp W 97	7,5	0,4	145

Aufbewahrung / Lagerung:

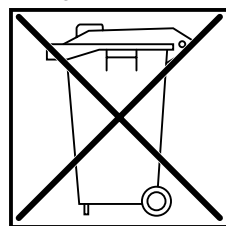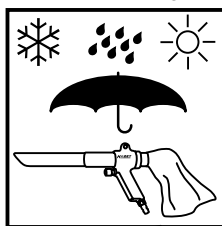

Das Gerät ist unter folgenden Bedingungen zu lagern und aufzubewahren:


- Gerät trocken und staubfrei lagern
- Gerät keinen Flüssigkeiten und/oder aggressiven Substanzen aussetzen
- Gerät nicht im Freien aufbewahren
- Gerät für Kinder unzugänglich aufbewahren
- Lagertemperatur -10°C bis +40°C
- Relative Luftfeuchtigkeit max. 60%

Umstellung Saugen/Blasen:



Lieferumfang:

9043-10 Pneumatische Saug- und Blaspistole mit Deflektor
Kupplungsstecker Nennweite 7,2

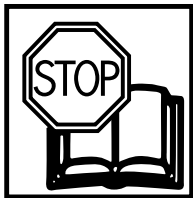

Application Note Pneumatic Suction and Blow Gun



9043-10



HAZET 9043-10 Pneumatic Suction and Blow Gun is ideal for sucking and blowing inaccessible contaminated areas clean thanks to its compact design.



Empty and clean the collection bag before each use.

The 9043-10 Suction and Blow Gun must not be connected to the compressed air while the collection bag is being cleaned.



Suction operation must only be used with the collection bag fitted, as particles that are sucked in are flung in the direction of the user at high speed!

Note: the tool is not electrically insulated.

Technical data:

HAZET No.		kg	Hose- Ø mm	Air consumption l/min.	Working pressure bar	dB(A)	Sound power level dB(A)	Vacuum level mmHg	Vibration acceleration m/s ²	mm
9043-10	12.91(1/4) - 7.2	0.67	10	96	6.3	Lp A 92	Lp W 97	7.5	0.4	145


Storage:

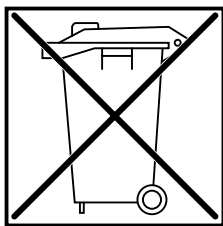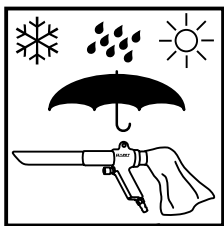

The tool must be stored as follows:

- Keep the tool in a dry and dust-free place
- Do not expose the tool to liquids and/or aggressive substances
- Do not store the tool outdoors
- Keep tool out of reach of children
- Storage temperature -10°C to +40°C
- Relative air humidity: max. 60%

Changing between suction and blowing:

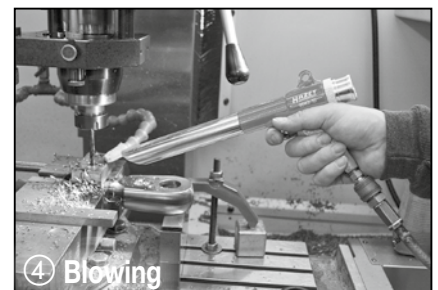

Included in delivery:

9043-10 Pneumatic Suction and Blow Gun with deflector
Coupler plug, nominal size 7.2

HAZET-WERK Hermann Zerver GmbH & Co. KG • 10 04 61 • D-42804 Remscheid • Germany

+49 (0) 21 91 / 7 92-0 • FAX +49 (0) 21 91 / 7 92-375 (Deutschland) -400 (International)

www.hazet.de • e-mail info@hazet.de