



**RoHS & REACH Compliant**

Signature	Revision History	Date	Rev.
LIBRA	For Bulk Production	Dec.14,2016	01

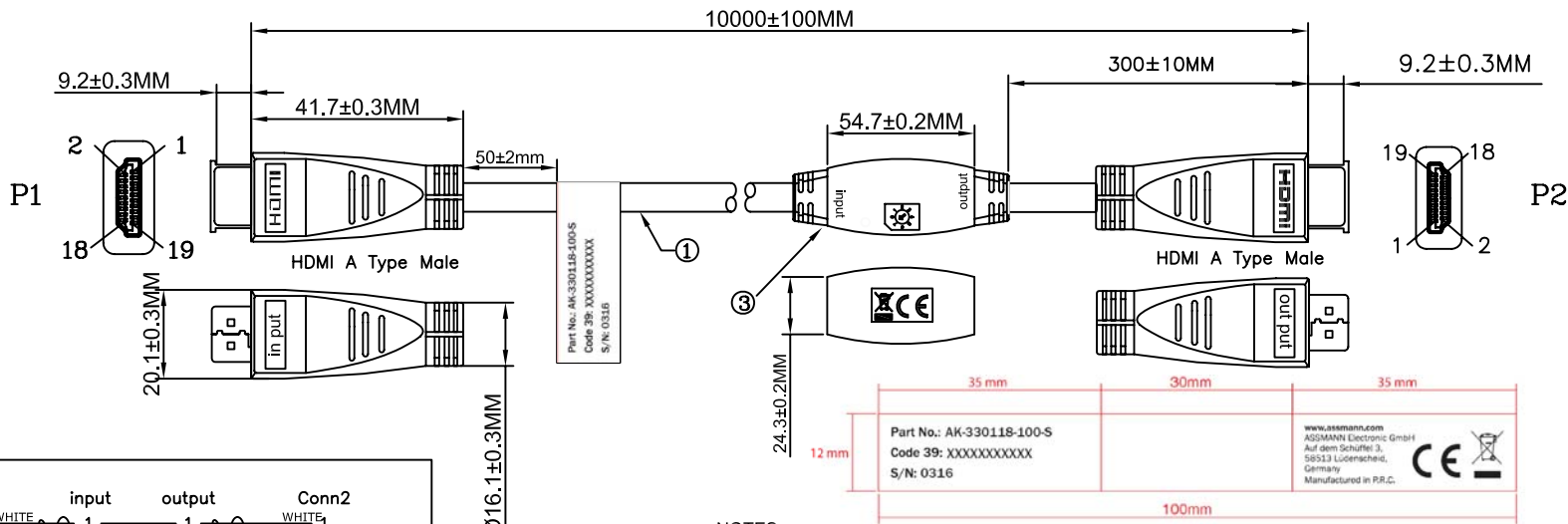


Conn1	input	output	Conn2
1	WHITE	1	WHITE
3	RED	3	RED
2	Drain	2	Drain
4	WHITE	4	WHITE
6	Brown	6	Brown
5	Drain	5	Drain
7	WHITE	7	WHITE
9	BLUE	9	BLUE
8	Drain	8	Drain
10	WHITE	10	WHITE
12	GREEN	12	GREEN
11	Drain	11	Drain
14	WHITE	14	WHITE
19	BLACK	19	BLACK
17	Drain	17	Drain
13	WHITE	13	WHITE
15	RED	15	RED
16	Pink	16	Pink
18	Gray	18	Gray
SHELL	Drain	SHELL	

- NOTES:
- CABLE: UL20276 (7/0.127T\*1PR+EAM)\*5C+7/0.127T\*4C+AEB AL(16\*5/0.12)OD:7.3MM BLACK HIGH SPEED HDMI@ CABLE WITH ETHERNET.....
  - CONNECTOR:  
P1 , P2 : HDMI M 19P Black rubber core Pin Gold-plated needle G/F Iron shell plating G/F
  - HDMI TO HDMI Adjustable Repeater (1.4V) +PCB
  - HOOD: MOLDED TYPE,PVC 45P,COLOR:BLACK.
  - ELECTRICLE TEST:  
(1)100% OPEN SHORT & MIS WIRE TEST.  
(2)CONTACT RESISTANCE 5 ohm Max .  
(3)INSULATION RESISTANCE 10M ohm Min .  
(4)HI-POT TEST:DC 300V/10ms

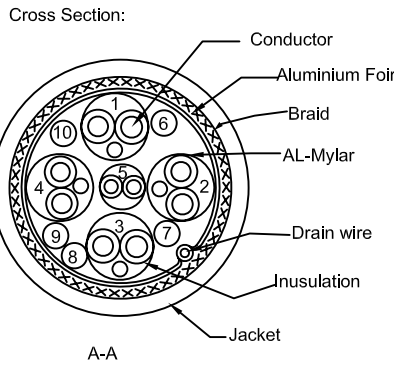

IC  
 东莞市南麟电子有限公司  
 LN6214P332P (3.3V SOT-89-3L)  
 DS16EV5110ASQE

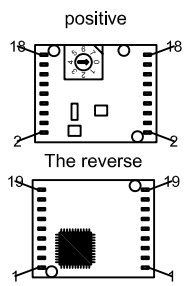

	Date	Name	Part No.
Drawn by	Dec.14,2016	Lyw	<b>AK-330118-100-S</b>
Checked by	Dec.14,2016	Saul	EAN:4016032336617
Approved by	19Dec, 2016	Joe	Title
<b>ASSMANN</b> Electronic GmbH			HDMI M TO M 28Awg Cable 1.3 b Gold-plated
			Scale Unit

# Package Details

RoHS & REACH Compliant



Signature	Revision History	Date	Rev.
LIBRA	For Bulk Production	Dec.14.2016	01

## Single Cable

P/N	Cable Length	Rolling Size (Single Cable)	Polybag Type (Single Cable)	Bag Size (Single Cable)	Article Weight (Single Cable)
AK-330118-100-S	10m	mm max.	ednet Polybag (Stick type)	350*280*0.06mm	0.607 kg

## Inner Packing Unit


P/N	Cable Length	Quantity (Inner Packing Unit)	Type (Inner Packing Unit)	Size (Inner Packing Unit)	Weight (Inner Packing Unit)
xxx	Xm	pcs	Polybag (Heat Sealed)	mm	kg

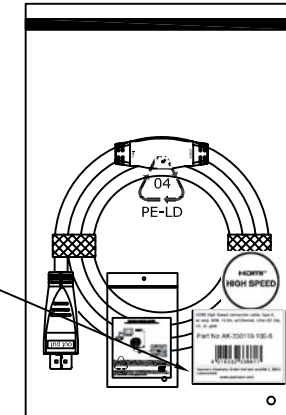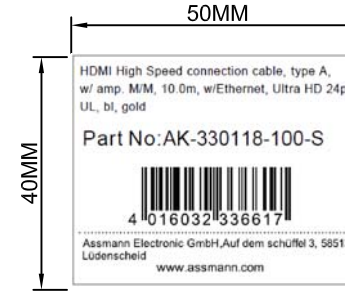

PE bag

## CARTON DETAILS


P/N	Cable Length	Quantity (Carton)	Measurement (Carton)	N.W. (Carton)	G.W. (Carton)
AK-330118-100-S	10m	15pcs	500*320*210MM	9.1 kg	9.9 kg

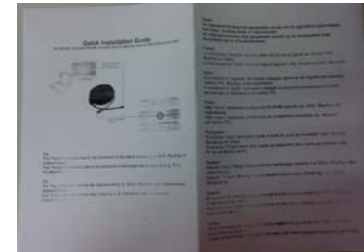

EAN-Code:



Code39:

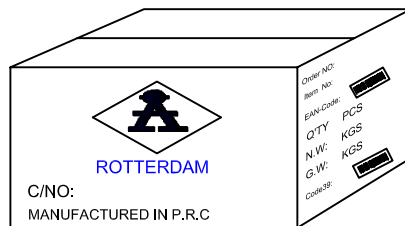

- \* "ROTTERDAM" is for Sea Freight shipment
- \* "COLOGNE" is for Air Freight shipment
- \* "LUDENSCHIED" is for Fedex or UPS shipment

Date		Name	Part No. <b>AK-330118-100-S</b> EAN:4016032336617
Drawn by	Dec.14,2016	Lyw	
Checked by	Dec.14,2016	Saul	
Approved by	19Dec, 2016	Joe	Title HDMI M TO M 28Awg Cable 1.3 b Gold-plated
<b>ASSMANN</b> Electronic GmbH			
Scale	N/A	Sheet	
Unit	MM	2/2	