







max. 60 m 13 mm (1/2")
max. 50 m 16 mm (5/8")
max. 35 m 19 mm (3/4")

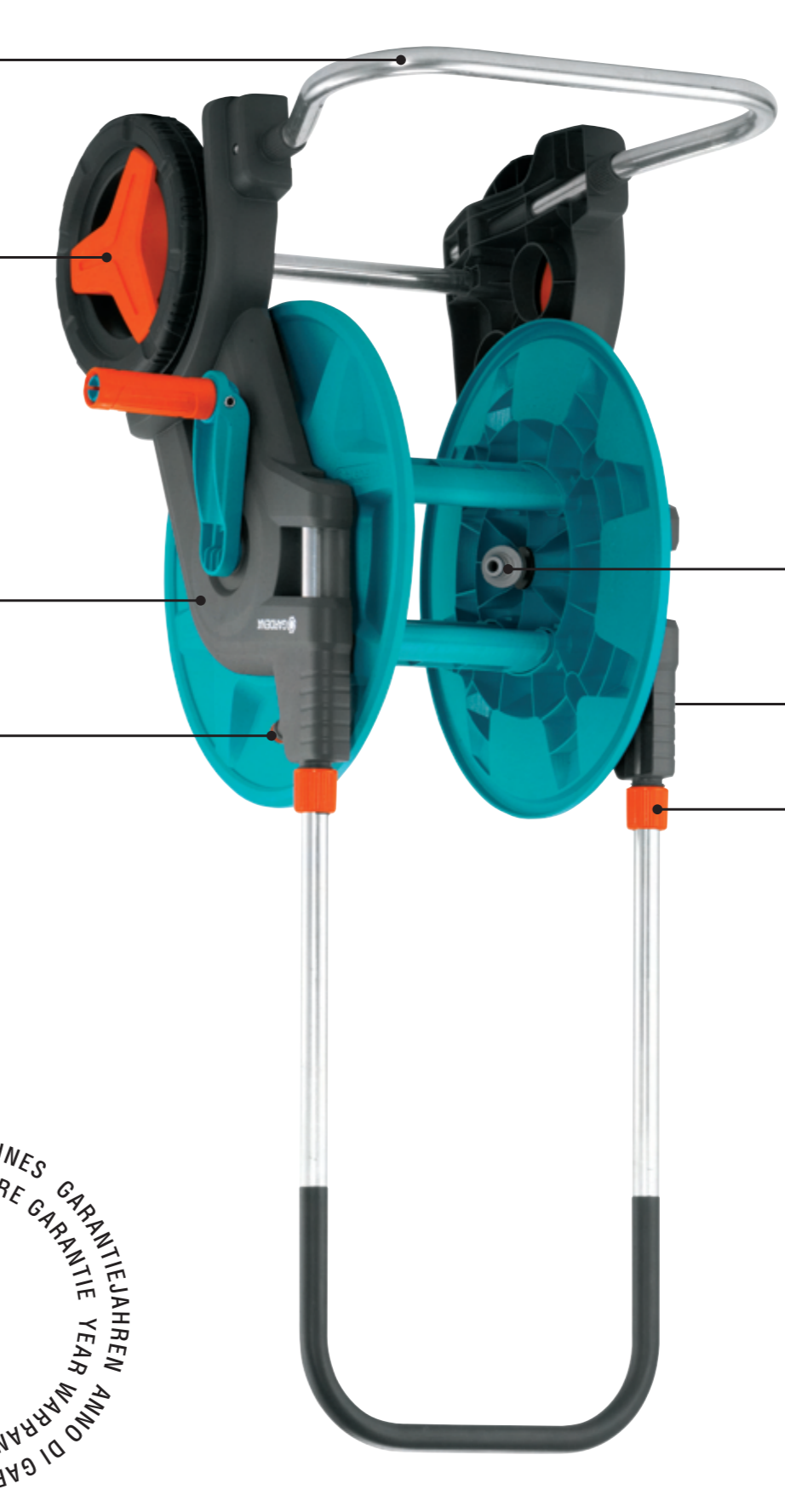

- 1. Griff
- 2. Handlauf
- 3. Schlauchanschluss
- 4. Schlauch
- 5. Handlauf
- 6. Griff

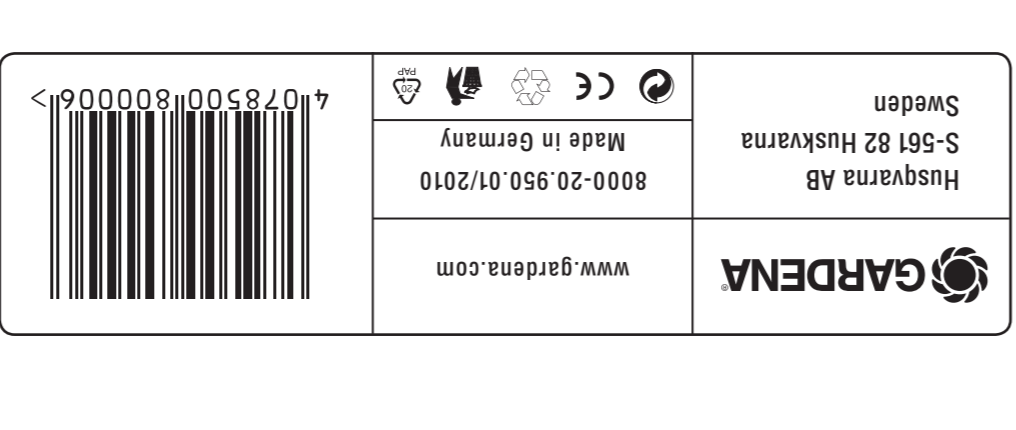

Original GARDENA System
8000-20.950.01+8003-20.950.01

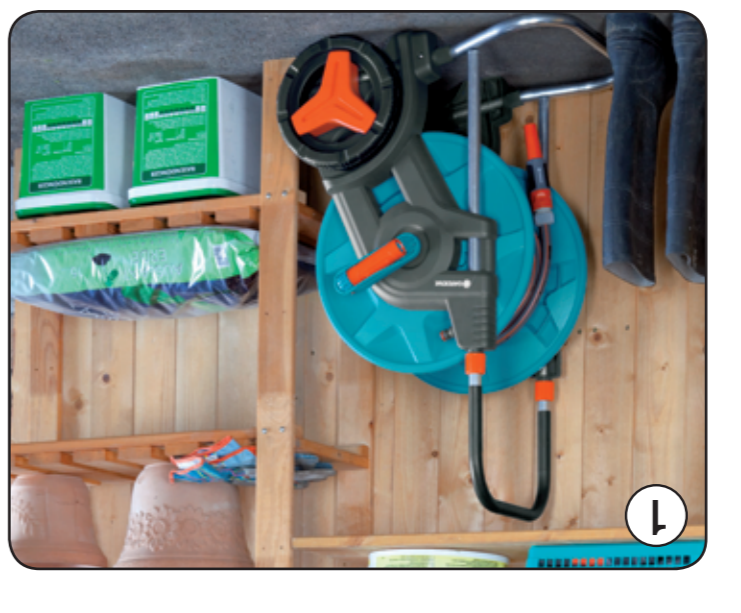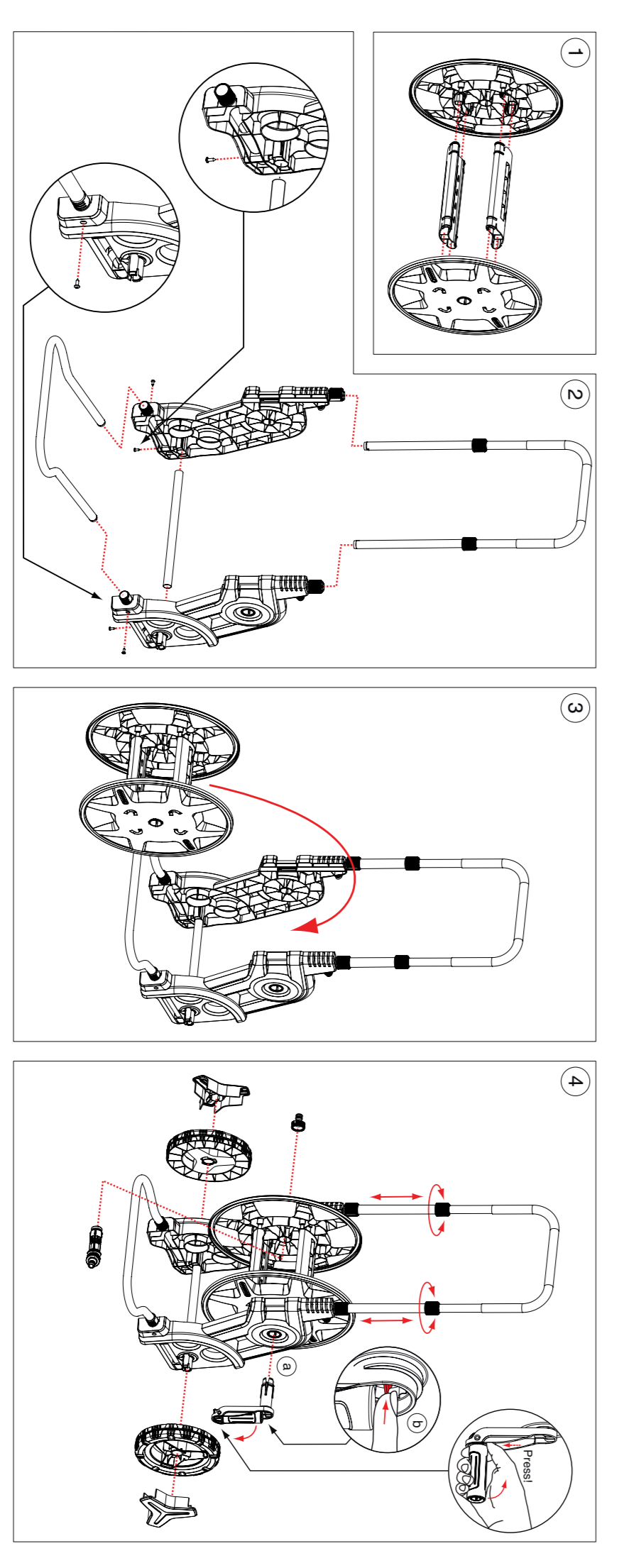

max. 60 m 13 mm (1/2")
max. 50 m 16 mm (5/8")
max. 35 m 19 mm (3/4")

Original GARDENA System

Original GARDENA System

CLASSIC 60 TS



max. 60 m 13 mm (1/2")
max. 50 m 16 mm (5/8")
max. 35 m 19 mm (3/4")

CLASSIC 60 TS



max. 60 m 13 mm (1/2")
max. 50 m 16 mm (5/8")
max. 35 m 19 mm (3/4")



Original GARDENA System

CLASSIC 60 TS

max. 60 m 13 mm (1/2")
max. 50 m 16 mm (5/8")
max. 35 m 19 mm (3/4")

