


5

4

3

2

1

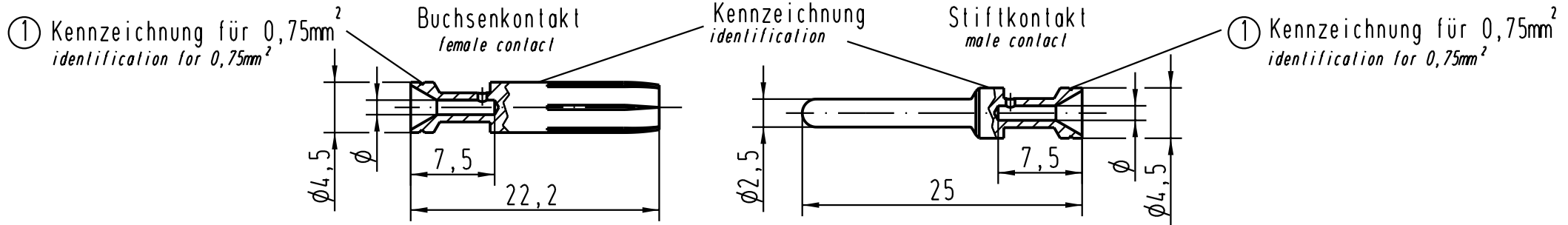

| | Bestell-Nummer /PART NO | | ϕ | Leiterquerschnitt | | Abisolierlänge der Litze | Kennzeichnung identification | |
|---------------------------------------|----------------------------|-------------------------|--------|-------------------|-------|-----------------------------|---------------------------------|----|
| | versilberl silverplated | vergoldet goldplated | | mm ² | AWG | | | |
| C Stiftkontakt male contact | 09 33 000 6127 | 09 33 000 6117 | 0,90 | 0,14-0,37 | 26-22 | 7,5 | keine Rille /no groove | 1) |
| | 09 33 000 6121 | 09 33 000 6122 | 1,15 | 0,5 | 20 | | keine Rille /no groove | |
| | 09 33 000 6114 | 09 33 000 6115 | 1,3 | 0,75 | 18 | | 1 Rille /1 groove ① | |
| | 09 33 000 6105 | 09 33 000 6118 | 1,45 | 1 | 18 | | 1 Rille /1 groove | |
| | 09 33 000 6104 | 09 33 000 6116 | 1,75 | 1,5 | 16 | | 2 Rillen /2 grooves | |
| | 09 33 000 6102 | 09 33 000 6123 | 2,25 | 2,5 | 14 | | 3 Rillen /3 grooves | |
| | 09 33 000 6106 | | 2,55 | 3 | 12 | | 1 breite Rille /1 wide groove | |
| | 09 33 000 6107 | 09 33 000 6119 | 2,85 | 4 | 12 | | keine Rille /no groove | |
| B Buchsenkontakt female contact | 09 33 000 6227 | 09 33 000 6217 | 0,90 | 0,14-0,37 | 26-22 | 7,5 | keine Rille /no groove | 1) |
| | 09 33 000 6220 | 09 33 000 6222 | 1,15 | 0,5 | 20 | | keine Rille /no groove | |
| | 09 33 000 6214 | 09 33 000 6215 | 1,3 | 0,75 | 18 | | 1 Rille /1 groove ① | |
| | 09 33 000 6205 | 09 33 000 6218 | 1,45 | 1 | 18 | | 1 Rille /1 groove | |
| | 09 33 000 6204 | 09 33 000 6216 | 1,75 | 1,5 | 16 | | 2 Rillen /2 grooves | |
| | 09 33 000 6202 | 09 33 000 6223 | 2,25 | 2,5 | 14 | | 3 Rillen /3 grooves | |
| | 09 33 000 6206 | | 2,55 | 3 | 12 | | 1 breite Rille /1 wide groove | |
| | 09 33 000 6207 | 09 33 000 6221 | 2,85 | 4 | 12 | | keine Rille /no groove | |

1) Nur für Buchanan Crimpwerkzeug
Einstell $\phi 1,0$
only for Buchanan crimping tool adjusting $\phi 1,0$

| | | | | | | | | | | | |
|----------------------|--|--|---|----------|------|--------------------------------|--|------|---|---|--------------|
| | | | All Dimensions in mm Original Size DIN A 4 | | | Techn. Character. | | | Nicht tolerierte Masse / Free size tolerances | | |
| | | | | | | Detail. | | Dat. | Name | Massstab / Scale | |
| | | | | | | Insp. | | | HERB | 2:1 | |
| | | | | | | Stand. | | | | Han E Kontakte gedreht 16A/ Han E contacts twisted 16A | |
| | | | 411037 | 18.05.04 | Loe. | HARTING Electric GmbH & Co. KG | | | TB 09 33 000 6... | | |
| | | | 19122 | 24.11.95 | KR | D-32339 Espelkamp | | | | | Blatt / page |
| | | | 15087 | 24.03.93 | ZILK | | | | | | Sub. |
| Bestell Nr / Part No | | | Mod. | Dat. | Name | | | | TB 09 33 000 6... v.17.03.92 | | |